


SAI-M23-SE-L-4/4**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

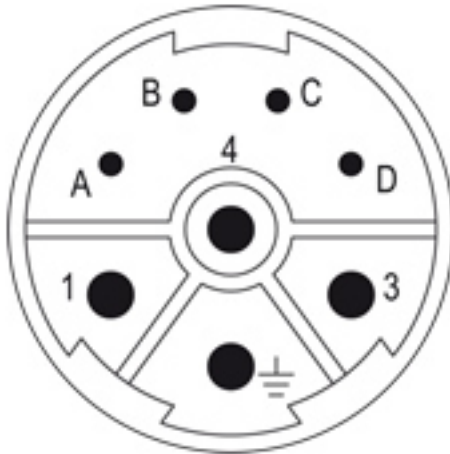Pinning

The M23 round plug-in connectors offer a high number of mating cycles, high current-carrying capacity and high contact-density coupled with minimum dimensions. Enclosures, inserts and crimp contacts need to be ordered separately.

General ordering data

Version	Sensor/Actuator plug-in connector, Insert
Order No.	1170380000
Type	SAI-M23-SE-L-4/4
GTIN (EAN)	4032248962518
Qty.	1 pc(s).

SAI-M23-SE-L-4/4

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 26
 D-32758 Detmold
 Germany

www.weidmueller.com

Technical data

Dimensions and weights

Net weight 7 g

Temperatures

Operating temperature, min. -40 °C Operating temperature, max. 125 °C

Technical data customisable plug-in connectors

Coding	none	Housing main material	Thermoplastic polyamide PA 6, PBT
Number of poles	8	Plugging cycles	> 1000
Pollution severity	3	Rated current	1 mm contact = 8 A, 2 mm contact = 28 A
Rated voltage	1 mm contact= 300 V, 2 mm contact= 600 V	Type of connection	Crimp connection

Classifications

ETIM 6.0	EC000438	ETIM 7.0	EC003557
ETIM 8.0	EC003557	ECLASS 9.1	27-44-02-05
ECLASS 10.0	27-44-02-23	ECLASS 11.0	27-44-02-23
ECLASS 12.0	27-44-02-23		

Approvals

Approvals



ROHS	Conform
UL File Number Search	UL Website
Certificate No. (UR)	E344862

Downloads

Engineering Data	CAD data – STEP
Catalogues	Catalogues in PDF-format
Brochures	FL FIELDWIRING EN FL FIELDWIRING EN


SAI-M23-SE-L-4/4

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 26
 D-32758 Detmold
 Germany


www.weidmueller.com

Drawings

Pinning

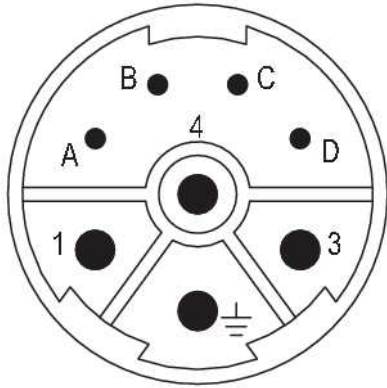

Dimensioned drawing

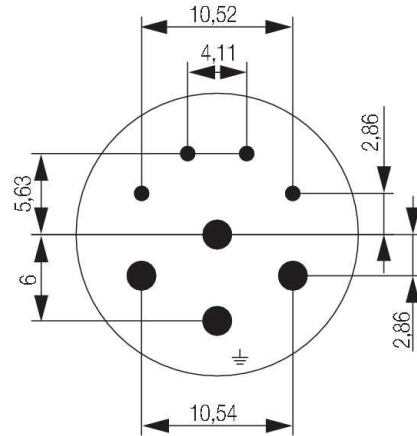

Technical data

		5 + PE		4/4	
No. of poles		5 + PE		4	4
Number of contacts		6		4	4
Contact-ø	mm	2		1	2

4 times 1-mm male and 4 times 2-mm male