

**IE-BHD-V01M-SCA****Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

[www.weidmueller.com](http://www.weidmueller.com)

Bayonet plug-in connectors according to IEC  
61076-3-106 ver.1 (EtherNet/IP), metal, empty housing

**General ordering data**

Version	Empty enclosure, Flange-mounted housing, Variant 1 to IEC 61076-3-106, IP67
Order No.	<a href="#">1221030000</a>
Type	IE-BHD-V01M-SCA
GTIN (EAN)	4050118003956
Qty.	10 pc(s).

Creation date March 7, 2023 6:08:20 PM CET

Catalogue status 03.03.2023 / We reserve the right to make technical changes.

## IE-BHD-V01M-SCA

Weidmüller Interface GmbH &amp; Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

## Technical data

## Dimensions and weights

Depth	27 mm	Depth (inches)	1.063 inch
Height	32 mm	Height (inches)	1.26 inch
Width	32 mm	Width (inches)	1.26 inch
Net weight	57 g		

## Temperatures

Operating temperature	-40 °C...70 °C	Operating temperature, min.	-40 °C
Operating temperature, max.	70 °C		

## General data

Colour	Miscellaneous	Housing main material	Zinc diecast
Plugging cycles	750	Protection degree	IP67
Type of mounting	4 screws, Central nut		

## General standards

Certificate no. (cULus)	E316369	Connector standard	IEC 61076-3-106 Var. 1
-------------------------	---------	--------------------	------------------------

## Classifications

ETIM 6.0	EC001031	ETIM 7.0	EC001031
ETIM 8.0	EC001031	ECLASS 9.0	27-18-27-02
ECLASS 9.1	27-18-27-02	ECLASS 10.0	27-18-27-02
ECLASS 11.0	27-18-27-02	ECLASS 12.0	27-18-27-02

## Environmental Product Compliance

REACH SVHC	Lead 7439-92-1 6,6'-di-tert-butyl-2,2'-methylenedi-p-cresol 119-47-1
SCIP	e5bbf197-73b5-420b-90c0-0173b7b3b6b7

## Approvals

Approvals



UL File Number Search	UL Website
Certificate no. (cULus)	E316369

**IE-BHD-V01M-SCA****Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

[www.weidmueller.com](http://www.weidmueller.com)**Technical data****Downloads**

---

Approval/Certificate/Document of Conformity	<a href="#">DUXR.E316369</a>
Engineering Data	<a href="#">CAD data – STEP</a>
User Documentation	<a href="#">MAN IE GUIDE DE</a> <a href="#">MAN IE GUIDE EN</a> <a href="#">Designation key / Type key</a> <a href="#">Manual</a>
Catalogues	<a href="#">Catalogues in PDF-format</a>
Brochures	<a href="#">MB FREECONTACT EN</a> <a href="#">FL FIELDWIRING EN</a> <a href="#">PI PROFINET CABLING EN</a> <a href="#">PI PROFINET CABLING EN</a>

---


**IE-BHD-V01M-SCA**

**Weidmüller Interface GmbH & Co. KG**  
Klingenbergstraße 26  
D-32758 Detmold  
Germany

**Drawings**

[www.weidmueller.com](http://www.weidmueller.com)

**Installation cut-out**

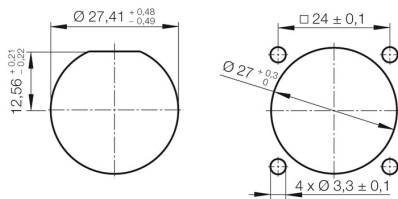

Mounting cut-out: 1. With central screw connection / 2. For mounting with four M3 screws