

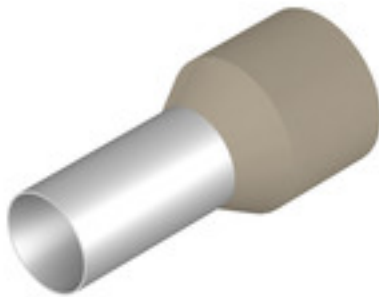
H35,0/32 S BE**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Similar to illustration

- Polypropylene conical cable entry funnel
 - Heat-resistant up to 105°C
- For conductors from 0.5 – 10.0 mm² (AWG 20-7)
Material: E-Cu, tin galvanised
Dimensional tolerance acc. to DIN 46228 sect. 4

General ordering data

Version	Wire-end ferrule, Standard, 21 mm, 18 mm, beige
Order No.	1418340000
Type	H35,0/32 S BE
GTIN (EAN)	4050118221725
Qty.	50 pc(s).
Packaging	loose

Creation date March 8, 2023 10:48:15 AM CET

Catalogue status 03.03.2023 / We reserve the right to make technical changes.

H35,0/32 S BE

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Technical data

Dimensions and weights

Net weight	2.02 g
------------	--------

Technical data

Description of article	Wire-end ferrules with plastic collar, special size, colour beige	Version	Standard
------------------------	---	---------	----------

Wire-end ferrules

Collar diameter (D2)	12.7 mm	Colour code	Weidmüller
Conductor cross-section	35 mm ²	Contact surface diameter (D1)	8.3 mm
Contact surface length (L2)	18 mm	L1 in mm	32 mm
Metal sleeve thickness (S1)	0.2 mm	Plastic collar thickness (S2)	0.4 mm
Stripping length	21 mm	Wire connection cross section AWG, max.	AWG 2

Classifications

ETIM 6.0	EC000005	ETIM 7.0	EC000005
ETIM 8.0	EC000005	ECLASS 9.0	27-40-02-01
ECLASS 9.1	27-40-02-01	ECLASS 10.0	27-40-02-01
ECLASS 11.0	27-40-02-01	ECLASS 12.0	27-40-02-01

Approvals

Approvals



ROHS	Conform
UL File Number Search	UL Website
Certificate No. (UR)	E354986

Downloads

User Documentation	Technical information - EN Technical information - DE
Catalogues	Catalogues in PDF-format

Data sheet

H35,0/32 S BE

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 26
D-32758 Detmold
Germany

www.weidmueller.com

Drawings

Drawing

