

PZ 10 HEX**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com**Crimping tools for wire end ferrules, with and without plastic collars**

- Ratchet guarantees precise crimping
- Release option in the event of incorrect operation

General ordering data

Version	Crimping tool for wire-end ferrules, 0.25mm ² , 10mm ² , Hexagonal crimp
Order No.	1445070000
Type	PZ 10 HEX
GTIN (EAN)	4050118250312
Qty.	1 pc(s).
Replacement parts	9202810000

Creation date March 8, 2023 11:08:54 AM CET

PZ 10 HEX**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Technical data**Dimensions and weights**

Width	195 mm	Width (inches)	7.677 inch
Net weight	600 g		

Technical data

Description of article	(1)Crimping tool
------------------------	------------------

Description of contact

Conductor cross-section, min. AWG	AWG 24	Crimping range, max.	10 mm ²
Crimping range, min.	0.25 mm ²	Type of contact	Wire-end ferrules with/ without plastic collars

tool data crimping

Crimping type/profile	Hexagonal crimp	Wire end ferrules cross-section, max.	10 mm ²
Wire end ferrules cross-section, min.	0.25 mm ²		

Classifications

ETIM 6.0	EC000168	ETIM 7.0	EC000168
ETIM 8.0	EC000168	ECLASS 9.0	21-04-38-11
ECLASS 9.1	21-04-38-11	ECLASS 10.0	21-04-38-11
ECLASS 11.0	21-04-38-11	ECLASS 12.0	21-04-38-11

Environmental Product Compliance

REACH SVHC	Lead 7439-92-1
SCIP	2159813b-98fd-4068-b62a-bc89a046c012

Downloads

Engineering Data	CAD data – STEP
User Documentation	Manual
Catalogues	Catalogues in PDF-format
Brochures	


Data sheet

PZ 10 HEX

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 26
D-32758 Detmold
Germany

www.weidmueller.com

Drawings

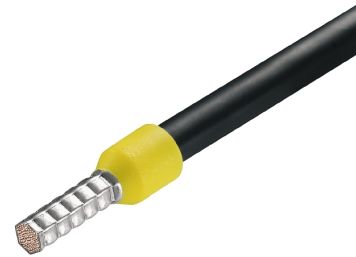

Example of use



Example of use



Example of use

