

CMA-3151-500-AO-24DC-05

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 26
 D-32758 Detmold
 Germany

www.weidmueller.com



Current transformer with analogue output

The simple conversion of "large" currents (100 - 500 A AC) into an analogue value without intermediate steps. Suitable for downstream devices, e.g. limit value detection.

General ordering data

Version	Primary current: 500 A, Output : 0(4)-20 mA, 0(2)-10 V, Load: 1 VA
Order No.	1532050000
Type	CMA-3151-500-AO-24DC-05
GTIN (EAN)	4050118337167
Qty.	1 Stück

Erstellungs-Datum June 2, 2023 9:28:25 AM CEST

CMA-3151-500-AO-24DC-05

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 26
 D-32758 Detmold
 Germany

www.weidmueller.com

Technische Daten

Dimensions and weights

Depth	71 mm	Depth (inches)	2.795 inch
Height	117.8 mm	Height (inches)	4.638 inch
Width	80 mm	Width (inches)	3.15 inch
Net weight	240 g		

Dimensions of live conductors

Round conductor	28 mm	Rail	30 x 10 mm
-----------------	-------	------	------------

Electrical attributes

Load	1 VA	Primary current	500 A
Tolerance class	0,5		

Technical properties

Insulation class	E	Nominal frequency	50 Hz
Thermal rated continuous current $I_{\text{thermal}} 1.5 \times I_{\text{rated}}$			

Output

Output current	4...20 mA
----------------	-----------

Classifications

ETIM 6.0	EC002048	ETIM 7.0	EC002048
ETIM 8.0	EC002048	ECLASS 9.0	27-21-09-02
ECLASS 9.1	27-21-09-02	ECLASS 10.0	27-21-09-02
ECLASS 11.0	27-21-09-02	ECLASS 12.0	27-21-09-02



Approvals

ROHS	Conform
------	---------

Downloads

Approval/Certificate/Document of Conformity	Declaration of Conformity
Catalogues	Catalogues in PDF-format

Zeichnungen

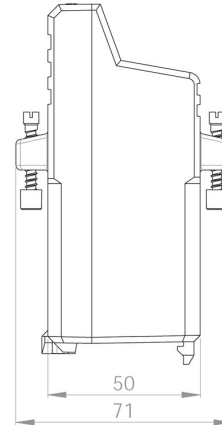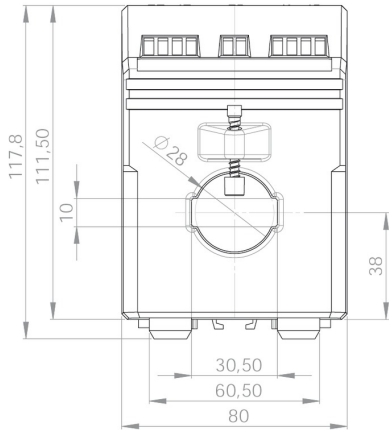

Connection diagram

