


PAGETAB 38/11**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

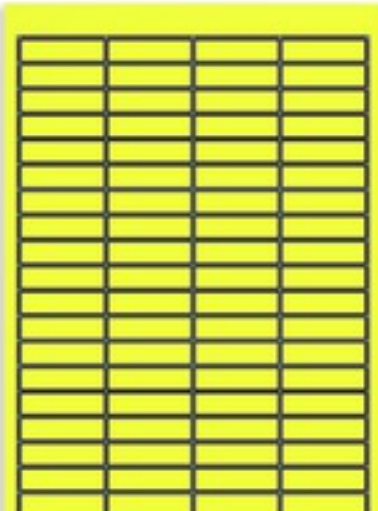

Similar to illustration

PageTab are woven-fabric labels in sheet form. Except for the 8 x 20 version, all labels have a black border.

General ordering data

Version	Device markers, Device markers, 11 x 38 mm, yellow
Order No.	1686200000
Type	PAGETAB 38/11
GTIN (EAN)	4008 190492632
Qty.	25 Stück

Erstellungs-Datum May 16, 2023 4:17:02 PM CEST

Katalogstand 12.05.2023 / Technische Änderungen vorbehalten

PAGETAB 38/11

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 26
 D-32758 Detmold
 Germany

www.weidmueller.com

Technische Daten

Dimensions and weights

Depth	0.08 mm	Depth (inches)	0.003 inch
Height	11 mm	Height (inches)	0.433 inch
Width	38 mm	Width (inches)	1.496 inch
Net weight	12.36 g		

Temperatures

Operating temperature range	-29...93 °C
-----------------------------	-------------

General data

Adhesive	Permanent acrylic copolymer	Colour	yellow
Material	Acrylic-coated fibre webbing	Material colour according to resistance code	4
Number of markers per combination	1 Label sheet = 100 Device markers	Number per sheet	100
Operating temperature range	-29...93 °C	Operating temperature range, max.	93 °C
Operating temperature range, min.	-29 °C	Printing	Neutral
Version	Self-adhesive	Width	38 mm

Classifications

ETIM 6.0	EC001288	ETIM 7.0	EC001288
ETIM 8.0	EC001288	ECLASS 9.0	27-40-06-29
ECLASS 9.1	27-40-06-29	ECLASS 10.0	27-40-06-29
ECLASS 11.0	27-28-11-04	ECLASS 12.0	27-28-11-04

Approvals

ROHS	Conform
------	---------

Downloads

Engineering Data	WSCAD, EPLAN
Catalogues	Catalogues in PDF-format

Zeichnungen

