

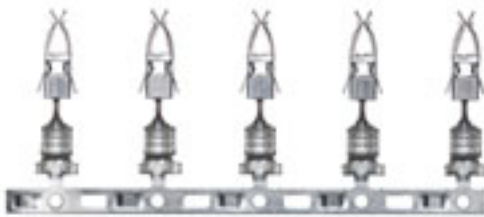
**FEKO ET ZRV2.5 1.5-2.5****Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

**Product image**

Similar to illustration

We offer a broad portfolio of mounting support for easy handling and supplementation of our products. From various tools to insulating sleeves and various screws, our components are matched to each other down to the last detail and thus facilitate assembly in compliance with the respective standards and protective regulations.

**General ordering data**

Version	Z-series, Crimp contact, 4.15 mm, silver, Direct mounting
Order No.	<a href="#">1893990000</a>
Type	FEKO ET ZRV2.5 1.5-2.5
GTIN (EAN)	4032248508211
Qty.	500 pc(s).
Packaging	Multipack bag

Creation date February 28, 2023 5:08:21 PM CET

Catalogue status 18.02.2023 / We reserve the right to make technical changes.

## FEKO ET ZRV2.5 1.5-2.5

Weidmüller Interface GmbH &amp; Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

## Technical data

## Dimensions and weights

Depth	3.1 mm	Depth (inches)	0.122 inch
Height	19.8 mm	Height (inches)	0.78 inch
Width	4.15 mm	Width (inches)	0.163 inch
Net weight	0.43 g		

## Temperatures

Storage temperature	-25 °C...55 °C
---------------------	----------------

## Material data

Material	Copper	Colour	silver
----------	--------	--------	--------

## System specifications

Version	Spring contact
---------	----------------

## Additional technical data

Installation advice	Direct mounting
---------------------	-----------------

## Conductors for clamping (rated connection)

Type of connection	Spring contact
--------------------	----------------

## General

Installation advice	Direct mounting
---------------------	-----------------

## Rating data

Rated cross-section	2.5 mm <sup>2</sup>	Volume resistance according to IEC 60947-7-x	1.33 mΩ
Power loss in accordance with IEC 60947-7-x	0.77 W		

## Classifications

ETIM 6.0	EC000796	ETIM 7.0	EC000796
ETIM 8.0	EC000796	ECLASS 9.0	27-44-02-04
ECLASS 9.1	27-44-02-04	ECLASS 10.0	27-44-02-04
ECLASS 11.0	27-44-02-04	ECLASS 12.0	27-44-02-04

## Environmental Product Compliance

REACH SVHC	Lead 7439-92-1
SCIP	c6099607-b1cd-4fc8-8f5b-8c2defa73093

## Approvals

ROHS	Conform
------	---------

**FEKO ET ZRV2.5 1.5-2.5**

**Weidmüller Interface GmbH & Co. KG**  
Klingenbergstraße 26  
D-32758 Detmold  
Germany

[www.weidmueller.com](http://www.weidmueller.com)

**Technical data****Downloads**

Engineering Data	<a href="#">CAD data – STEP</a>
Engineering Data	<a href="#">WSCAD</a>
User Documentation	<a href="#">StorageConditionsTerminalBlocks</a>
Catalogues	<a href="#">Catalogues in PDF-format</a>
Brochures	<a href="#">CAT 1 TERM 16/17 EN</a>