

**IE-PS-SC-MM****Weidmüller Interfaces GmbH & Co. KG**

Postfach 3030


32760 Detmold

Tel. +49 5231 14-0

Fax. +49 5231 14-2083

info@weidmueller.com

www.weidmueller.com

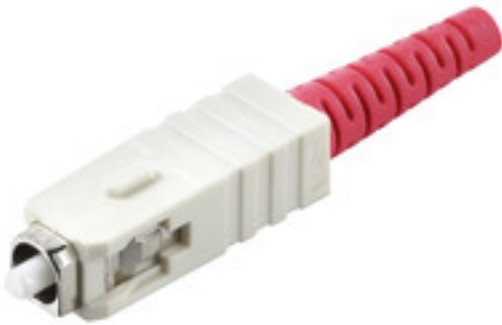

IE plug-in connectors, IP20, for copper and fibre optic cables

**General ordering data**

Version	FO connector, Plug SC, multimode, IP20
Order No.	<a href="#">1962910000</a>
Type	IE-PS-SC-MM
GTIN (EAN)	4032248645107
Qty.	10 Stück

## IE-PS-SC-MM

**Weidmüller Interfaces GmbH & Co. KG**

Postfach 3030

32760 Detmold

Tel. +49 5231 14-0

Fax. +49 5231 14-2083

info@weidmueller.com

www.weidmueller.com

## Technische Daten

### Dimensions and weights

Net weight 12.4 g

### Temperatures

Operating temperature -40 °C...70 °C

Operating temperature, min. -40 °C

Operating temperature, max. 70 °C

### General data

Colour Miscellaneous

Connection 1 SC-Simplex

Connection 2 gluing, crimping, polishing

Description of article Plug SC, multimode

Fibre type Multimode

Insertion loss ≤ 0.4 dB

Plugging cycles 1000

Protection degree IP20

Return loss (attenuation) ≥ 30 dB

### General standards

Connector standard IEC 61754-4

### Classifications

ETIM 6.0 EC001122

ETIM 7.0 EC001122

ETIM 8.0 EC001122

ECLASS 9.0 19-17-01-22

ECLASS 9.1 19-17-01-22

ECLASS 10.0 19-17-01-22

ECLASS 11.0 19-17-01-22

ECLASS 12.0 19-17-01-22

### Environmental Product Compliance

REACH SVHC Lead 7439-92-1

SCIP 67cf1078-beca-4687-860b-dc475a6ec24a

### Approvals

Approvals



ROHS Conform

### Downloads

Approval/Certificate/Document of Conformity [GOST Approval](#)

Engineering Data [WSCAD](#)

User Documentation [MAN IE GUIDE DE](#)  
[MAN IE GUIDE EN](#)

Catalogues [Catalogues in PDF-format](#)

Brochures [FL FIELDWIRING EN](#)  
[PI PROFINET CABLING EN](#)