

**IE-BS-V04P-SCRJ2SC-SM-C**

**Weidmüller Interfaces GmbH & Co. KG**

Postfach 3030

32760 Detmold

Tel. +49 5231 14-0

Fax. +49 5231 14-2083

info@weidmueller.com

www.weidmueller.com



PushPull plug-in connector set according to IEC  
61076-3-106 ver.4 (IEC24702), plastic with SC insert

**General ordering data**

Version	Flange FO, IP67, Version 4, coupling from SCRJ on 2*SC, Singlemode
Order No.	<a href="#">1963420000</a>
Type	IE-BS-V04P-SCRJ2SC-SM-C
GTIN (EAN)	4032248645510
Qty.	10 Stück

## IE-BS-V04P-SCRJ2SC-SM-C

Weidmüller Interfaces GmbH & Co. KG

Postfach 3030

32760 Detmold

Tel. +49 5231 14-0

Fax. +49 5231 14-2083

info@weidmueller.com

www.weidmueller.com

## Technische Daten

### Dimensions and weights

Depth	48.3 mm	Depth (inches)	1.902 inch
Height	38 mm	Height (inches)	1.496 inch
Width	27 mm	Width (inches)	1.063 inch
Net weight	29.3 g		

### Temperatures

Operating temperature	-40 °C...70 °C	Operating temperature, min.	-40 °C
Operating temperature, max.	70 °C		

### General data

Colour	Miscellaneous	Connection 1	SC
Connection 2	SCRJ	Description of article	Version 4, coupling from SCRJ on 2*SC
Fibre type	Singlemode	Housing main material	PA UL 94 V0
Insertion loss	≤ 0.5 dB	Plugging cycles	500
Protection degree	IP67	Return loss (attenuation)	≥ 40 dB

### General standards

Connector standard	IEC 61076-3-106 Var. 4, IEC 61754-4, IEC 61754-24
--------------------	---

### Classifications

ETIM 6.0	EC001122	ETIM 7.0	EC001122
ETIM 8.0	EC001122	ECLASS 9.0	19-17-01-22
ECLASS 9.1	19-17-01-22	ECLASS 10.0	19-17-01-22
ECLASS 11.0	19-17-01-22	ECLASS 12.0	19-17-01-22

### Approvals

ROHS	Conform
------	---------

### Downloads

Approval/Certificate/Document of Conformity	<a href="#">GOST Approval</a> <a href="#">PROFINET Manufacturer's Declaration</a>
Engineering Data	<a href="#">CAD data – STEP</a>
Engineering Data	<a href="#">WSCAD</a>
User Documentation	<a href="#">MAN IE GUIDE DE</a> <a href="#">MAN IE GUIDE EN</a> <a href="#">Designation key / Type key</a> <a href="#">Manual</a>
Catalogues	<a href="#">Catalogues in PDF-format</a>
Brochures	<a href="#">FL FIELDWIRING EN</a> <a href="#">PI PROFINET CABLING EN</a> <a href="#">PI PROFINET CABLING EN</a>

## IE-BS-V04P-SCRJ2SC-SM-C

Weidmüller Interfaces GmbH & Co. KG

Postfach 3030

32760 Detmold

Tel. +49 5231 14-0


Fax. +49 5231 14-2083

info@weidmueller.com

www.weidmueller.com

## Zeichnungen

### Installation cut-out

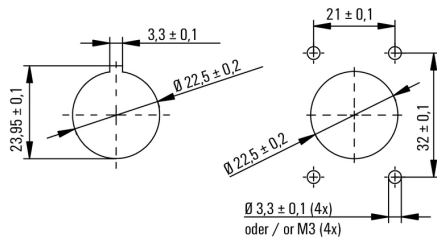

Mounting cut-out: 1. With central screw connection / 2. For mounting with four M3 screws