

IE-BS-V01M-RJ45-FJ-A**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Bayonet plug-in connector sets according to IEC
61076-3-106 ver.1 (EtherNet/IP), RJ45 metal insert incl.
RJ45 insert

General ordering data

Version	Flange RJ45, IP67, Variant 1 metal, IDC, EIA/TIA 586 A, Cat.6A / Class EA (ISO/IEC 11801 2010)
Order No.	1963480000
Type	IE-BS-V01M-RJ45-FJ-A
GTIN (EAN)	4032248645572
Qty.	10 pc(s).

Creation date February 28, 2023 6:54:07 PM CET

Catalogue status 18.02.2023 / We reserve the right to make technical changes.

IE-BS-V01M-RJ45-FJ-A

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Technical data

Dimensions and weights

Height	32 mm	Height (inches)	1.26 inch
Width	32 mm	Width (inches)	1.26 inch
Net weight	61.4 g		

Temperatures

Operating temperature	-40 °C...70 °C	Operating temperature, min.	-40 °C
Operating temperature, max.	70 °C		

General data

Connection 1	RJ45	Connection 2	IDC
Description of article	Variant 1 metal, IDC, EIA/ TIA 586 A	Wiring	TIA-568A
Seal material	EPDM	Colour	Miscellaneous
Housing main material	Zinc diecast	Insulation cross-section, max.	1.6 mm
Category	Cat.6A / Class EA (ISO/ IEC 11801 2010)	Contact surface	Gold over nickel
Connection diameter, solid	0.4...0.64 mm	Conductor connection cross-section, solid (AWG)	AWG 24...AWG 22
Connection diameter, flexible	0.48...0.76 mm	Conductor connection cross-section, flexible (AWG)	AWG 26...AWG 22
Shielding	360°; all-round enclosure	Protection degree	IP67
Plugging cycles	750		

General standards

Certificate no. (cULus)	E316369	Connector standard	IEC 61076-3-106 Var. 1, IEC 60603-7-51
-------------------------	---------	--------------------	---

Classifications

ETIM 6.0	EC001121	ETIM 7.0	EC001121
ETIM 8.0	EC001121	ECLASS 9.0	27-44-03-90
ECLASS 9.1	27-44-03-90	ECLASS 10.0	27-44-03-90
ECLASS 11.0	27-44-03-90	ECLASS 12.0	27-44-03-90

Environmental Product Compliance

REACH SVHC	Lead 7439-92-1
SCIP	67cf1078-beca-4687-860b-dc475a6ec24a

Approvals

Approvals



ROHS	Conform
UL File Number Search	UL Website
Certificate no. (cULus)	E316369

Creation date February 28, 2023 6:54:07 PM CET

Catalogue status 18.02.2023 / We reserve the right to make technical changes.

2

IE-BS-V01M-RJ45-FJ-A

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Technical data

Downloads

Approval/Certificate/Document of Conformity	GOST Approval ISO/IEC and TIA/EIA DE ISO/IEC EN and TIA/EIA Screened Class E Category 6, 3 connector permanent link ISO/IEC EN and TIA/EIA Screened Class E Category 6, 4 connector channel ISO/IEC EN and TIA/EIA Screened Class EA Category 6A, 2 connector channel DUXR.E316369 Compliance Statement Screened Category 6 ISO/IEC EN and TIA/EIA Connecting Hardware
Engineering Data	CAD data – STEP
Engineering Data	WSCAD
Product Change Notification	Technical change to Bulkhead Variant 1 (Metal) - EN Technical change to Bulkhead Variant 1 (Metal) - DE 20190724 Technische Änderung zu Flansch Variante 1 (Metall) 20190724 Technische Änderung zu Flansch Variante 1 (Metall) 20190724 Technical change to Bulkhead Variant 1 (Metal)
User Documentation	MAN IE GUIDE DE MAN IE GUIDE EN Designation key / Type key Manual
Catalogues	Catalogues in PDF-format
Brochures	MB FREECONCONTACT EN FL FIELDWIRING EN PI PROFINET CABLING EN PI PROFINET CABLING EN


IE-BS-V01M-RJ45-FJ-A

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 26
D-32758 Detmold
Germany

Drawings

www.weidmueller.com

Installation cut-out

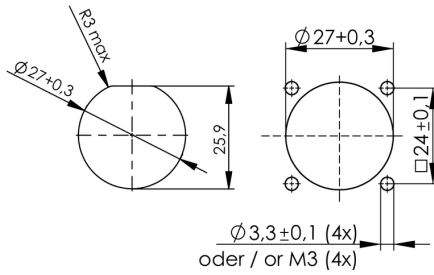

Mounting cut-out: 1. With central screw connection / 2. For mounting with four M3 screws