

**IE-BS-V04P-LCD-MM-C****Weidmüller Interfaces GmbH & Co. KG**

Postfach 3030

32760 Detmold

Tel. +49 5231 14-0

Fax. +49 5231 14-2083

info@weidmueller.com

www.weidmueller.com



PushPull plug-in connector set according to IEC  
61076-3-106 ver.4 (IEC24702), plastic with LC insert

**General ordering data**

|            |   |
|------------|---|
| Version    | Flange FO, IP67, Version 4, LC Duplex coupling, Multimode |
| Order No.  | <a href="#">1964460000</a>                                |
| Type       | IE-BS-V04P-LCD-MM-C                                       |
| GTIN (EAN) | 4032248651924   |
| Qty.       | 10 Stück  |

## IE-BS-V04P-LCD-MM-C

Weidmüller Interfaces GmbH & Co. KG

Postfach 3030

32760 Detmold

Tel. +49 5231 14-0

Fax. +49 5231 14-2083

info@weidmueller.com

www.weidmueller.com

## Technische Daten

### Dimensions and weights

|            |         |                 |            |
|------------|---------|-----------------|------------|
| Depth      | 45.3 mm | Depth (inches)  | 1.783 inch |
| Height     | 38 mm   | Height (inches) | 1.496 inch |
| Width      | 27 mm   | Width (inches)  | 1.063 inch |
| Net weight | 25.3 g  |                 |            |

### Temperatures

|                             |                |                             |        |
|-----------------------------|----------------|-----------------------------|--------|
| Operating temperature       | -40 °C...70 °C | Operating temperature, min. | -40 °C |
| Operating temperature, max. | 70 °C          |                             |        |

### General data

|                   |               |                           |                               |
|-------------------|---------------|---------------------------|-------------------------------|
| Colour            | Miscellaneous | Connection 1              | LC Duplex                     |
| Connection 2      | LC Duplex     | Description of article    | Version 4, LC Duplex coupling |
| Fibre type        | Multimode     | Housing main material     | PA UL 94 V0                   |
| Insertion loss    | ≤ 0.4 dB      | Plugging cycles           | 500                           |
| Protection degree | IP67          | Return loss (attenuation) | ≥ 30 dB                       |

### General standards

|                    |   |
|--------------------|---|
| Connector standard | IEC 61076-3-106 Var. 4,<br>IEC 61754-20 |
|--------------------|---|

### Classifications

|             |             |             |             |
|-------------|-------------|-------------|-------------|
| ETIM 6.0    | EC001122    | ETIM 7.0    | EC001122    |
| ETIM 8.0    | EC001122    | ECLASS 9.0  | 19-17-01-22 |
| ECLASS 9.1  | 19-17-01-22 | ECLASS 10.0 | 19-17-01-22 |
| ECLASS 11.0 | 19-17-01-22 | ECLASS 12.0 | 19-17-01-22 |

### Approvals

|      |         |
|------|---------|
| ROHS | Conform |
|------|---------|

### Downloads

|   |  |
|---|--|
| Approval/Certificate/Document of Conformity | <a href="#">GOST Approval</a>  |
| Engineering Data                            | <a href="#">WSCAD</a>  |
| User Documentation                          | <a href="#">MAN IE GUIDE DE</a><br><a href="#">MAN IE GUIDE EN</a><br><a href="#">Designation key / Type key</a><br><a href="#">Manual</a> |
| Catalogues                                  | <a href="#">Catalogues in PDF-format</a>   |
| Brochures                                   | <a href="#">FL FIELDWIRING EN</a><br><a href="#">PI PROFINET CABLING EN</a><br><a href="#">PI PROFINET CABLING EN</a>                      |

## IE-BS-V04P-LCD-MM-C

Weidmüller Interfaces GmbH & Co. KG

Postfach 3030

32760 Detmold

Tel. +49 5231 14-0


Fax. +49 5231 14-2083

info@weidmueller.com

www.weidmueller.com

## Zeichnungen

### Installation cut-out

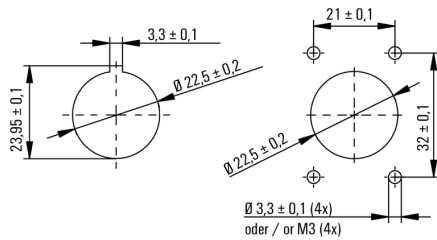

Mounting cut-out: 1. With central screw connection / 2. For mounting with four M3 screws