

## IE-FC-DFM-CAB-DB

**Weidmüller Interfaces GmbH & Co. KG**

Postfach 3030

32760 Detmold

Tel. +49 5231 14-0

Fax. +49 5231 14-2083

info@weidmueller.com

www.weidmueller.com



FrontCom® Vario integrates multiple functions in only one single frame. The system is easy to install and you can select from a wide range of data, signal and power modules. In addition to being extremely compact, FrontCom® Vario offers a number of unique product features that will make your project planning and work activities secure, fast and future-proof. Furthermore, the FrontCom® Vario system has an attractive housing design that, by the way, offers highest impact-resistance and fully meets the requirements of IP 65 protection class.

### General ordering data

Version	FrontCom, Double frame, Metal cover, Lockable with cabinet key (Daimler lock)
Order No.	<a href="#">2003150000</a>
Type	IE-FC-DFM-CAB-DB
GTIN (EAN)	4050118386929
Qty.	1 pc(s).

## IE-FC-DFM-CAB-DB

Weidmüller Interfaces GmbH &amp; Co. KG

Postfach 3030

32760 Detmold

Tel. +49 5231 14-0

Fax. +49 5231 14-2083

info@weidmueller.com

www.weidmueller.com

## Technical data

## Dimensions and weights

Depth	27.5 mm	Depth (inches)	1.083 inch
Height	134 mm	Height (inches)	5.276 inch
Width	132 mm	Width (inches)	5.197 inch
Wall thickness, min.	1 mm	Wall thickness, max.	5 mm
Net weight	815.95 g		

## Temperatures

Operating temperature	-40 °C...70 °C	Operating temperature, min.	-40 °C
Operating temperature, max.	70 °C		

## General data

Material cover	Zinc diecast, powder-coated	Material frame	Zinc diecast
Product type	Double frame, Metal cover, Lockable with cabinet key (Daimler lock)	Protection class (UL)	Type 12
Protection degree	IP65, in closed state		

## General standards

Certificate No. (CSA)	2000039-80039714	Certificate No. (cURus)	E223801
-----------------------	------------------	-------------------------	---------

## Classifications

ETIM 6.0	EC001031	ETIM 7.0	EC001031
ETIM 8.0	EC001031	ECLASS 9.0	27-18-27-02
ECLASS 9.1	27-18-27-90	ECLASS 10.0	27-18-27-02
ECLASS 11.0	27-18-27-02	ECLASS 12.0	27-18-28-92

## Approvals

Approvals



ROHS	Conform
UL File Number Search	UL Website
Certificate No. (cURus)	E223801

## Downloads

Engineering Data	<a href="#">CAD data – STEP</a>
User Documentation	<a href="#">Manual</a> <a href="#">Designation key / Type key</a>
Catalogues	<a href="#">Catalogues in PDF-format</a>

**IE-FC-DFM-CAB-DB**

Weidmüller Interfaces GmbH & Co. KG

Postfach 3030


32760 Detmold

Tel. +49 5231 14-0

Fax. +49 5231 14-2083


**Drawings**

**Dimensioned drawing**

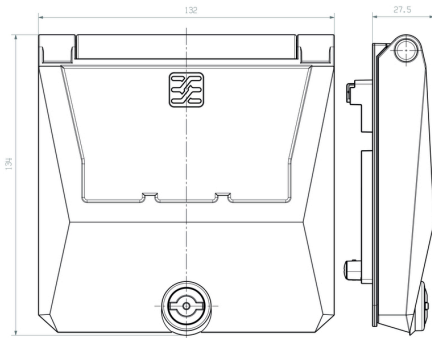


Unit: mm

**Installation cut-out** [info@weidmueller.com](mailto:info@weidmueller.com)

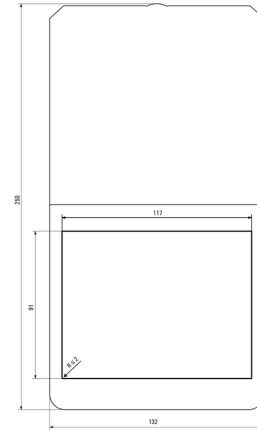


Unit: mm

**Dimensioned drawing**

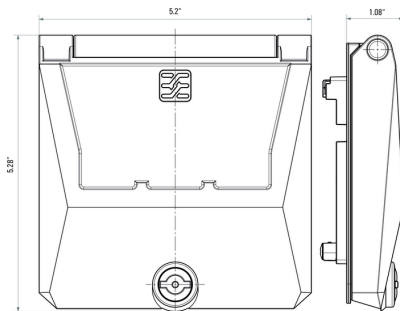

Unit: in

**Installation cut-out**

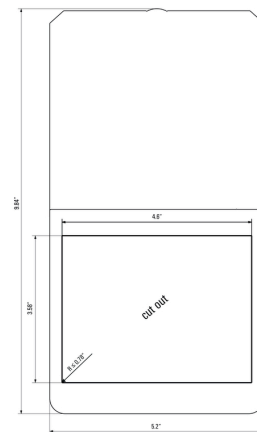

Unit: in