

SAI-WDF 5P M12 K

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 26
D-32758 Detmold
Germany

www.weidmueller.com

Similar to illustration



General ordering data

Order No.	2427060000
Type	SAI-WDF 5P M12 K
GTIN (EAN)	4050118435542
Qty.	1 pc(s).

SAI-WDF 5P M12 K

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Technical data

Dimensions and weights

Net weight 20 g

Technical data customisable plug-in connectors

Cable glands	M 12	Coding	A
Contact surface	Gold-plated	Housing main material	CuZn
Number of poles	5	Protection degree	IP67
Rated current	4 A	Rated voltage	60 V
Temperature range of housing	-40 ... +85 °C	Type of connection	Screw connection

General technical specifications

Cable glands	M 12	Coding	A
Connection thread	M12 socket, M12 plug	Contact material	CuZn
Contact surface	Gold-plated	Housing main material	CuZn
Number of poles	5	Protection degree	IP67
Rated current	4 A	Rated voltage	60 V
Temperature range of housing	-40 ... +85 °C	Type of connection	Screw connection

Classifications

ETIM 6.0	EC002925	ETIM 7.0	EC002925
ETIM 8.0	EC002925	ECLASS 9.0	27-44-01-06
ECLASS 9.1	27-44-01-06	ECLASS 10.0	27-44-01-06
ECLASS 11.0	27-44-01-06	ECLASS 12.0	27-44-01-06

Environmental Product Compliance

REACH SVHC	Lead 7439-92-1
SCIP	22cbd99b-5f46-4c36-9938-bd61e241a9ab

Approvals

Approvals



ROHS Conform

Downloads

Engineering Data	CAD data – STEP
Engineering Data	WSCAD
Catalogues	Catalogues in PDF-format
Brochures	FL FIELDWIRING EN


SAI-WDF 5P M12 K

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 26
 D-32758 Detmold
 Germany


www.weidmueller.com

Drawings


Dimensioned drawing

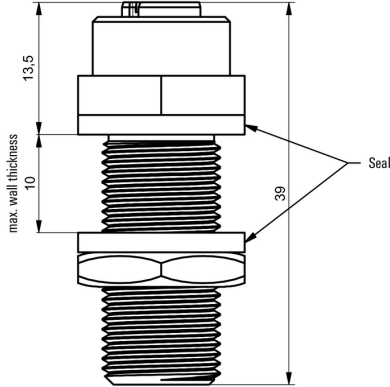

Dimensioned drawing

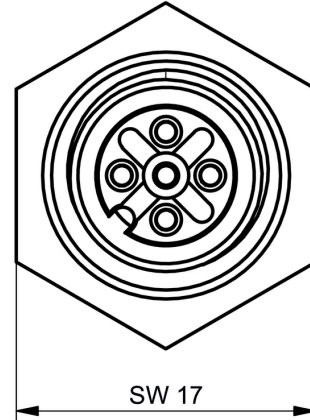

Pole scheme

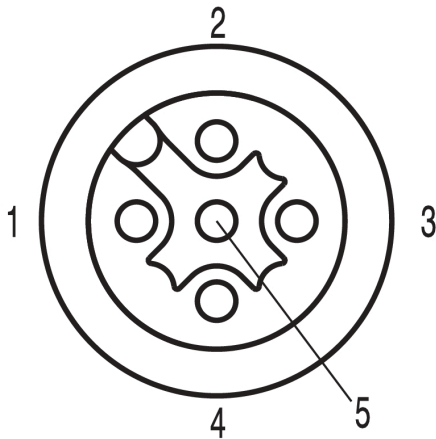

Pole scheme

