

**SAI-WDF 4P M12 K 230**

**Weidmüller Interface GmbH & Co. KG**  
Klingenbergstraße 26  
D-32758 Detmold  
Germany

[www.weidmueller.com](http://www.weidmueller.com)

**Similar to illustration**



**General ordering data**

Order No.	<a href="#">2485360000</a>
Type	SAI-WDF 4P M12 K 230
GTIN (EAN)	4050118496048
Qty.	1 pc(s).

**SAI-WDF 4P M12 K 230****Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

**Technical data****Dimensions and weights**

Net weight 23 g

**Technical data customisable plug-in connectors**

Coding	A	Contact surface	Gold-plated
Housing main material	CuZn	Number of poles	5
Protection degree	IP67	Rated current	4 A
Rated voltage	230 V	Temperature range of housing	-40 ... +85 °C
Type of connection	Screw connection		

**General technical specifications**

Coding	A	Connection thread	M12 socket, M12 plug
Contact material	CuZn	Contact surface	Gold-plated
Housing main material	CuZn	Number of poles	5
Protection degree	IP67	Rated current	4 A
Rated voltage	230 V	Temperature range of housing	-40 ... +85 °C
Type of connection	Screw connection		

**Classifications**

ETIM 6.0	EC002925	ETIM 7.0	EC002925
ETIM 8.0	EC002925	ECLASS 9.0	27-44-01-06
ECLASS 9.1	27-44-01-06	ECLASS 10.0	27-44-01-06
ECLASS 11.0	27-44-01-06	ECLASS 12.0	27-44-01-06

**Environmental Product Compliance**

REACH SVHC	Lead 7439-92-1
SCIP	22cbd99b-5f46-4c36-9938-bd61e241a9ab

**Approvals**

Approvals



ROHS Conform

**Downloads**

Engineering Data	<a href="#">CAD data – STEP</a>
Catalogues	<a href="#">Catalogues in PDF-format</a>
Brochures	<a href="#">FL FIELDWIRING EN</a>


**SAI-WDF 4P M12 K 230**

**Weidmüller Interface GmbH & Co. KG**  
 Klingenbergstraße 26  
 D-32758 Detmold  
 Germany


www.weidmueller.com

**Drawings**


**Dimensioned drawing**

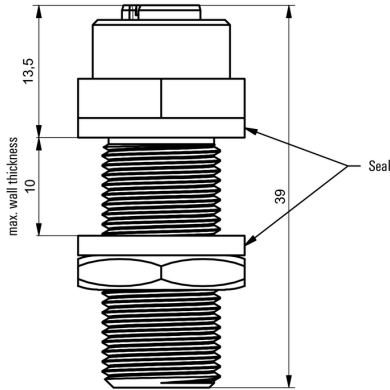

**Dimensioned drawing**

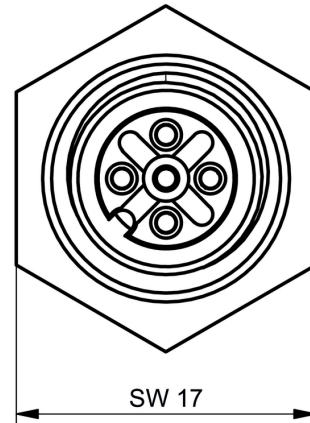

**Pole scheme**

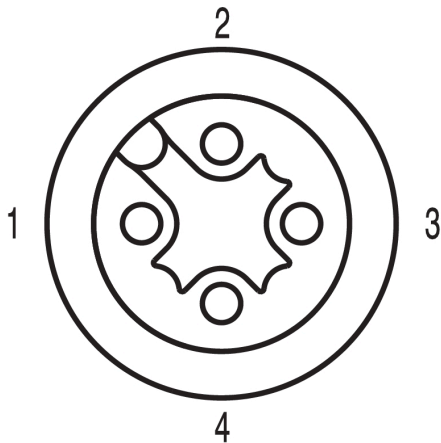

**Pole scheme**

