

**IE-BHD-VAPM****Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com



PushPull Power plug-in connector according to PROFINET specification

**General ordering data**

Version	Power connector, Device flange, PROFINET
Order No.	<a href="#">2493490000</a>
Type	IE-BHD-VAPM
GTIN (EAN)	4050118529104
Qty.	1 pc(s).

Creation date March 9, 2023 9:39:41 PM CET

Catalogue status 03.03.2023 / We reserve the right to make technical changes.

## IE-BHD-VAPM

Weidmüller Interface GmbH &amp; Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

## Technical data

## Dimensions and weights

Height	42 mm	Height (inches)	1.654 inch
Width	36.2 mm	Width (inches)	1.425 inch
Length	14.2 mm	Length (inches)	0.559 inch
Net weight	23 g		

## Temperatures

Operating temperature	-40 °C...80 °C	Operating temperature, min.	-40 °C
Operating temperature, max.	80 °C		

## General data

Colour	Silver grey	Housing main material	Zinc diecast, nickel-plated
Plugging cycles	500	Pollution severity	2
Protection degree	IP67	Sealing material	NBR
Shielding	unshielded	Type of interlock	Push Pull
Type of mounting	4 screws		

## General standards

Certificate No. (UR)	E92202
----------------------	--------

## Classifications

ETIM 6.0	EC001121	ETIM 7.0	EC001121
ETIM 8.0	EC001121	ECLASS 9.0	27-44-03-90
ECLASS 9.1	27-44-03-90	ECLASS 10.0	27-44-03-90
ECLASS 11.0	27-44-03-90	ECLASS 12.0	27-44-03-90

## Approvals

Approvals



UL File Number Search	UL Website
Certificate No. (UR)	E92202

## Downloads

Approval/Certificate/Document of Conformity	<a href="#">PROFINET Manufacturer's Declaration</a>
Engineering Data	<a href="#">CAD data – STEP</a>
Catalogues	<a href="#">Catalogues in PDF-format</a>


**IE-BHD-VAPM**

**Weidmüller Interface GmbH & Co. KG**  
Klingenbergstraße 26  
D-32758 Detmold  
Germany

[www.weidmueller.com](http://www.weidmueller.com)

**Drawings**

**Dimensioned drawing**

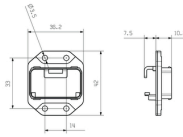

**Installation cut-out**

