

FF 67 55/230V BK

Weidmüller Interfaces GmbH & Co. KG

Postfach 3030

32760 Detmold

Tel. +49 5231 14-0

Fax. +49 5231 14-2083

info@weidmueller.com

www.weidmueller.com

Similar to illustration



The filter fans combine a safe and profitable cabinet cooling due to their low energy consumption by maximum air flow. The fluted filter mat of the IP 55 version extends the service life by up to 300% in comparison to conventional filter mats.

General ordering data

Version	Filter fan, IP55, black
Order No.	2556980000
Type	FF 67 55/230V BK
GTIN (EAN)	4050118567601
Qty.	1 Stück

FF 67 55/230V BK

Weidmüller Interfaces GmbH & Co. KG

Postfach 3030

32760 Detmold

Tel. +49 5231 14-0

Fax. +49 5231 14-2083

info@weidmueller.com

www.weidmueller.com

Technische Daten

Dimensions and weights

Depth	157 mm	Depth (inches)	6.181 inch
Height	320 mm	Height (inches)	12.598 inch
Width	320 mm	Width (inches)	12.598 inch
Net weight	3,700 g		

Temperatures

Operating temperature range	-40...55 °C
-----------------------------	-------------

General data

Colour	black		
Current consumption	Mains frequency	50 Hz	
	Current	0.62 A	
	Mains frequency	60 Hz	
	Current	0.86 A	
EMC version	No		
Fan type	Roof fan		
Filter class	G 4		
Fuse	6 A		
Height of installation cut-outs	291 mm		
MTBF	40,000 h		
Mounting depth	150 mm		
Mounting height	7 mm		
Noise emission	66 dB(A)		
Operating temperature range	-40...55 °C		
Power	Mains frequency	50 Hz	
	nominal	140 W	
	Mains frequency	60 Hz	
	nominal	197 W	
Protection class (UL)	Type 12		
Rated AC voltage	230 V		
Rated voltage	230 V AC \pm 10%		
Size	6		
Type of connection	Spring contact		
Type of mounting	Snap-on		
UL 94 flammability rating	V-0		
UV-resistant	Yes		
Volume flow with exhaust filter	Mains frequency	50 Hz	
	Volume flow	570 m ³ /h	
	Exhaust filter	IP55	
	Mains frequency	60 Hz	
	Volume flow	625 m ³ /h	
	Exhaust filter	IP55	
Volume flow, free-blowing	Mains frequency	50 Hz	
	Volume flow	925 m ³ /h	
	Mains frequency	60 Hz	
	Volume flow	950 m ³ /h	
Volume flow, free-blowing at 50 Hz	925 m ³ /h		
Volume flow, free-blowing at 60 Hz	950 m ³ /h		
Width of installation cut-outs	291 mm		
With filter	Yes		
With protective cover	Yes		

Erstellungs-Datum June 1, 2023 9:22:38 AM CEST

FF 67 55/230V BK**Weidmüller Interfaces GmbH & Co. KG**

Postfach 3030

32760 Detmold

Tel. +49 5231 14-0

Fax. +49 5231 14-2083

info@weidmueller.comwww.weidmueller.com**Technische Daten****Classifications**

ETIM 6.0	EC000320	ETIM 7.0	EC000320
ETIM 8.0	EC000320	ECLASS 9.1	27-18-07-16
ECLASS 10.0	27-18-07-16	ECLASS 11.0	27-18-07-16
ECLASS 12.0	27-18-07-16		

Approvals

Approvals



ROHS	Conform
UL File Number Search	UL Website
Certificate No. (cURus)	E252704

Downloads

Approval/Certificate/Document of Conformity	EU Declaration of Conformity
User Documentation	Installation- and operating instructions
Catalogues	Catalogues in PDF-format

FF 67 55/230V BK

Weidmüller Interfaces GmbH & Co. KG

Postfach 3030

32760 Detmold


Tel. +49 5231 14-0

Fax. +49 5231 14-2083

info@weidmueller.com

Zeichnungen

Graph

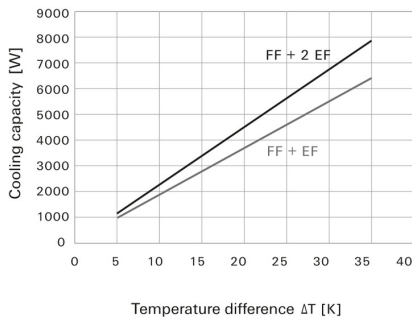

Graph

