

FF-SL 67 55/230V GY**Weidmüller Interfaces GmbH & Co. KG**

Postfach 3030

32760 Detmold

Tel. +49 5231 14-0

Fax. +49 5231 14-2083

info@weidmueller.com

www.weidmueller.com



Optimised design for compact cabinets where space is a premium. Suitable for indoor and outdoor use due to IP55 protection and the use of UV-resistant plastic.

General ordering data

Version	Filter fan, IP55, grey
Order No.	2557030000
Type	FF-SL 67 55/230V GY
GTIN (EAN)	4050118567663
Qty.	1 Stück

FF-SL 67 55/230V GY

Weidmüller Interfaces GmbH & Co. KG

Postfach 3030

32760 Detmold

Tel. +49 5231 14-0

Fax. +49 5231 14-2083

info@weidmueller.com

www.weidmueller.com

Technische Daten

Dimensions and weights

Depth	131 mm	Depth (inches)	5.157 inch
Height	320 mm	Height (inches)	12.598 inch
Width	320 mm	Width (inches)	12.598 inch
Net weight	4,050 g		

Temperatures

Operating temperature range	-40...55 °C
-----------------------------	-------------

General data

Colour	grey		
Current consumption	Mains frequency	50 Hz	
	Current	0.51 A	
	Mains frequency	60 Hz	
	Current	0.7 A	
EMC version	No		
Fan type	Shelf		
Filter class	G 4		
Fuse	6 A		
Height of installation cut-outs	291 mm		
MTBF	40,000 h		
Mounting depth	124 mm		
Mounting height	7 mm		
Noise emission	66 dB(A)		
Operating temperature range	-40...55 °C		
Power	Mains frequency	50 Hz	
	nominal	115 W	
	Mains frequency	60 Hz	
	nominal	165 W	
Protection class (UL)	Type 12		
Rated AC voltage	230 V		
Rated voltage	230 V AC \pm 10%		
Size	6		
Type of connection	Terminal strip		
Type of mounting	Snap-on		
UL 94 flammability rating	V-0		
UV-resistant	Yes		
Volume flow with exhaust filter	Mains frequency	50 Hz	
	Volume flow	530 m ³ /h	
	Exhaust filter	IP55	
	Mains frequency	60 Hz	
	Volume flow	580 m ³ /h	
	Exhaust filter	IP55	
Volume flow, free-blowing	Mains frequency	50 Hz	
	Volume flow	705 m ³ /h	
	Mains frequency	60 Hz	
	Volume flow	725 m ³ /h	
Volume flow, free-blowing at 50 Hz	705 m ³ /h		
Volume flow, free-blowing at 60 Hz	725 m ³ /h		
Width of installation cut-outs	291 mm		
With filter	Yes		

Erstellungs-Datum June 1, 2023 9:23:05 AM CEST

Katalogstand 26.05.2023 / Technische Änderungen vorbehalten

FF-SL 67 55/230V GY

Weidmüller Interfaces GmbH & Co. KG

Postfach 3030

32760 Detmold

Tel. +49 5231 14-0

Fax. +49 5231 14-2083

info@weidmueller.com

www.weidmueller.com

Technische Daten

Classifications

ETIM 6.0	EC000320	ETIM 7.0	EC000320
ETIM 8.0	EC000320	ECLASS 9.1	27-18-07-16
ECLASS 10.0	27-18-07-16	ECLASS 11.0	27-18-07-16
ECLASS 12.0	27-18-07-16		

Approvals

Approvals



ROHS	Conform
UL File Number Search	UL Website
Certificate No. (cURus)	E252704

Downloads

Approval/Certificate/Document of Conformity	EU Declaration of Conformity
User Documentation	Installation- and operating instructions
Catalogues	Catalogues in PDF-format

FF-SL 67 55/230V GY

Weidmüller Interfaces GmbH & Co. KG

Postfach 3030

32760 Detmold


Tel. +49 5231 14-0

Fax. +49 5231 14-2083

info@weidmueller.com

Zeichnungen

Graph

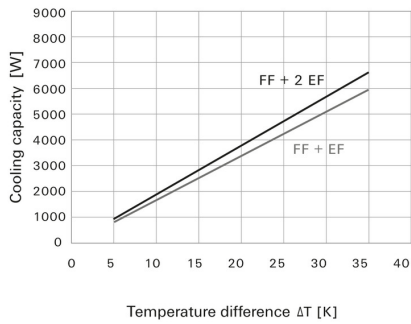

Graph

