

RH-TCO 75W 110-250V**Weidmüller Interfaces GmbH & Co. KG**

Postfach 3030


32760 Detmold

Tel. +49 5231 14-0

Fax. +49 5231 14-2083

info@weidmueller.com

www.weidmueller.com

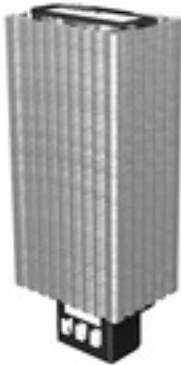

The formation of condensation is one of the largest dangers for electrical cabinets. With our cabinet heaters prevention of condensation in the cabinet is guaranteed.

General ordering data

Version	Radiant heating panel, 110 V, 250 V, IP20, silver
Order No.	2557960000
Type	RH-TCO 75W 110-250V
GTIN (EAN)	4050118568608
Qty.	1 Stück

RH-TCO 75W 110-250V

Weidmüller Interfaces GmbH & Co. KG

Postfach 3030

32760 Detmold

Tel. +49 5231 14-0

Fax. +49 5231 14-2083

info@weidmueller.com

www.weidmueller.com

Technische Daten

Dimensions and weights

Depth	50 mm	Depth (inches)	1.969 inch
Height	175 mm	Height (inches)	6.89 inch
Width	70 mm	Width (inches)	2.756 inch
Net weight	510 g		

Temperatures

Operating temperature range	-40...70 °C
-----------------------------	-------------

General data

Continuous heat output at 10°C	75 W	Inrush current	max. 4.5 A
Operating temperature range	-40...70 °C	Protection degree	IP20
Supply voltage, max.	250 V	Supply voltage, min.	110 V
Type of connection	Spring contact	Type of mounting	Rail
With room thermostat	No		

Classifications

ETIM 6.0	EC000737	ETIM 7.0	EC000737
ETIM 8.0	EC000737	ECLASS 9.1	27-18-07-10
ECLASS 10.0	27-18-07-10	ECLASS 11.0	27-18-07-10
ECLASS 12.0	27-18-07-10		

Approvals

Approvals



ROHS	Conform
UL File Number Search	UL Website
Certificate No. (cURus)	E497839

Downloads

Approval/Certificate/Document of Conformity	EU Declaration of Conformity
Engineering Data	CAD data – STEP
Catalogues	Catalogues in PDF-format