

IE-CDR-V14MRJ/VAPM-C**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com



FreeCon Active PROFINET repeater for PushPull Var. 14
plug-in connectors according to IEC 61076-3-117 and
PushPull Power according to the PROFINET specification

General ordering data

Version	PROFINET copper repeater, FreeCon, IP65
Order No.	2581810000
Type	IE-CDR-V14MRJ/VAPM-C
GTIN (EAN)	4050118590869
Qty.	1 Stück

Erstellungs-Datum May 25, 2023 3:05:22 PM CEST

Katalogstand 12.05.2023 / Technische Änderungen vorbehalten

IE-CDR-V14MRJ/VAPM-C

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 26
 D-32758 Detmold
 Germany

www.weidmueller.com

Technische Daten

Dimensions and weights

Depth	53 mm	Depth (inches)	2.087 inch
Width	100 mm	Width (inches)	3.937 inch
Length	130.4 mm	Length (inches)	5.134 inch
Net weight	661.8 g		

Temperatures

Operating temperature	-20 °C...55 °C	Operating temperature, min.	-20 °C
Operating temperature, max.	55 °C		

General data

Data interface	PROFINET PushPull RJ45 (V14)	Housing main material	Aluminium profile, Zinc die cast, electroplated lid
Power interface	PROFINET PushPull Power	Protection degree	IP65
Type of mounting	4 screws	UL 94 flammability rating	V-0

Electrical properties

Baud rate	100 MBit/s	Current consumption	100 mA
LED indicator	ACT1: activity Port 1, ACT2: activity Port2, SF: general error, BF: bus error, US1: voltage 1 (electronics), US2: voltage 2, LNK1: port active, LNK2: port active	Operating voltage	24 V DC
Operational voltage range	18...30 V DC	Protocol	PROFINET IRT

General standards

Certificate no. (cULus)	E141197	Connector standard	IEC 61076-3-117 Var. 14
Network standard	IEC 61158, IEC 61784	PROFINET specification	Conformance Class C acc. V2.3

Classifications

ETIM 6.0	EC000732	ETIM 7.0	EC000732
ETIM 8.0	EC000732	ECLASS 9.0	19-17-02-06
ECLASS 9.1	19-17-01-25	ECLASS 10.0	19-17-02-06
ECLASS 11.0	19-17-02-06	ECLASS 12.0	19-17-02-06

Environmental Product Compliance

REACH SVHC	Lead 7439-92-1
SCIP	67cf1078-beca-4687-860b-dc475a6ec24a

Approvals

Approvals



UL File Number Search	UL Website
Certificate no. (cULus)	E141197

Erstellungs-Datum May 25, 2023 3:05:22 PM CEST

Katalogstand 12.05.2023 / Technische Änderungen vorbehalten

IE-CDR-V14MRJ/VAPM-C

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 26
D-32758 Detmold
Germany

www.weidmueller.com

Technische Daten

Downloads

Approval/Certificate/Document of Conformity	Certificate
Engineering Data	CAD data – STEP
Product Change Notification	FreeCon Active Repeater FreeCon Active Repeater
Software	Runtime Software – CFG configurator - Weidmueller FreeCon Device description – GSDML-V2.35 COP Firmware – Firmware ABCC COP
User Documentation	Handbuch_FreeCon_Active_V1_0_de Handbuch_FreeCon_Active_V1_0_en
Catalogues	Catalogues in PDF-format


IE-CDR-V14MRJ/VAPM-C

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 26
 D-32758 Detmold
 Germany


www.weidmueller.com

Zeichnungen

Dimensioned drawing

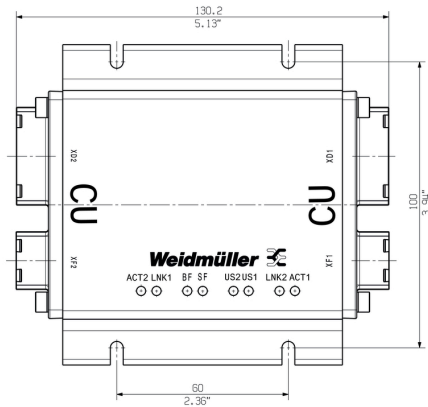

Dimensioned drawing

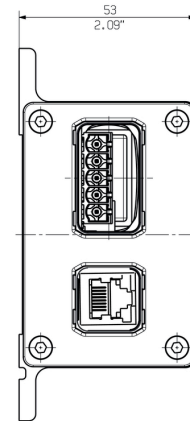

Wiring diagram

