

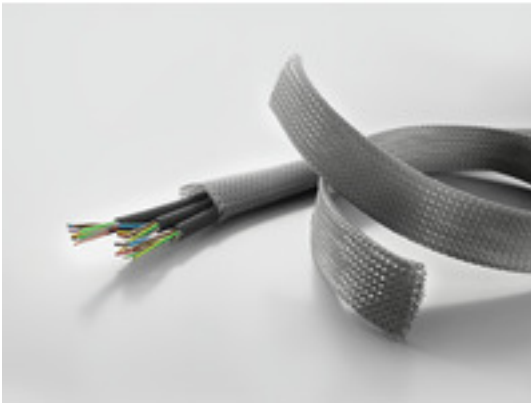
CBC-FB 5-10/200**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Similar to illustration

Spiral and webbing hoses are particularly suitable for the construction of space-saving cable routing systems in switch gears and control cabinets. They are used for guiding, protecting and bundling cables and wires - for example, in the transition between the enclosure interior and the door.

General ordering data

Version	Fabric of protective cable hose
Order No.	2588950000
Type	CBC-FB 5-10/200
GTIN (EAN)	4050118602487
Qty.	200 m

CBC-FB 5-10/200

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 26
 D-32758 Detmold
 Germany

www.weidmueller.com

Technische Daten

Dimensions and weights

Length	100,000 mm	Length (inches)	3,937 inch
Diameter	10 mm	Net weight	5.42 g

Temperatures

Operating temperature range	-50...150 °C	Operating temperature, min.	-50 °C
Operating temperature, max.	150 °C		

General information

Bundle diameter, max.	10 mm	Bundle diameter, min.	5 mm
Colour	Silver grey	Diameter	10 mm
Material	Polyethylene terephthalate PET	Nominal diameter	5 mm
Operating temperature range	-50...150 °C	UL 94 flammability rating	HB
Usable cross-section	78 mm ²		

Classifications

ETIM 6.0	EC002604	ETIM 7.0	EC002604
ETIM 8.0	EC002604	ECLASS 9.1	27-43-03-02
ECLASS 10.0	27-43-03-02	ECLASS 11.0	27-43-03-02
ECLASS 12.0	27-43-03-02		

Approvals

ROHS	Conform
------	---------

Downloads

Catalogues	Catalogues in PDF-format
------------	------------------------------------------