

**IE-CCM-5P-10.5****Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com



The Weidmüller connecting module is helpful whenever you have to repair or want to extend a broken installation cable without cable reserve in confined spaces.

**General ordering data**

Version	Connecting module, IP68 (50 m / 24 h)
Order No.	<a href="#">2685580000</a>
Type	IE-CCM-5P-10.5
GTIN (EAN)	4050118695335
Qty.	1 Stück

Erstellungs-Datum June 5, 2023 10:19:40 AM CEST

Katalogstand 26.05.2023 / Technische Änderungen vorbehalten

## IE-CCM-5P-10.5

**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

## Technische Daten

### Dimensions and weights

Net weight 35 g

### Temperatures

Operating temperature	-40 °C...105 °C	Operating temperature, min.	-40 °C
Operating temperature, max.	105 °C		

### General Info

Number of poles	5	Description of article	Connecting module
Colour	black	Housing main material	Nylon, Glass fibre, UL recongnized
Contact material	Brass, nickel plated	Contact surface	Nickel-plated CuZn
Conductor connection cross-section, solid (AWG)	AWG 18...AWG 14	Wire cross-section, solid, min. (AWG)	AWG 18
Wire cross-section, solid, max. (AWG)	AWG 14	Wire connection cross section, finely stranded, min.	0.75 mm <sup>2</sup>
Wire connection cross section, finely stranded, max.	2.5 mm <sup>2</sup>	Conductor connection cross-section, flexible	0.75...2.5 mm <sup>2</sup>
Sheath diameter, min.	8.5 mm	Sheath diameter, max.	10.5 mm
Contact holder materials	Nylon + Glass fibre, UL Recongnized	Protection degree	IP68 (50 m / 24 h)
Tightening torque connecting module, min.	0.196 Nm	Tightening torque connecting module, max.	0.44 Nm
Tightening torque gland nut, min.	0.78 Nm	Tightening torque gland nut, max.	0.98 Nm
Tightening torque gland pipe, min.	0.78 Nm	Tightening torque gland pipe, max.	0.98 Nm

### Electrical properties

Rated current	8 A	Rated voltage	600 V
---------------	-----	---------------	-------

### General standards

Certificate No. (cURus) E486077

### Classifications

ETIM 6.0	EC001059	ETIM 7.0	EC001059
ETIM 8.0	EC001059	ECLASS 9.0	27-40-02-12
ECLASS 9.1	27-40-02-12	ECLASS 10.0	27-40-02-12
ECLASS 11.0	27-40-02-12	ECLASS 12.0	27-40-02-12

### Approvals

Approvals



ROHS	Conform
UL File Number Search	UL Website
Certificate No. (cURus)	E486077

## IE-CCM-5P-10.5

**Weidmüller Interface GmbH & Co. KG**  
Klingenbergstraße 26  
D-32758 Detmold  
Germany

[www.weidmueller.com](http://www.weidmueller.com)

## Technische Daten

### Downloads

Engineering Data	<a href="#">CAD data – STEP</a>
User Documentation	<a href="#">MAN IE GUIDE DE</a> <a href="#">MAN IE GUIDE EN</a>
Catalogues	<a href="#">Catalogues in PDF-format</a>


## IE-CCM-5P-10.5

**Weidmüller Interface GmbH & Co. KG**  
Klingenbergstraße 26  
D-32758 Detmold  
Germany

[www.weidmueller.com](http://www.weidmueller.com)

# Zeichnungen

### Dimensioned drawing

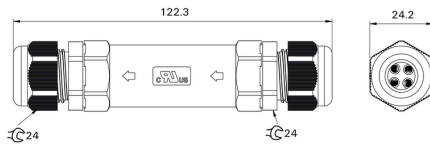

### Installation cut-out

