

## RIM 2 6/24VDC

**Weidmüller Interface GmbH & Co. KG**  
 Klingenbergstraße 26  
 D-32758 Detmold  
 Germany

www.weidmueller.com

### Product image



### General ordering data

Version	RIDERSERIES RCL, LED module with freewheel diode, Rated control voltage: 6...24 V DC, Plug-in connection
Order No.	<a href="#">8690950000</a>
Type	RIM 2 6/24VDC
GTIN (EAN)	4032248361632
Qty.	10 Stück

Erstellungs-Datum May 25, 2023 12:11:19 PM CEST

Katalogstand 12.05.2023 / Technische Änderungen vorbehalten

## RIM 2 6/24VDC

**Weidmüller Interface GmbH & Co. KG**  
 Klingenbergstraße 26  
 D-32758 Detmold  
 Germany

www.weidmueller.com

## Technische Daten

### Dimensions and weights

Depth	34.5 mm	Depth (inches)	1.358 inch
Height	9 mm	Height (inches)	0.354 inch
Width	12.5 mm	Width (inches)	0.492 inch
Net weight	2.788 g		

### Temperatures

Storage temperature	-40 °C...70 °C	Operating temperature	-40 °C...70 °C
Operating temperature, min.	-40 °C	Operating temperature, max.	70 °C
Humidity	40 °C / 93 % rel. humidity, no condensation		

### Control side

Rated control voltage	6...24 V DC	Status indicator	red LED
Protective circuit	Free-wheeling diode		

### General data

Colour	black
--------	-------

### Connection data

Wire connection method	Plug-in connection
------------------------	--------------------

### Classifications

ETIM 6.0	EC002586	ETIM 7.0	EC002586
ETIM 8.0	EC002586	ECLASS 9.1	27-37-10-10
ECLASS 10.0	27-37-10-10	ECLASS 11.0	27-37-16-92
ECLASS 12.0	27-37-16-92		

### Approvals

Approvals	
ROHS	Conform

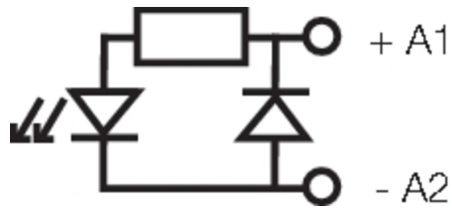
### Downloads

Engineering Data	<a href="#">CAD data – STEP</a>
Engineering Data	<a href="#">WSCAD, EPLAN</a>
Catalogues	<a href="#">Catalogues in PDF-format</a>

**RIM 2 6/24VDC**

**Weidmüller Interface GmbH & Co. KG**  
Klingenbergstraße 26  
D-32758 Detmold  
Germany

[www.weidmueller.com](http://www.weidmueller.com)

**Zeichnungen****Wiring diagram****Dimensional drawing**