


H2,5/19D ZH BL SV

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 26
D-32758 Detmold
Germany

www.weidmueller.com

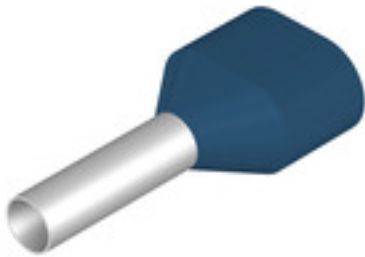

- in multi-pack bag (5 x 100 pcs.)
- DIN colour code
- other colour code

General ordering data

Version	Wire-end ferrule, Twin wire-end ferrule, 13 mm, 10 mm, blue
Order No.	9004430000
Type	H2,5/19D ZH BL SV
GTIN (EAN)	4008 190099367
Qty.	250 pc(s).
Packaging	Multipack bag

Creation date March 2, 2023 11:07:51 AM CET

Catalogue status 18.02.2023 / We reserve the right to make technical changes.

H2,5/19D ZH BL SV**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Technical data**Dimensions and weights**

Net weight 0.328 g

Technical data

Description of article Twin wire end ferrule, blue Version Twin wire-end ferrule

Wire-end ferrules

Collar height (A) 8 mm Collar width (B) 4.5 mm

Colour code DIN Conductor cross-section 2.5 mm²

Contact surface diameter (D1) 2.8 mm Contact surface length (L2) 10 mm

L1 in mm 19 mm Metal sleeve thickness (S1) 0.15 mm

Plastic collar thickness (S2) 0.4 mm Stripping length 13 mm

Wire connection cross section AWG, max. AWG 14

Classifications

ETIM 6.0 EC000005 ETIM 7.0 EC000005

ETIM 8.0 EC000005 ECLASS 9.0 27-40-02-01

ECLASS 9.1 27-40-02-01 ECLASS 10.0 27-40-02-01

ECLASS 11.0 27-40-02-01 ECLASS 12.0 27-40-02-01

Approvals

Approvals



ROHS Conform

UL File Number Search UL Website

Certificate no. (cULus) E499744

DownloadsEngineering Data [CAD data – STEP](#)Engineering Data [WSCAD, Zuken E3.S](#)User Documentation [Technical information - EN](#)[Technical information - DE](#)Catalogues [Catalogues in PDF-format](#)

Brochures

H2,5/19D ZH BL SV

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 26
D-32758 Detmold
Germany

www.weidmueller.com

Drawing

