

**H10,0/24 ZH EB SV****Weidmüller Interfaces GmbH & Co. KG**

Postfach 3030


32760 Detmold

Tel. +49 5231 14-0

Fax. +49 5231 14-2083

info@weidmueller.com

www.weidmueller.com

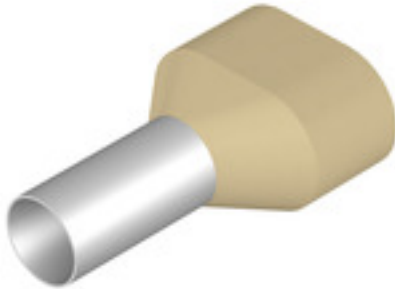

- in multipack bag (5 x 100 pcs.)
- Weidmüller colour code
- DIN colour code
- other colour code

**General ordering data**

Version	Wire-end ferrule, Twin wire-end ferrule, 17 mm, 12 mm, Ivory
Order No.	<a href="#">9004940000</a>
Type	H10,0/24 ZH EB SV
GTIN (EAN)	4008190482718
Qty.	100 pc(s).
Packaging	Multipack bag

**H10,0/24 ZH EB SV**

Weidmüller Interfaces GmbH &amp; Co. KG

Postfach 3030

32760 Detmold

Tel. +49 5231 14-0

Fax. +49 5231 14-2083

info@weidmueller.com

www.weidmueller.com

**Technical data****Dimensions and weights**

Net weight 0.18 g

**Technical data**

Description of article Twin wire end ferrule, ivory Version Twin wire-end ferrule

**Wire-end ferrules**

Collar height (A)	13.4 mm	Collar width (B)	7.6 mm
Colour code	Weidmüller	Conductor cross-section	10 mm <sup>2</sup>
Contact surface diameter (D1)	5.8 mm	Contact surface length (L2)	12 mm
L1 in mm	24 mm	Metal sleeve thickness (S1)	0.2 mm
Plastic collar thickness (S2)	0.5 mm	Stripping length	17 mm
Wire connection cross section AWG, max.	AWG 8		

**Classifications**

ETIM 6.0	EC000005	ETIM 7.0	EC000005
ETIM 8.0	EC000005	ECLASS 9.0	27-40-02-01
ECLASS 9.1	27-40-02-01	ECLASS 10.0	27-40-02-01
ECLASS 11.0	27-40-02-01	ECLASS 12.0	27-40-02-01

**Approvals**

Approvals



ROHS	Conform
UL File Number Search	UL Website
Certificate no. (cULus)	E499744

**Downloads**

Engineering Data	<a href="#">CAD data – STEP</a>
Engineering Data	<a href="#">WSCAD, Zuken E3.S</a>
User Documentation	<a href="#">Technical information - EN</a> <a href="#">Technical information - DE</a>
Catalogues	<a href="#">Catalogues in PDF-format</a>
Brochures	

**H10,0/24 ZH EB SV**

**Weidmüller Interfaces GmbH & Co. KG**

Postfach 3030

32760 Detmold

Tel. +49 5231 14-0

Fax. +49 5231 14-2083

info@weidmueller.com

**Drawings**

**Drawing**

