


H10,0/26T ZH BR SV**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

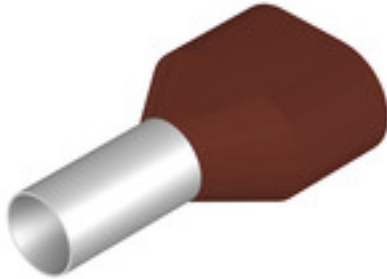

- in multipack bag (5 x 100 pcs.)
- Weidmüller colour code
- DIN colour code
- other colour code

General ordering data

Version	Wire-end ferrule, Twin wire-end ferrule, 17 mm, 12 mm, brown
Order No.	9005170000
Type	H10,0/26T ZH BR SV
GTIN (EAN)	4008190482756
Qty.	100 pc(s).
Packaging	Multipack bag

Creation date February 28, 2023 8:22:28 AM CET

Catalogue status 18.02.2023 / We reserve the right to make technical changes.

H10,0/26T ZH BR SV

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 26
 D-32758 Detmold
 Germany

www.weidmueller.com

Technical data**Dimensions and weights**

Net weight 0.89 g

Technical data

Description of article	Twin wire end ferrule, brown	Version	Twin wire-end ferrule
------------------------	------------------------------	---------	-----------------------

Wire-end ferrules

Collar height (A)	13.4 mm	Collar width (B)	7.6 mm
Colour code	Telemecanique	Conductor cross-section	10 mm ²
Contact surface diameter (D1)	5.8 mm	Contact surface length (L2)	12 mm
L1 in mm	26 mm	Metal sleeve thickness (S1)	0.2 mm
Plastic collar thickness (S2)	0.5 mm	Stripping length	17 mm
Wire connection cross section AWG, max.	AWG 8		

Classifications

ETIM 6.0	EC000005	ETIM 7.0	EC000005
ETIM 8.0	EC000005	ECLASS 9.0	27-40-02-01
ECLASS 9.1	27-40-02-01	ECLASS 10.0	27-40-02-01
ECLASS 11.0	27-40-02-01	ECLASS 12.0	27-40-02-01

Approvals

Approvals



ROHS	Conform
UL File Number Search	UL Website
Certificate no. (cULus)	E499744

Downloads

Engineering Data	CAD data – STEP
Engineering Data	WSCAD, Zuken E3.S
User Documentation	Technical information - EN Technical information - DE
Catalogues	Catalogues in PDF-format
Brochures	

Data sheet

H10,0/26T ZH BR SV

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 26
D-32758 Detmold
Germany

www.weidmueller.com

Drawings

Drawing

