


H10,0/24S ZH EB**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

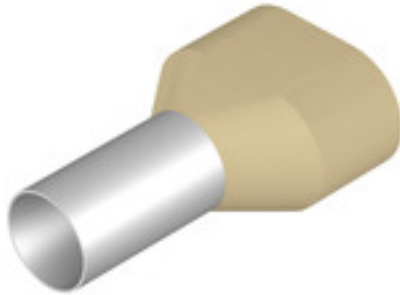

- Polypropylene conical cable entry funnel
- Heat-resistant up to 105°C

For conductors from 0.5 – 10.0 mm² (AWG 20-7)

Material: E-Cu, tin galvanised

Dimensional tolerance acc. to DIN 46228 sect. 4

General ordering data

Version	Wire-end ferrule, Twin wire-end ferrule, 17 mm, 12 mm, Ivory
Order No.	9018860000
Type	H10,0/24S ZH EB
GTIN (EAN)	4032248105816
Qty.	100 pc(s).
Packaging	loose

Creation date February 23, 2023 4:19:15 PM CET

Catalogue status 18.02.2023 / We reserve the right to make technical changes.

H10,0/24S ZH EB**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Technical data**Dimensions and weights**

Net weight 0.84 g

Technical data

Description of article Twin wire end ferrule, ivory Version Twin wire-end ferrule

Wire-end ferrules

Collar height (A) 13.4 mm Collar width (B) 7.6 mm

Colour code Weidmüller Conductor cross-section 10 mm²

Contact surface diameter (D1) 6.5 mm Contact surface length (L2) 12 mm

L1 in mm 24 mm Metal sleeve thickness (S1) 0.2 mm

Plastic collar thickness (S2) 0.5 mm Stripping length 17 mm

Wire connection cross section AWG, max. AWG 8

Classifications

ETIM 6.0 EC000005 ETIM 7.0 EC000005

ETIM 8.0 EC000005 ECLASS 9.0 27-40-02-01

ECLASS 9.1 27-40-02-01 ECLASS 10.0 27-40-02-01

ECLASS 11.0 27-40-02-01 ECLASS 12.0 27-40-02-01

Approvals

Approvals



ROHS Conform

DownloadsEngineering Data [CAD data – STEP](#)Engineering Data [WSCAD](#)User Documentation [Technical information - EN](#)[Technical information - DE](#)Catalogues [Catalogues in PDF-format](#)

Brochures

Data sheet

H10,0/24S ZH EB

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 26
D-32758 Detmold
Germany

www.weidmueller.com

Drawings

Drawing

