


H6,0/20D GE

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 26
D-32758 Detmold
Germany

www.weidmueller.com

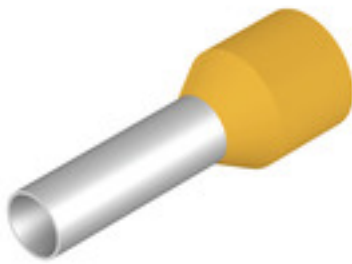

- supplied loose in poly-bag
- Weidmüller colour code
- DIN colour code
- other colour code

General ordering data

Version	Wire-end ferrule, Standard, 14 mm, 12 mm, yellow
Order No.	9019220000
Type	H6,0/20D GE
GTIN (EAN)	4008190151607
Qty.	100 pc(s).
Packaging	loose

Creation date February 23, 2023 4:19:43 PM CET

Catalogue status 18.02.2023 / We reserve the right to make technical changes.

H6,0/20D GE

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 26
 D-32758 Detmold
 Germany

www.weidmueller.com

Technical data

Dimensions and weights

Net weight 0.36 g

Technical data

Description of article	Wire end ferrule with plastic collar, yellow	Version	Standard
------------------------	--	---------	----------

Wire-end ferrules

Collar diameter (D2)	6.3 mm	Colour code	DIN
Conductor cross-section	6 mm ²	Contact surface diameter (D1)	3.5 mm
Contact surface length (L2)	12 mm	L1 in mm	20 mm
Metal sleeve thickness (S1)	0.2 mm	Military designation	T 20A 022 A
Plastic collar thickness (S2)	0.3 mm	Stripping length	14 mm
Wire connection cross section AWG, max.	AWG 10		

Classifications

ETIM 6.0	EC000005	ETIM 7.0	EC000005
ETIM 8.0	EC000005	ECLASS 9.0	27-40-02-01
ECLASS 9.1	27-40-02-01	ECLASS 10.0	27-40-02-01
ECLASS 11.0	27-40-02-01	ECLASS 12.0	27-40-02-01

Approvals

Approvals



ROHS	Conform
UL File Number Search	UL Website
Certificate no. (cULus)	E499744

Downloads

Engineering Data	CAD data – STEP
Engineering Data	WSCAD, Zuken E3.S
User Documentation	Technical information - EN Technical information - DE
Catalogues	Catalogues in PDF-format
Brochures	

Data sheet

H6,0/20D GE

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 26
D-32758 Detmold
Germany

www.weidmueller.com

Drawings

Drawing

