

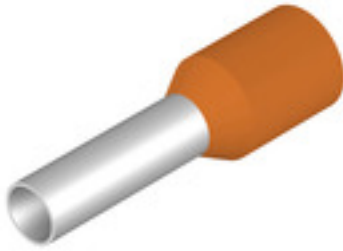
H4,0/15TS OR**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Similar to illustration

- Polypropylene conical cable entry funnel
- Heat-resistant up to 105°C

For conductors from 0.5 – 10.0 mm² (AWG 20-7)

Material: E-Cu, tin galvanised

Dimensional tolerance acc. to DIN 46228 sect. 4

General ordering data

Version	Wire-end ferrule, Standard, 10 mm, 8 mm, orange
Order No.	9036230000
Type	H4,0/15TS OR
GTIN (EAN)	4032248068029
Qty.	500 pc(s).
Packaging	loose

Creation date March 3, 2023 11:07:36 AM CET

Catalogue status 18.02.2023 / We reserve the right to make technical changes.

H4,0/15TS OR

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 26
 D-32758 Detmold
 Germany

www.weidmueller.com

Technical data**Dimensions and weights**

Net weight	0.224 g
------------	---------

Technical data

Description of article	Wire end ferrule with plastic collar, special size, orange	Version	Standard
------------------------	--	---------	----------

Wire-end ferrules

Collar diameter (D2)	4.8 mm	Conductor cross-section	4 mm ²
Contact surface diameter (D1)	2.8 mm	Contact surface length (L2)	8 mm
L1 in mm	15 mm	Metal sleeve thickness (S1)	0.2 mm
Military designation	T 20A 023 A	Plastic collar thickness (S2)	0.3 mm
Stripping length	10 mm	Wire connection cross section AWG, max.	AWG 12

Classifications

ETIM 6.0	EC000005	ETIM 7.0	EC000005
ETIM 8.0	EC000005	ECLASS 9.0	27-40-02-01
ECLASS 9.1	27-40-02-01	ECLASS 10.0	27-40-02-01
ECLASS 11.0	27-40-02-01	ECLASS 12.0	27-40-02-01

Approvals

Approvals



ROHS	Conform
UL File Number Search	UL Website
Certificate No. (UR)	E354986

Downloads

Engineering Data	WSCAD
User Documentation	Technical information - EN Technical information - DE
Catalogues	Catalogues in PDF-format

Data sheet

H4,0/15TS OR

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 26
D-32758 Detmold
Germany

www.weidmueller.com

Drawings

Drawing

