


H10,0/22S EB**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

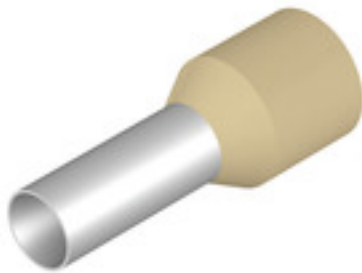

- Polypropylene conical cable entry funnel
- Heat-resistant up to 105°C

For conductors from 0.5 – 10.0 mm² (AWG 20-7)

Material: E-Cu, tin galvanised

Dimensional tolerance acc. to DIN 46228 sect. 4

General ordering data

Version	Wire-end ferrule, Standard, 15 mm, 12 mm, Ivory
Order No.	9203620000
Type	H10,0/22S EB
GTIN (EAN)	403224856506 1
Qty.	100 pc(s).
Packaging	loose

Creation date February 20, 2023 3:07:04 PM CET

Catalogue status 03.02.2023 / We reserve the right to make technical changes.

H10,0/22S EB**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Technical data**Dimensions and weights**

Net weight 0.51 g

Technical data

Description of article	Wire end ferrule with plastic collar, special size, ivory	Version	Standard
------------------------	---	---------	----------

Wire-end ferrules

Collar diameter (D2)	7.1 mm	Colour code	Miscellaneous
Conductor cross-section	10 mm ²	Contact surface diameter (D1)	4.6 mm
Contact surface length (L2)	12 mm	L1 in mm	22 mm
Metal sleeve thickness (S1)	0.2 mm	Plastic collar thickness (S2)	0.6 mm
Stripping length	15 mm	Wire connection cross section AWG, max.	AWG 8

Classifications

ETIM 6.0	EC000005	ETIM 7.0	EC000005
ETIM 8.0	EC000005	ECLASS 9.0	27-40-02-01
ECLASS 9.1	27-40-02-01	ECLASS 10.0	27-40-02-01
ECLASS 11.0	27-40-02-01	ECLASS 12.0	27-40-02-01

Approvals

Approvals



ROHS Conform

Downloads

Engineering Data	WSCAD
User Documentation	Technical information - EN Technical information - DE
Catalogues	Catalogues in PDF-format
Brochures	

Data sheet

H10,0/22S EB

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 26
D-32758 Detmold
Germany

www.weidmueller.com

Drawings

Drawing

