


Pneumatically Driven Linear Guides

MPPT16 Series



Pneumatically Driven Linear Guides - L-Shaped

MPPU10, MPPU12 Series

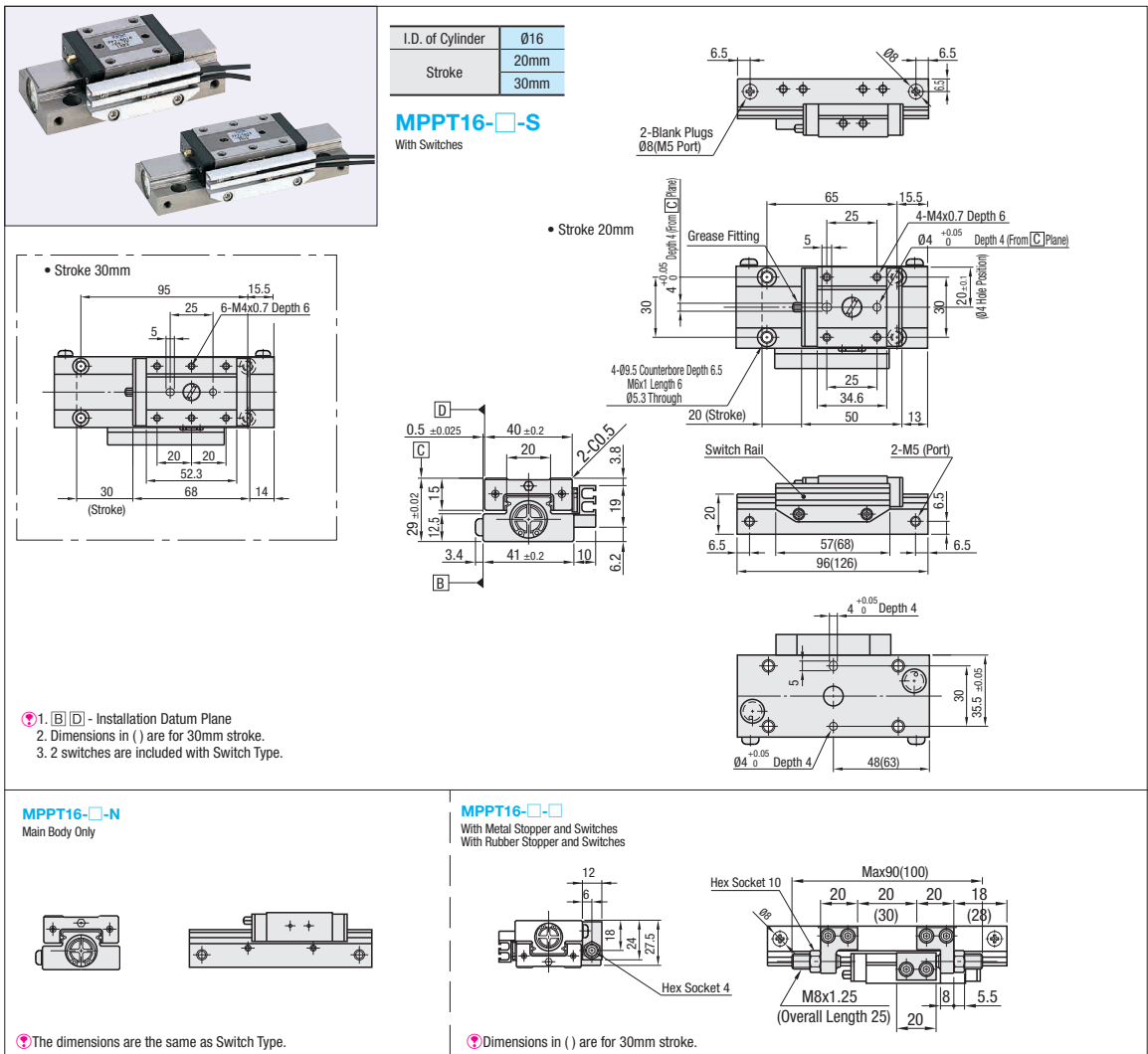

Part Number	Stroke	Specification Selection	Stroke Adjustable Amount	Max. Load Mass	Main Body Mass	Unit Price (per Each Spec.) 1 ~ 3 pc(s).
MPPT16	20	N (Main Body Only)	-	2.0kg	445g	-
	30	J (Main Body with Switch Rail)			610g	-
	20	S (Contacting Switch)			490g	-
	30	MS (Non-contact Switch)			660g	-
	20	MT (3 Wire Non-contact Switch)	10mm for Both Sides	1.0kg	590g	-
	30	RS (Metal Stopper, Contacting Switch)			760g	-
	20	RMS (Metal Stopper, Non-contact Switch)			590g	-
	30	RMT (Metal Stopper, 3 Wire Non-contact Switch)			760g	-
	20	TS (Rubber Stopper, Contacting Switch)	-	2.0kg	590g	-
	30	TMS (Rubber Stopper, Non-contact Switch)			760g	-
	20	TMT (Rubber Stopper, 3 Wire Non-contact Switch)			760g	-
	30	TMT (Rubber Stopper, 3 Wire Non-contact Switch)			760g	-

For orders larger than indicated quantity, please request a quotation.

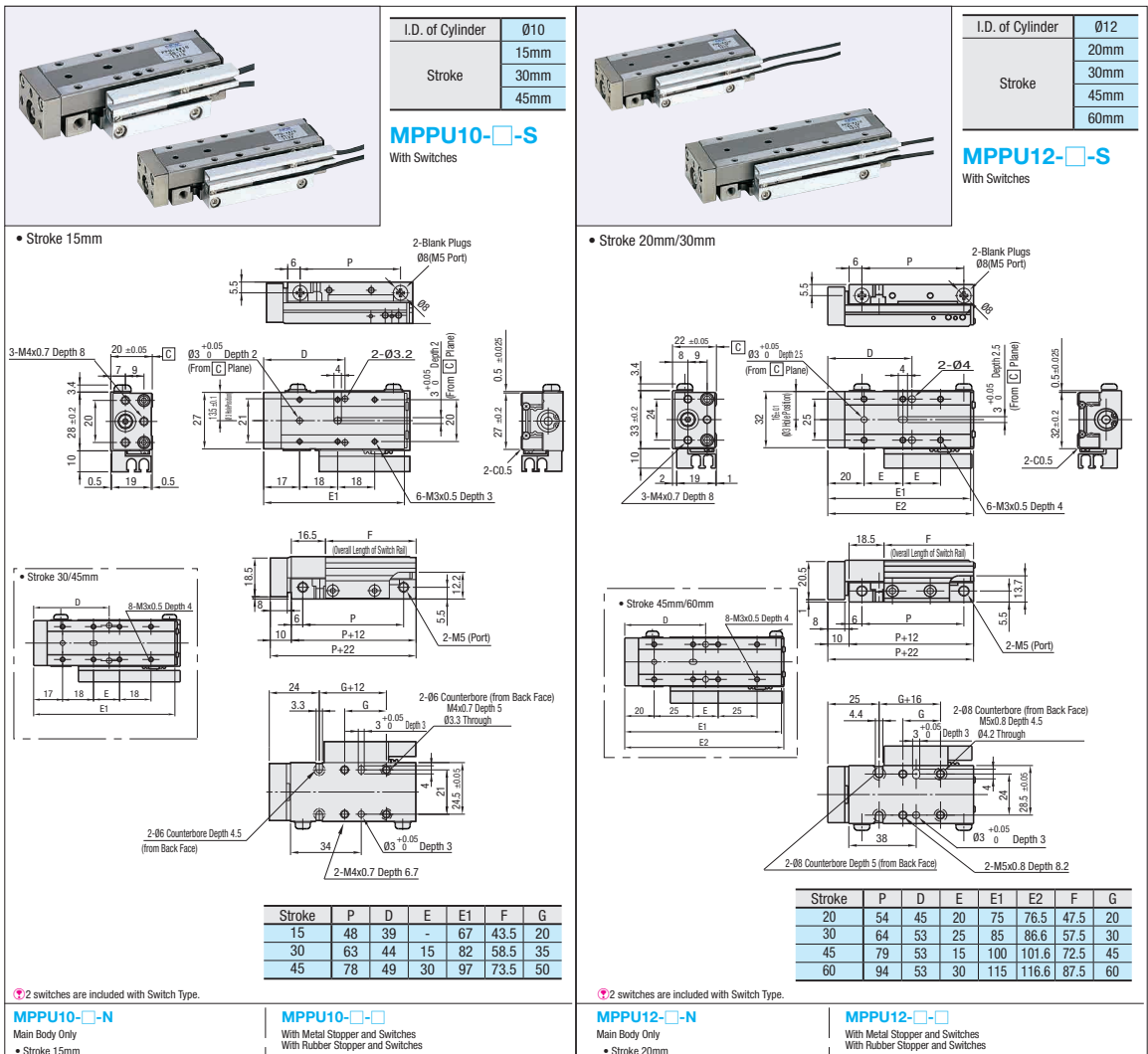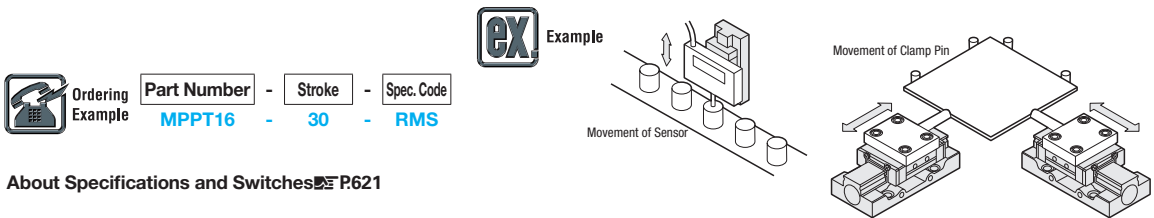

Part Number	Stroke	Specification Selection	Stroke Adjustable Amount	Max. Load Mass	Main Body Mass	Unit Price (per Each Spec.) 1 ~ 3 pc(s).
MPPU10	15	N (Main Body Only)	-	0.8kg	230g	-
	30	J (Main Body with Switch Rail)			270g	-
	45	S (Contacting Switch)			320g	-
	15	MS (Non-contact Switch)			275g	-
	30	MT (3 Wire Non-contact Switch)	Push Side 15mm	0.3kg	320g	-
	45	SS (Metal Stopper, Contacting Switch)			375g	-
	30	SMS (Metal Stopper, Non-contact Switch)			310g	-
	45	SMT (Metal Stopper, 3 Wire Non-contact Switch)			430g	-
	15	SN (Rubber Stopper, Contacting Switch)	-	0.8kg	310g	-
	30	SMN (Rubber Stopper, Non-contact Switch)			365g	-
	45	SMR (Rubber Stopper, 3 Wire Non-contact Switch)			430g	-
	45	SMR (Rubber Stopper, 3 Wire Non-contact Switch)			430g	-

Ordering Example: Part Number - Stroke - Spec. Code
MPPU12 - 60 - MS

About Specifications and Switches P621

Part Number	Stroke	Specification Selection	Stroke Adjustable Amount	Max. Load Mass	Main Body Mass	Unit Price (per Each Spec.) 1 ~ 3 pc(s).
MPPU12	20	N (Main Body Only)	-	1.2kg	320g	-
	30	J (Main Body with Switch Rail)			370g	-
	45	S (Contacting Switch)			425g	-
	60	MS (Non-contact Switch)			495g	-
	20	MT (3 Wire Non-contact Switch)	Push Side 15mm	0.5kg	367g	-
	30	SS (Metal Stopper, Contacting Switch)			420g	-
	45	SMS (Metal Stopper, Non-contact Switch)			480g	-
	60	SMT (Metal Stopper, 3 Wire Non-contact Switch)			555g	-
	20	SN (Rubber Stopper, Contacting Switch)	-	1.2kg	412g	-
	30	SMN (Rubber Stopper, Non-contact Switch)			475g	-
	45	SMR (Rubber Stopper, 3 Wire Non-contact Switch)			550g	-
	60	SMR (Rubber Stopper, 3 Wire Non-contact Switch)			640g	-

For orders larger than indicated quantity, please request a quotation.