



Super High Torque Timing Belts (MTS8M, UP5M, UP8M)

■ **Features:** Having nearly doubled transmission capacity compared to standard timing belts, higher-load transmission and space-saving design can be realized.
■ Super High Torque Timing Belt MTS8M is compatible with Super High Torque Timing Pulley S8M on **P.1403**. UP5M/UP8M is compatible with P5M/P8M on **P.1411~P.1414**.

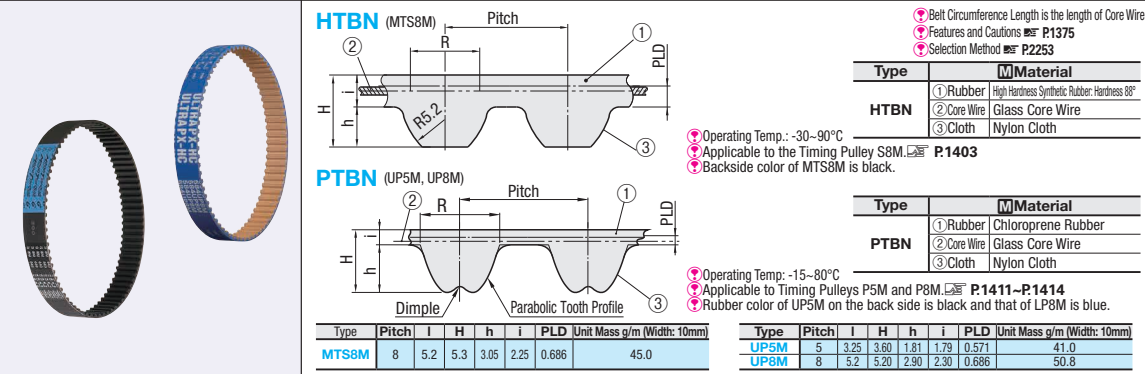

Timing Belts (T5, T10)

■ Timing Belt T5 is compatible with Timing Pulley T5 on **P.1417** and Timing Belt T10 is compatible with Timing Pulley T10 on **P.1419**.

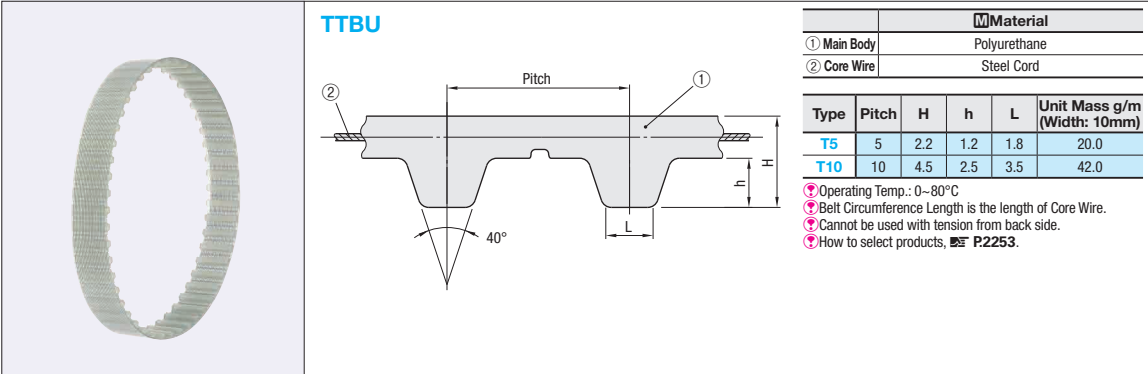

■ Type: MTS8M (Pitch: 8mm)

Part Number	Type	Belt Number	Belt Nominal Width	Number of Teeth	Belt Circumference Length (mm)	Unit Price			
						Belt Nominal Width			
						150	250	300	400
528-MTS8M	HTBN (Rubber)	528	150	66	528				
560-MTS8M		560	150	70	560				
584-MTS8M		584	150	73	584				
600-MTS8M		600	150	75	600				
632-MTS8M		632	150	79	632				
640-MTS8M		640	150	80	640				
656-MTS8M		656	150	82	656				
712-MTS8M		712	150	89	712				
720-MTS8M		720	150	90	720				
760-MTS8M		760	150	95	760				
800-MTS8M		800	150	100	800				
824-MTS8M		824	150	103	824				
848-MTS8M		848	150	106	848				
856-MTS8M		856	150	107	856				
880-MTS8M		880	150	110	880				
896-MTS8M		896	150	112	896				
920-MTS8M		920	150	115	920				
928-MTS8M		928	150	116	928				
944-MTS8M		944	150	118	944				
960-MTS8M		960	150	120	960				
976-MTS8M		976	150	122	976				
1000-MTS8M		1000	150	125	1000				
1024-MTS8M		1024	250	128	1024				
1056-MTS8M		1056	250	132	1056				
1080-MTS8M		1080	250	135	1080				
1120-MTS8M		1120	250	140	1120				
1152-MTS8M		1152	250	144	1152				
1160-MTS8M		1160	250	145	1160				
1200-MTS8M		1200	250	150	1200				
1216-MTS8M		1216	250	152	1216				
1248-MTS8M		1248	250	156	1248				
1280-MTS8M		1280	250	160	1280				
1304-MTS8M		1304	250	163	1304				
1320-MTS8M		1320	250	165	1320				
1352-MTS8M		1352	250	169	1352				
1360-MTS8M		1360	250	170	1360				
1400-MTS8M		1400	250	175	1400				
1480-MTS8M		1480	250	185	1480				
1520-MTS8M		1520	250	190	1520				
1600-MTS8M		1600	250	200	1600				
1640-MTS8M		1640	250	205	1640				
1680-MTS8M		1680	250	210	1680				
1760-MTS8M		1760	250	220	1760				
1800-MTS8M		1800	250	225	1800				
1880-MTS8M		1880	250	235	1880				
1960-MTS8M		1960	250	245	1960				
2000-MTS8M		2000	250	250	2000				
2064-MTS8M		2064	250	258	2064				
2400-MTS8M		2400	250	300	2400				
2600-MTS8M		2600	250	325	2600				
2800-MTS8M		2800	250	350	2800				

■ Type: UP5M (Pitch: 5mm)

Part Number	Type	Belt Number	Belt Nominal Width	Number of Teeth	Belt Circumference Length (mm)	Unit Price 1~4 pcs.	
						Belt Nominal Width	
						100	150
215-UP5M	PTBN (Rubber)	215	100	43	215		
225-UP5M		225	100	45	225		
255-UP5M		255	100	51	255		
260-UP5M		260	100	52	260		
275-UP5M		275	100	55	275		
295-UP5M		295	100	59	295		
300-UP5M		300	100	60	300		
310-UP5M		310	100	62	310		
320-UP5M		320	100	64	320		
325-UP5M		325	100	65	325		
340-UP5M		340	100	68	340		
350-UP5M		350	100	70	350		
370-UP5M		370	100	74	370		
375-UP5M		375	100	75	375		
400-UP5M		400	100	80	400		
420-UP5M		420	100	84	420		
425-UP5M		425	100	85	425		
430-UP5M		430	100	86	430		
440-UP5M		440	100	88	440		
450-UP5M		450	100	90	450		
475-UP5M		475	100	95	475		
480-UP5M		480	100	98	480		
500-UP5M		500	100	100	500		
515-UP5M		515	100	103	515		
520-UP5M		520	100	104	520		
525-UP5M		525	100	105	525		
530-UP5M		530	100	106	530		
550-UP5M		550	100	110	550		
560-UP5M		560	100	112	560		
575-UP5M		575	100	115	575		
595-UP5M		595	100	119	595		
600-UP5M		600	100	120	600		
605-UP5M		605	100	121	605		
635-UP5M		635	100	127	635		
650-UP5M		650	100	130	650		
670-UP5M		670	100	134	670		
675-UP5M		675	100	135	675		
690-UP5M		690	100	138	690		
725-UP5M		725	100	145	725		
740-UP5M		740	100	148	740		
750-UP5M		750	100	150	750		
780-UP5M		780	100	156	780		
800-UP5M		800	100	160	800		
835-UP5M		835	100	167	835		
850-UP5M		850	100	170	850		
900-UP5M		900	100	180	900		
1000-UP5M		1000	100	200	1000		
1050-UP5M		1050	100	210	1050		


For orders larger than indicated quantity, please request a quotation.

■ Type: UP8M (Pitch: 8mm)


Part Number	Type	Belt Number	Belt Nominal Width	Number of Teeth	Belt Circumference Length (mm)	Unit Price 1~4 pcs.	
						Belt Nominal Width	
						150	250
480-UP8M	PTBN (Rubber)	480	150	60	480		
512-UP8M		512	150	64	512		
520-UP8M		520	150	65	520		
536-UP8M		536	150	67	536		
560-UP8M		560	150	70	560		
584-UP8M		584	150	73	584		
600-UP8M		600	150	75	600		
632-UP8M		632	150	79	632		
640-UP8M		640	150	80	640		
680-UP8M		680	150	85	680		
712-UP8M		712	150	89	712		
720-UP8M		720	150	90	720		
760-UP8M		760	150	95	760		
800-UP8M		800	150	100	800		
832-UP8M		832	150	104	832		
840-UP8M		840	150	105	840		
856-UP8M		856	150	107	856		
880-UP8M		880	150	110	880		
960-UP8M		960	150	120	960		
1040-UP8M		1040	150	130	1040		
1080-UP8M		1080	150	135	1080		

For orders larger than indicated quantity, please request a quotation.

■ Comparison of Transmission Capacity between UP8M and P8M (Ref.)

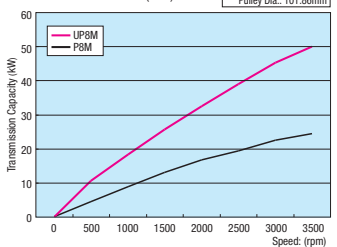

■ Comparison of Transmission Capacity between MTS8M and S8M (Ref.)

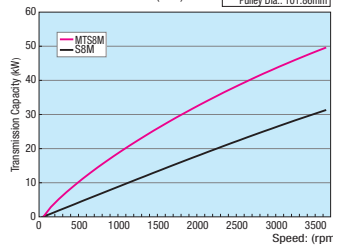

■ Type: T5 (Pitch: 5mm)

Type: T5 (Pitch: 5mm)								
Part Number		Belt Nominal Width	Number of Teeth	Belt Circumference Length (mm)	Unit Price			
Type	Belt Number				Belt Nominal Width			
TTBU	185T5	100 (10mm)	37	185				
	200T5		40	200				
	225T5		45	225				
	250T5		50	250				
	275T5		55	275				
	280T5		56	280				
	295T5		59	295				
	300T5		60	300				
	325T5		65	325				
	350T5		70	350				
	375T5		75	375				
	400T5		80	400				
	425T5		85	425				
	440T5		88	440				
	450T5		90	450				
	475T5		95	475				
	500T5	100	500					
	525T5	105	525					
	550T5	110	550					
	575T5	115	575					
	590T5	118	590					
	600T5	120	600					
	625T5	125	625					
	630T5	126	630					
	650T5	130	650					
	675T5	135	675					
	690T5	138	690					
	700T5	140	700					
	725T5	145	725					
	750T5	150	750					
	780T5	156	780					
	800T5	160	800					
	850T5	170	850					
	900T5	180	900					
1000T5	200	1000						
1075T5	215	1075						
1090T5	218	1090						
1100T5	220	1100						
1115T5	223	1115						
1215T5	243	1215						
1350T5	270	1350						
1380T5	276	1380						