

Brackets for Sensor with Stands

Plastic Stands / Stand Sheet Metal Type

Bracket Components for Sensor with Stands

Pipe Shafts / Stands / Brackets / Plastic Strut Clamps / Flexible Clamps

■ **Features:** Sensors can be installed right after the purchase since Stands, Pipe Shafts and Brackets are already included in a set.

■ **Plastic Stands**
1-Shaft Pipe



2-Shaft Pipe



RoHS10

SENJ GSENJ (Calibrated Pipe)

① Number of Pipe Shafts (1, 2) ③ Bracket (A, T, Y)

② Stand (G, S)


Material: Stand Pipe Polyamide EN 1.4301 Equiv.

When 2-shaft configuration is selected, SENJK (Strut Clamp for sensor on the right-hand page) is included.

For detailed dimensions of each product, refer to the drawing on the next page.

① Number of Pipe Shafts


1

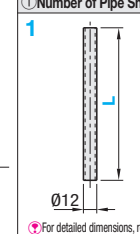

For detailed dimensions, refer to the next page SENP, GSENP


② Stand

G (Flat Mount)

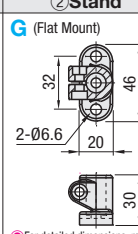

For detailed dimensions, refer to the next page SENJG


S (Side Mount)

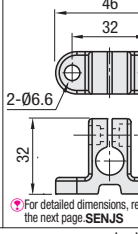

For detailed dimensions, refer to the next page SENJS


③ Bracket

A (Perpendicular Shaft Mount, Tip Rotation)

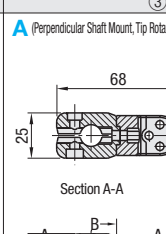


Section A-A

T (Parallel Shaft Mount)

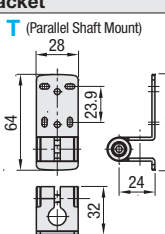

For detailed dimensions, refer to the next page SENRT

Y (Perpendicular Shaft Mount)

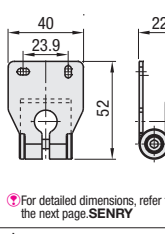

Can be fixed at desired location in 22.5° increment.

Details of Hatched Area (B-B)

For detailed dimensions, refer to the next page SENJA

For detailed dimensions, refer to the next page SENRY

■ **Plastic Stands** Dedicated nuts, dedicated washers and M5 hex socket head cap screws are included with Stands and Bracket set.

Part Number		L Selection	Stand	Bracket	Unit Price									
Type	Number of Pipe Shafts				Stand G (Flat Mount)					Stand S (Side Mount)				
					L100	L150	L200	L250	L300	L100	L150	L200	L250	L300
SENJ	1	100 150 200 250 300	G (Flat Mount)	T (Parallel Shaft Mount)										
GSENJ	2			Y (Perpendicular Shaft Mount)										

■ **Stand Sheet Metal Type**
1-Shaft Pipe



2-Shaft Pipe



RoHS10

SENRR GSENR (Calibrated Pipe)

① Number of Pipe Shafts (1, 2) ③ Bracket (A, T, Y)

② Stand (G, S)


Material: Stand, Pipe Shaft: EN 1.4301 Equiv.

When 2-shaft configuration is selected, FLYS12-12 (next page) is included.

For detailed dimensions of each product, refer to the drawing on the next page.

① Number of Pipe Shafts


1

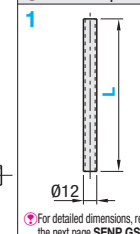

For detailed dimensions, refer to the next page SENRR


② Stand

G (Flat Mount)

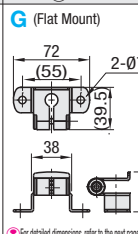

For detailed dimensions, refer to the next page SENRG


S (Side Mount)

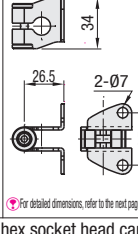

For detailed dimensions, refer to the next page SENRS


③ Bracket

A (Perpendicular Shaft Mount, Tip Rotation)

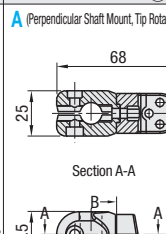


Section A-A

T (Parallel Shaft Mount)

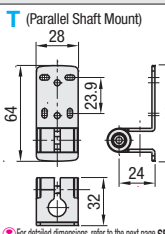

For detailed dimensions, refer to the next page SENRT

Y (Perpendicular Shaft Mount)

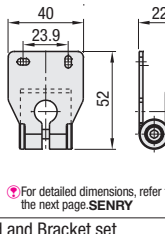

Can be fixed at desired location in 22.5° increment.

Details of Hatched Area (B-B)


For detailed dimensions, refer to the next page SENJA

For detailed dimensions, refer to the next page SENRY

■ **Stand Sheet Metal Type** A dedicated nut, a dedicated washer and an M5 hex socket head cap screw are included with Stand and Bracket set.

Part Number		L Selection	Stand	Bracket	Unit Price									
Type	Number of Pipe Shafts				Stand G (Flat Mount)					Stand S (Side Mount)				
					L100	L150	L200	L250	L300	L100	L150	L200	L250	L300
SENRR	1	100 150 200 250 300	G (Flat Mount)	T (Parallel Shaft Mount)										
GSENR	2			Y (Perpendicular Shaft Mount)										

Ordering Example	Part Number	L	Stand	Bracket
	Type	Number of Shafts		
	GSENJ	2	- 100	- S - A
	SENRR	1	- 150	- G - Y

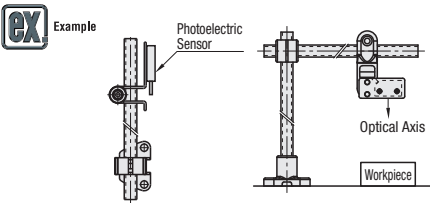


■ Pipe for Mounting Sensor with Scale




RoHS10

SENPP (Calibrated)

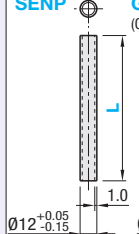

For detailed dimensions, refer to the next page SENRT

GSENP (Calibrated)

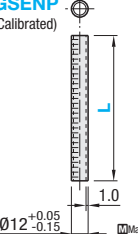

For detailed dimensions, refer to the next page SENRY

Part Number

L Selection

Unit Price

L100 L150 L200 L250 L300

SENPP 100 150 200 250 300

GSENP

Ordering Example

Part Number - L


SENPP - 300

■ Plastic Stands - Flat Mount / Side Mount




RoHS10

SENJG (Flat Mount)

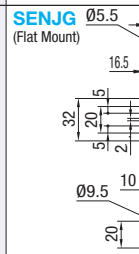

For detailed dimensions, refer to the next page SENRT

SENJS (Side Mount)

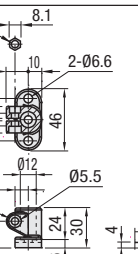

For detailed dimensions, refer to the next page SENRY

Material: Polyamide

Accessory: M5 Nut 1 pc. Bolt (Trivalent Chromate) SENJG: M5-15 1 pc. SENJS: M5-12 1 pc.

Part Number

Unit Price

Volume Discount Rate

1 ~ 4 pc(s) 5 ~ 9 pcs 10 ~ 50 pcs

SENJG

SENJS

For orders larger than indicated quantity, please check with WOS.

Ordering Example

Part Number


SENJG

■ Sheet Metal Stands - Flat Mount / Side Mount




RoHS10

SENRRG (Flat Mount)

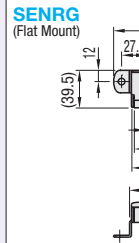

For detailed dimensions, refer to the next page SENRT

SENRS (Side Mount)

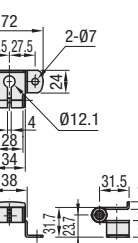

For detailed dimensions, refer to the next page SENRY

Material: EN 1.4301 Equiv.

Accessory: Dedicated Washer 1 pc. Dedicated Nut 1 pc. Screw (Trivalent Chromate) SENRRG: M5-30 1 pc. SENRS: M5-25 1 pc.

Part Number

Unit Price

Volume Discount Rate

1 ~ 4 pc(s) 5 ~ 9 pcs 10 ~ 50 pcs

SENRRG

SENRS

For orders larger than indicated quantity, please check with WOS.

Ordering Example

Part Number


SENRRG

■ Plastic Brackets - Perpendicular Shaft Mount / Tip Rotation



RoHS10

SENJA

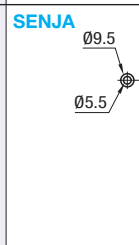

For detailed dimensions, refer to the next page SENRT

Material: Polyamide

Accessory: M5 Nut 2 pcs. Screw (Trivalent Chromate) M5-20 1 pc. M5-15 1 pc.

Part Number

Unit Price

Volume Discount Rate

1 ~ 4 pc(s) 5 ~ 9 pcs 10 ~ 50 pcs

SENJA

For orders larger than indicated quantity, please check with WOS.

Ordering Example

Part Number


SENJA

■ Sheet Metal Brackets - Parallel Shaft Mount / Perpendicular Shaft Mount




RoHS10

SENRT (Parallel Shaft Mount)

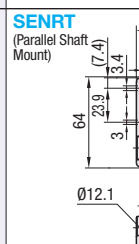

For detailed dimensions, refer to the next page SENRY

SENRY (Perpendicular Shaft Mount)

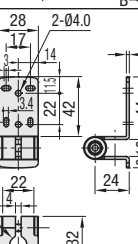

For detailed dimensions, refer to the next page SENRY

Material: EN 1.4301 Equiv.

Accessory: Dedicated Nut 1 pc. Screw (Trivalent Chromate) M5-23 1 pc. Dedicated Washer 1 pc.

Part Number

Unit Price

Volume Discount Rate

1 ~ 4 pc(s) 5 ~ 9 pcs 10 ~ 50 pcs

SENRT

SENRY

For orders larger than indicated quantity, please check with WOS.

Ordering Example

Part Number


SENRT

■ Plastic Strut Clamps



RoHS10

SENJK

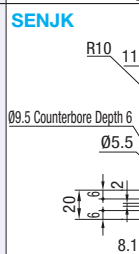

For detailed dimensions, refer to the next page SENRY

Material: Polyamide

Accessory: M5 Nut 2 pcs. Screw (Trivalent Chromate) M5-12 2 pcs.

Part Number

Unit Price

Volume Discount Rate

1 ~ 9 pc(s) 10 ~ 50 pcs

SENJK

For orders larger than indicated quantity, please check with WOS.

Ordering Example

Part Number


SENJK

■ Flexible Clamps



RoHS10

FLYS12-12

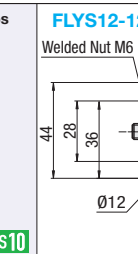

For detailed dimensions, refer to the next page SENRY

Material: EN 1.4301 Equiv.

Part Number

Unit Price

Volume Discount Rate

1 ~ 9 pc(s) 10 ~ 50 pcs

FLYS12-12

For orders larger than indicated quantity, please check with WOS.

Ordering Example

Part Number

FLYS12-12

Plastic clamps are not suitable for supporting heavy objects.

Part Number

Unit Price

Volume Discount Rate

1 ~ 9 pc(s) 10 ~ 50 pcs

SENJK

For orders larger than indicated quantity, please check with WOS.

Ordering Example

Part Number

SENJK

Part Number

Unit Price

Volume Discount Rate

1 ~ 9 pc(s) 10 ~ 50 pcs

FLYS12-12

For orders larger than indicated quantity, please check with WOS.

Ordering Example

Part Number

FLYS12-12