


Holders for Proximity Sensors / Sensor Flags / Sensor Flag Brackets

Proximity Sensor Flags


Set Screw / Slit

■ **Features:** Can be used in combination with Rails for Switches and Sensors - Aluminum (No. 4) on P.2077~P.2083

Holders for Proximity Sensors

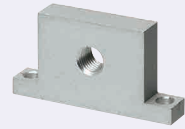

RoHS 10

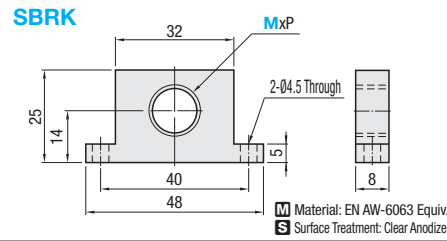

Part Number	Type	No.	M	MxP (Fine)	Unit Price	Volume Discount Rate
SBRK		4	8	8x1.0		10~50
			12	12x1.0		


⚠ For orders larger than indicated quantity, please check with WOS.

Ordering Example: Part Number - M
 SBRK4 - 8

Sensor Flags



RoHS 10

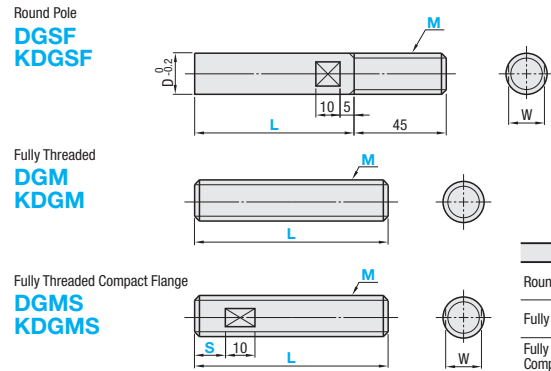

Type	M	Material	S	Surface Treatment
Round Pole	DGSF	EN 1.1191 Equiv.		Black Oxide
Fully Threaded	DGM			Black Oxide
Fully Threaded Compact Flange	DGMS			Black Oxide

Part Number	Type	M (Coarse)	L	5mm Increment	D	W	DGSF Unit Price				KDGSF Unit Price				
							L50~100	L105~200	L205~400	L405~600	L50~100	L105~200	L205~400	L405~600	
Round Pole	DGSF	10	50~500		10	8									
		12			12	10									
		16	50~600		16	12									

Part Number	Type	M (Coarse)	L	5mm Increment	DGM Unit Price			KDGM Unit Price		
					L50~100	L105~200	L205~400	L50~100	L105~200	L205~400
Fully Threaded	DGM	10	50~400							
		12								
		16								


Part Number	Type	M (Coarse)	L	5mm Increment	S	W	DGMS Unit Price			KDGMS Unit Price		
							L50~100	L105~200	L205~400	L50~100	L105~200	L205~400
Fully Threaded Compact Flange	DGMS	10	50~400		0≤S≤L-10	8						
		12				10						
		16				14						

Ordering Example: Part Number - L - S
 DGSF10 - 150
 DGMS16 - 300 - 100

Sensor Flag Brackets



RoHS 10

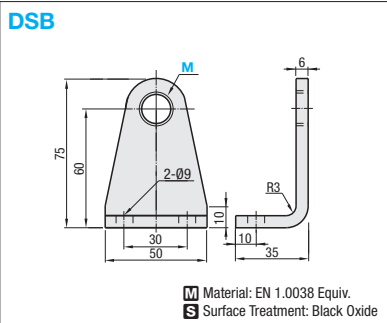


M Material: EN 1.0038 Equiv.
 S Surface Treatment: Black Oxide

Part Number	Type	M (Coarse)	Unit Price	Volume Discount Rate
DSB		10		10~50
		12		
		16		

⚠ For orders larger than indicated quantity, please check with WOS.

Ordering Example: Part Number
 DSB12

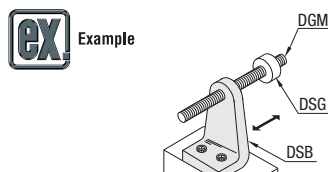

Limit Switch Flags P.2093, 2094

Set Screw




RoHS 10

⚠ Part Numbers in yellow are not RoHS compliant.


Shaft Bore	Type	M	Material	S	Surface Treatment	A	Accessory
Disc Type with Through Hole	DSS		EN 1.1191 Equiv.		Black Oxide		Set Screw 2 pcs.
Disc Type with Tapped Hole	DMG, DMGFS						Set Screw 2 pcs., Brass Ball 2 pcs.

6.3


Disc Type with Through Hole and Set Screw
 DSS

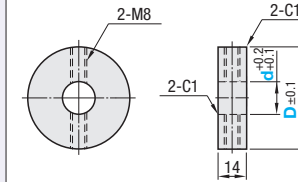

Disc Type with Tapped Hole and Set Screw
 DMG (With Brass Ball)

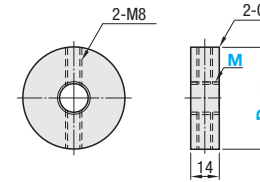

Stepped Type with Tapped Hole and Set Screw
 DMGFS (With Brass Ball)

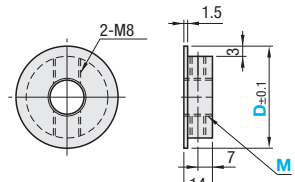

With Through Hole and Set Screw

Part Number	Type	D	d	Unit Price	Volume Discount Rate	
						1 ~ 9 pc(s).
DSS		25	8			
		30	10			
		40	12	16		
		50	12	16		

⚠ For orders larger than indicated quantity, please check with WOS.

Ordering Example: Part Number - d, M
 Type D
 DSS 25 - 8

With Tapped Hole and Set Screw

Part Number	Type	D	M (Coarse)	Unit Price	Volume Discount Rate	
						1 ~ 9 pc(s).
DMG		25	8			
		30	8	10		
		40	12	16		
		50	12	16		
DMGFS		40	12			
		50	12	16		

⚠ For orders larger than indicated quantity, please check with WOS.

Ordering Example: Part Number - d, M
 Type D
 DSS 25 - 8

Limit Switch Flags P.2093, 2094

With Slit




RoHS 10


Type	M	Material	S	Surface Treatment	A	Accessory
DSG, DMS, DMSL		EN 1.1191 Equiv.		Black Oxide		Hex Socket Head Cap Screw 1 pc.

6.3


Disc Type with Through Hole and Slit
 DSG

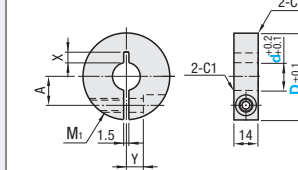

Disc Type with Tapped Hole and Slit
 DMS

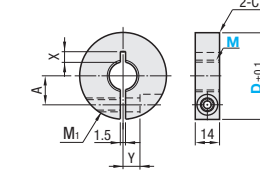

Disc Type with Tapped Hole and Slit, Deep C-bore
 DMSL

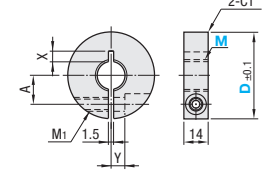

Disc Type with Through Hole and Slit

Part Number	Type	D	d	M ₁ (Coarse)	A	X	Y	Unit Price	Volume Discount Rate
								1 ~ 9 pc(s).	10~50
DSG		30	10	M5	9.0	6	6		
		40	12		16	14.0	7	8	
		50			M6	16.5	10	10	

⚠ For orders larger than indicated quantity, please check with WOS.

Disc Type with a Tapped Hole and Slit

Part Number	Type	D	M (Coarse)	M ₁ (Coarse)	A	X	Y	Unit Price	Volume Discount Rate
								1 ~ 9 pc(s).	10~50
DMS		30	10	M5	9.0	6	6		
		40	12		16	14.0	7	8	
		50			M6	16.5	10	10	
DMSL		50	12	M6	15.5	10	6		

⚠ For orders larger than indicated quantity, please check with WOS.

Ordering Example: Part Number - d, M
 Type D
 DSG 40 - 16
 DMS 30 - 10

