

Device Stands

Compact - Through Hole

■ **Features:** A set of a device mounting post and a stand for mounting in limited spaces.

■ Sets (Posts + Brackets)



■ Bracket only




■ Sets (Posts + Brackets)

Type		Post		Bracket		Accessory		
Solid	Hollow	M Material	H Hardness	S Surface Treatment	M Material	S Surface Treatment	Solid	Hollow
FSBNM	FSBAM	EN 1.1191 Equiv. Induction Hardened		Electroless Nickel Plating	EN 1.1191 Equiv.	LTBC Plating	Set Screw	Set Screw Cap (P2143)
MFSBN	MFSBA	EN 1.1191 Equiv.		Black Oxide				
KFSBN	KFSBA	EN 1.4301 Equiv.		-				
MSFSBN	MFSBB	EN 1.4301 Equiv.		-	EN 1.1191 Equiv.	Electroless Nickel Plating		
FSTNM	FSTAM	EN 1.1191 Equiv. Induction Hardened		Electroless Nickel Plating				
MFSTN	MFSTA	EN 1.1191 Equiv.		-				
MSFSTN	MFSTB	EN 1.4301 Equiv.		-	EN 1.1191 Equiv.	Black Oxide		
KBFSBN	KBFSBA	EN 1.1191 Equiv.		Black Oxide				
MSFSS	MFSSS	EN 1.4301 Equiv.		-				


* Case Induction Hardened (Post): 58HRC ~, Depth 1.0 ~ 1.5
* For Posts for Stands only, see P2143, 2144.
* There may be no electroless nickel plating and black oxide at ends and grooves of posts.

■ Sets (Posts + Brackets)

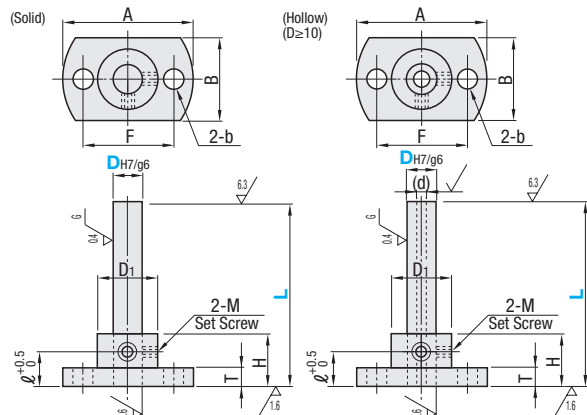

■ Bracket only

Type	Material	Surface Treatment	Accessory
MFSBF	EN 1.1191 Equiv.	LTBC Plating	Set Screw
MFSTF	EN 1.1191 Equiv.	Electroless Nickel Plating	
MFSLF	EN 1.4301 Equiv.	Black Oxide	
MFSS	EN 1.4301 Equiv.	-	

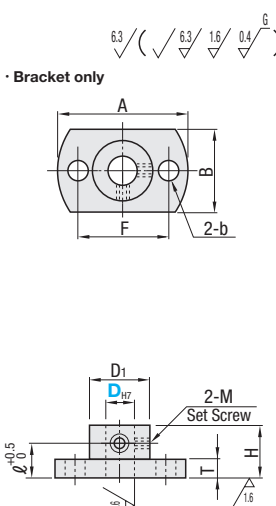

Part Number		Dg6		L 1mm Increment		A	B	F	D1	H	T	ℓ	b	M	(d)
Type															
Set	(Solid) FSBNM MFSBN KFSBN MSFSBN FSTNM MFSTN MSFSTN KBFSBN MSFSS	(Hollow) FSBAM MFSBA KFSBA MFSBB FSTAM MFSTA MFSTB KBFSBA MFSSS	MFSBF MFSTF MFSLF MFSS	6	-0.004 -0.012	50~150	33	18	23	14	20	6	12.5		
				8	-0.005	50~200	38	20	26	16	30	8	15	4.5	M4
				10	-0.014	50~250	40	22	28	18	35	8	18		6.0
				12	-0.006	50~300	46	24	32	20	35	8	18	5.5	M4
				15	-0.017	75~350	56	29	40	25	40	8	20	6.6	M5
				20		75~400	63	34	46	30	45	10	25	6.6	M5
				25	-0.007 -0.020	75~450	78	41	56	37	50	10	30		15.2
				30		100~450	82	46	62	42	60	10	30	9	M6
															16.0

*1. D6 is available for FSTNM, MFSBN, MFSTN, MSFSTN, MFSBF and MFSTF only. *2. Hollow posts are available from D10. *3. Refer to the price list for availability of brackets as a separate item.

Ordering Example	Part Number	-	L
	MFSTN15	-	250
	MFSBF20	-	

■ Sets (Posts + Brackets)

D	L	Unit Price									
		Solid					Hollow				
		*2FSBNM FSTNM	MFSBN MFSTN	KFSBN	*2MFSBN MSFSTN	KBFSBN	MSFSS	FSBAM FSTAM	MFSBA MFSTA	KFSBA	MFSBB MFSTB
6	Min. L ~ 100 101~150										
8	Min. L ~ 100 101~200										
10	Min. L ~ 150 151~250										
12	Min. L ~ 150 151~300										
15	Min. L ~ 200 201~350										
20	Min. L ~ 200 201~400										
25	Min. L ~ 200 201~450										
30	Min. L ~ 200 201~450										

*2. D6 is not available for FSBNM and MSFSBN.

■ Bracket only

D	Unit Price		
	MFSBF MFSTF	MFSLF	MFSS
6			
8			
10			
12			
15			
20			
25			
30			

Device Stands

Compact - Slotted Hole

■ **Features:** A set of a device mounting post and a stand for fine-tuning and mounting in limited spaces.

■ Sets (Posts + Brackets)



■ Bracket only




■ Sets (Posts + Brackets)

Type		Post		Bracket		Accessory			
Solid	Hollow	Material	Hardness	Surface Treatment	Material	Surface Treatment	Solid	Hollow	
LFSBN	LFSBA	EN 1.1191 Equiv.		Electroless Nickel Plating	EN 1.1191 Equiv.	LTBC Plating	Set Screw Washer Cap (P2143)	Set Screw Washer Cap (P2143)	
LFSTSM	-	EN 1.1191 Equiv. Induction Hardened		Electroless Nickel Plating					
LFSTN	LFSTA	EN 1.1191 Equiv.		-					
LSFSS	-	EN 1.4301 Equiv.		-	EN 1.4301 Equiv.	Electroless Nickel Plating			

* Case Induction Hardened (Post): 58HRC ~, Depth 1.0 ~ 1.5
* For Posts for Stands only, see P2143, 2144.
* There may be no electroless nickel plating and black oxide at ends and grooves of posts.
* Surface treatment may not be applied to the inside of the slotted holes on the bracket.


■ Sets (Posts + Brackets)

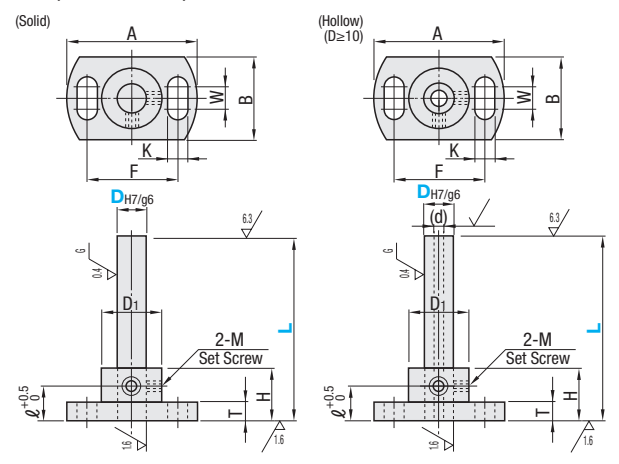

■ Bracket only

Type	Material	Surface Treatment	Accessory
LFSBF	EN 1.1191 Equiv.	LTBC Plating	Set Screw
LFSTF	EN 1.1191 Equiv.	Electroless Nickel Plating	

■ Bracket only

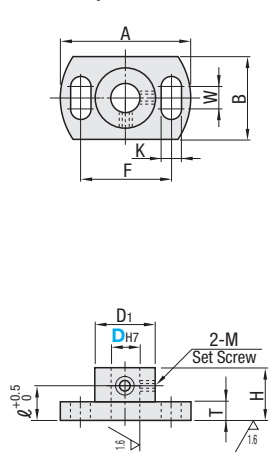

Part Number		Dg6		L		A	B	F	W	K	D1	H	T	ℓ	M	(d)
Type																
Set	(Solid) LFSBN LFSTSM LFSTN LSFSS	(Hollow) LFSBA LFSTA LFSTF	LFSBF	6	-0.004 -0.012	50~150	33	18	23		14	20	6	12.5		
				8	-0.005	50~200	38	20	26	6	16	30	8	15	M4	
				10	-0.014	50~250	40	22	28		18	35		18		6
				12	-0.006	50~300	46	24	32	6	20	35		18	M4	6
				15	-0.017	75~350	56	29	40	10	25	40		20	M5	10
				20		75~400	63	34	46		30	45		25	M5	11.7
				25	-0.007 -0.020	75~450	78	41	56	10	37	50	10	30	M6	15.2
				30		100~450	82	46	62		42	60		30	M6	16

*1. Hollow posts are available from D10. *2. Refer to the price list for availability of Brackets as a separate item.

Ordering Example	Part Number	-	L
	LFSTN15	-	250
	LSFSS20	-	

■ Sets (Posts + Brackets)

D	L	Unit Price			
		Solid		Hollow	
		LFSBN LFSTN	LFSTSM	LSFSS	LFSBA LFSTA
6	Min. L ~ 100 101~150				
8	Min. L ~ 100 101~200				
10	Min. L ~ 150 151~250				
12	Min. L ~ 150 151~300				
15	Min. L ~ 200 201~350				
20	Min. L ~ 200 201~400				
25	Min. L ~ 200 201~450				
30	Min. L ~ 200 201~450				

■ Bracket only

D	Unit Price	
	LFSBF	LFSTF
6		
8		
10		
12		
15		
20		
25		
30		



For Sensor Mounting (with Single Bracket)

