


Metal Washer

Standard Grade, T Dimension Selectable / Configurable

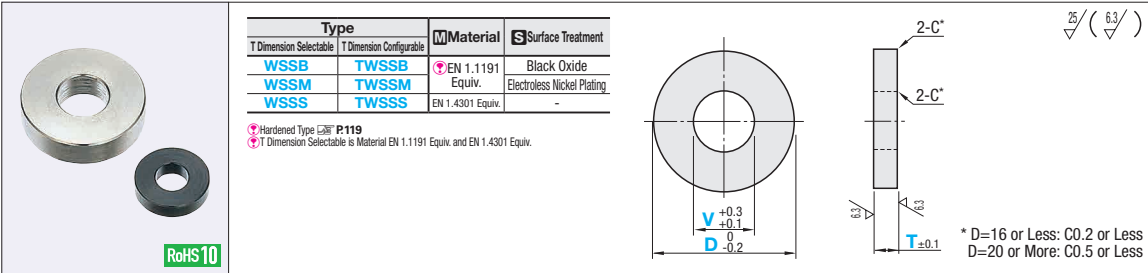

T Dimension Selectable (Standard Grade)

Part Number Type	D	V Selection	T Selection	Unit Price		
				WSSB	WSSM	WSSS
WSSB WSSM WSSS	4	2	1 2			
			1.5 2.5			
	5	2 3	1 2			
		3	1.5 2.5 3			
	6	2 3 4	1 2			
		3 4	1.5 2.5 3 4 5 6			
	8	2 3 4 5 6	1 2 3 5			
		3 4 5 6	1.5 2.5 4 6 8			
	10	2 3 4 5 6 8	1 2 3 5			
		3 4 5 6 8	1.5 2.5 4 6 8			
	12	3 4 5 6 8 10	1 2 3 5			
		4 5 6 8 10	1.5 2.5 4 6 8			
	13	4 5 6 8 10	1 2 3 5			
		5 6 8 10	1.5 2.5			
		6 8 10	4 6 8			
	14	4 5 6 8 10	1 2 3 5			
		5 6 8 10	1.5 2.5			
		6 8 10	4 6 8			
	15	4 5 6 8 10 12	1 2 3 5			
		5 6 8 10 12	1.5 2.5			
			4 6 8			
	16	4 5 6 8 10 12	1 2 3 5			
		6 8 10 12	1.5 2.5 4 6 8			
	20	4 5 6 8 10 12 15 16	1 2 3 5			
		6 8 10 12 15	1.5 2.5 4 6 8			
	25	6 8 10 12 15 16 20	1 2 3 5			
			4 6 8			
	30	8 10 12 15 16 20 25	1 2 3 5			
			4 6 8			
	35	10 12 15 16 20 25	3 5 10			
	40	10 12 15 16 20 25 30	3 5 10			
	50	10 12 15 16 20 25 30	3 5 10			
	60	15 16 20 25 30	3 5 10			

Ordering Example
Part Number - V - T
WSSS14 - 10 - 5

T Dimension Configurable (Standard Grade)


Part Number Type	D	V Selection	T 0.5mm Increment
4	2		
5	2 3		
6	2 3 4		
8	2 3 4 5 6		
10	2 3 4 5 6 8		
12	3 4 5 6 8 10		
13	4 5 6 8 10		
14	4 5 6 8 10		
15	4 5 6 8 10 12		
16	4 5 6 8 10 12		
20	4 5 6 8 10 12 15 16		
25	6 8 10 12 15 16 20		
30	8 10 12 15 16 20 25		

Ordering Example
Part Number - V - T
TWSSB30 - 8 - 5.5

D	T	Unit Price		
		TWSSB	TWSSM	TWSSS
4~10	1.0~ 2.0			
	2.5~ 5.0			
	5.5~10.0			
12~20	1.0~ 2.0			
	2.5~ 5.0			
	5.5~10.0			
25, 30	1.0~ 2.0			
	2.5~ 5.0			
	5.5~10.0			

Metal Washer

Precision Grade, T Dimension Selectable / Configurable

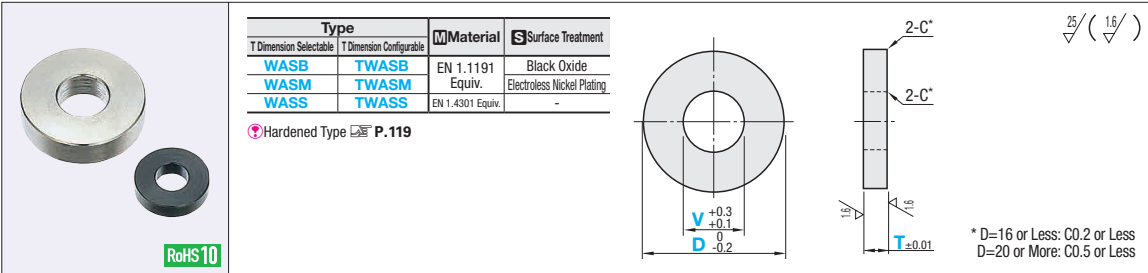

T Dimension Selectable (Precision Grade)

Part Number Type	D	V Selection	T Selection	Unit Price		
				WASB	WASM	WASS
WASB WASM WASS	4	2	1 2			
	5	2 3	1 2			
	6	2 3 4	1 2			
		3 4	1.5			
	8	2 3 4 5 6	1 2 3 5			
		3 4 5 6	1.5			
	10	2 3 4 5 6 8	1 2 3 5			
		4 5 6 8	1.5 2.5			
	12	3 4 5 6 8 10	1 2 3 5			
		5 6 8 10	1.5 2.5			
	13	4 5 6 8 10	1 2 3 5			
		6 8	1.5 2.5			
	14	4 5 6 8 10	1 2 3 5			
		6 8 10	1.5			
	15	4 5 6 8 10 12	1 2 3 5			
		6 8 10 12	1.5			
	16	4 5 6 8 10 12	1 2 3 5			
		6 8 10 12	1.5			
	20	4 5 6 8 10 12 15 16	2 3 5			
		6 10 15	1.5 2.5			
	25	6 8 10 12 15 16 20	2 3 5			
	30	8 10 12 15 16 20 25	2 3 5			
	35	10 12 15 16 20 25	3 5 10			
	40	10 12 15 16 20 25 30	3 5 10			
	50	10 12 15 16 20 25 30	3 5 10			
	60	15 16 20 25 30	3 5 10			

Ordering Example
Part Number - V - T
WASB14 - 10 - 5

T Dimension Configurable (Precision Grade)

Part Number Type	D	V Selection	T 0.5mm Increment
4	2		
5	2 3		
6	2 3 4		
8	2 3 4 5 6		
10	2 3 4 5 6 8		
12	3 4 5 6 8 10		
13	4 5 6 8 10		
14	4 5 6 8 10		
15	4 5 6 8 10 12		
16	4 5 6 8 10 12		
20	4 5 6 8 10 12 15 16		
25	6 8 10 12 15 16 20		
30	8 10 12 15 16 20 25		

Ordering Example
Part Number - V - T
TWASB30 - 8 - 5.5

D	T	Unit Price		
		TWASB	TWASM	TWASS
4~10	1.0~ 2.0			
	2.5~ 5.0			
	5.5~10.0			
12~20	1.0~ 2.0			
	2.5~ 5.0			
	5.5~10.0			
25, 30	1.0~ 2.0			
	2.5~ 5.0			
	5.5~10.0			