

Captured Washer Phillips Pan Head Screws / Phillips Pan Head Screws

Stainless Steel (Available in Box)


Phillips Pan Head Screws / Precision Machine Screws

Single Item Sale Pkg. Sale



Phillips Pan Head Screws with Captured Washer

Type	Part Number	Material
BOX-SCBJ	Screw	EN 1.4301 Equiv.
	Spring Washer	EN 1.4301 Equiv.
	Flat Washer	

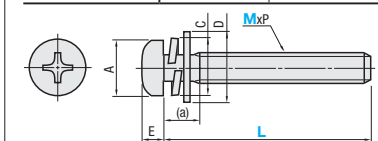


MxP (Coarse)	A	E	C	D	(a)	Phillips No.
2 x0.4	3.5	1.3	4	6	2.1	1
2.5x0.45	4.5	1.7	4.8	7.5	2.7	1
2.6x0.45	4.5	1.7	4.8	7.5	2.7	1
3 x0.5	5.5	2	5.5	8	3	2
4 x0.7	7	2.6	7	10	4.4	2
5 x0.8	9	3.3	8.5	12	5.4	2
6 x1.0	10.5	3.9	11.5	13	6.9	3

(a) is the max length (reference) between head surface and the complete thread.
Can be ordered as a separate item. P227



Phillips Pan Head Screws

Type	Material
BOX-NKJ	EN 1.4301 Equiv.

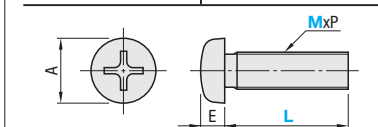

MxP (Coarse)	A	E	Phillips No.
2 x0.4	3.5	1.3	1
2.5x0.45	4.5	1.7	1
2.6x0.45	4.5	1.7	1
3 x0.5	5.5	2	2
4 x0.7	7	2.6	2
5 x0.8	9	3.3	2
6 x1.0	10.5	3.9	3

Can be ordered as a separate item. P226
Please specify in box quantity when ordering.
One box is shipped for an order of 1.

Ordering Example
Part Number
BOX-SCBJ5-10
BOX-NKJ5-10

Box package is cost-saving for in-house stock or when large quantities are needed.

Part Number		Unit Price 1 to 10 boxes		Pcs./ Box
Type	M-L	Price per pkg.	1 Box	
BOX-SCBJ (Stainless Steel)	2- 4 5 6 8 10			500 pcs./box
	2.5- 4 5 6 8 10			
	2.6- 4 5 6 8 10			
	3- 5 6 8 10			
	4- 5 6 8 10			
	5- 8 10 12 15			
	6-10 12 15			

For orders larger than indicated quantity, please check with WOS.


Part Number		Unit Price 1 to 10 boxes		Pcs./ Box
Type	M-L	Price per pkg.	1 Box	
BOX-NKJ (Stainless Steel)	2- 3 4 5 6 8 10			2,000 pcs./box
	2.5- 3 4 5 6 8 10			
	2.6- 3 4 5 6 8 10			
	3- 5 6 8 10			
	4- 5 6 8 10			
	5- 8 10 12 15			
	6-10 12 15			

For orders larger than indicated quantity, please check with WOS.

Phillips Pan Head Screws



Type	Material	Surface Treatment
BKJ	JIS-SWCH Equiv.	Trivalent Chromate
NKJ	EN 1.4301 Equiv.	-

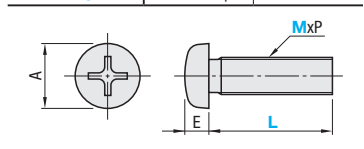

MxP (Coarse)	A	E	Phillips No.
2x0.4	3.5	1.3	1
2.5x0.45	4.5	1.7	1
2.6x0.45	4.5	1.7	1
3x0.5	5.5	2	2
4x0.7	7	2.6	2
5x0.8	9	3.3	2
6x1.0	10.5	3.9	3

BKJ (Trivalent Chromate)


Part Number		Unit Price	Volume Discount Rate		
Type	M - L	1 ~ 29 pc(s).	30 ~ 99 pcs.	100 ~ 299 pcs.	300 ~ 500 pcs.
BKJ	2 - 2 3 4 5 6 8 10				
	3 - 3 4 5 6 8 10				
	4 - 4 5 6 8 10 12 15				
	5 - 6 8 10 12 15				
	6 - 10 12 15 20				

Ordering Example
Part Number
NKJ3-6


NKJ (Stainless Steel)

Part Number		Unit Price	Volume Discount Rate		
Type	M - L	1 ~ 29 pc(s).	30 ~ 99 pcs.	100 ~ 149 pcs.	150 ~ 500 pcs.
NKJ	2 - 2 3 4 5 6 8 10				
	2.5 - 3 4 5 6 8 10				
	2.6 - 3 4 5 6 8 10				
	3 - 3 4 5 6 8 10 12				
	4 - 4 5 6 8 10 12 15				
	5 - 6 8 10 12 15 20				
	6 - 10 12 15 20				

Precision Machine Screws (Package)

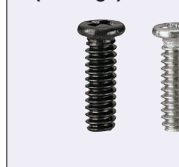

PACK-MIB PACK-SMIB (Stainless Steel)

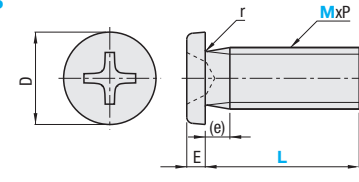

Type	Material	Surface Treatment
PACK-MIB	JIS-SWCH16A	Trivalent Black
PACK-SMIB	EN 1.4301 Equiv.	-

No. 0, Type 1 Pan Head Screw

Part Number		MxP	D	E	r (Max.)	(e) (Max.)	Qty. / Pack	Unit Price 1 - 2 pkg(s).	Volume Discount Rate 3-10 pkgs.					
Type	M									L				
PACK-MIB PACK-SMIB	1.2	2	3	4	5	*6	*8	1.2x0.25	1.8	0.5	0.05	0.4	50 pcs./pkg.	
	1.4	2	3	4	5	6	8	1.4x0.3	2		0.5			
	1.6	2	3	4	5	6	8	1.6x0.35	2.4		0.55			
	1.7	2	3	4	5	6	8	1.7x0.35	2.5	0.5				
	2.0	2	3	4	5	6	8	2.0x0.4	3	0.6				

The sizes marked with * are available for PACK-SMIB only.

Ordering Example
Part Number
PACK-MIB1.6-5

When placing an order, please specify number of packages. 1 package will be delivered for an order for 1.

For orders larger than indicated quantity, please check with WOS.