

Phillips Pan Head Screws with Captured Washer


Single Item Sale

Phillips Pan Head Screws with Captured Washer SW+JIS W Captured



RoHS10

NSET SCBJ

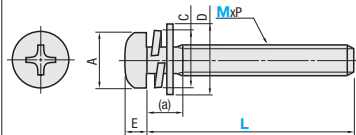

NSET

Screw	Material: JIS-SWCH Equiv.
Washers	Spring Washer JIS B 1251 Flat Washer JIS B 1256
Surface Treatment	Trivalent Chromate

SCBJ

Screw	Material: EN 1.4301 Equiv.
Washers	Spring Washer JIS B 1251 Flat Washer JIS B 1256

MxP	A	E	C (Max.)	D	(a)	Phillips No.
2 x0.4	3.5	1.3	4.0	6.0	2.1	1
2.5x0.45	4.5	1.7	4.8	6.5	2.7	1
2.6x0.45	4.5	1.7	4.8	7.5	2.7	1
3 x0.5	5.5	2.0	5.5	8.0	3.0	2
4 x0.7	7.0	2.6	7.0	10.0	4.4	2
5 x0.8	9.0	3.3	8.5	12.0	5.4	2
6 x1.0	10.5	3.9	11.5	13.0	6.9	3

Part Number	Type	M-L	NSET		SCBJ			
			Unit Price	Volume Discount Rate	Unit Price	Volume Discount Rate		
			1 ~ 99 pc(s).	100 ~ 500 pcs.	1 ~ 29 pc(s).	30 ~ 99 pcs.	100 ~ 149 pcs.	150 ~ 500 pcs.
2 - 4								
5								
6								
8								
2.5 - 4								
5								
6								
8								
10								
2.6 - 4								
5								
6								
8								
10								
3 - 5								
6								
8								
10								
12								
14								
15								
16								
20								
25								
30								
35								
40								
45								
50								
4 - 5								
6								
8								
10								
12								
14								
16								
20								
25								
30								
35								
40								
45								
50								
5 - 8								
10								
12								
14								
16								
20								
25								
30								
35								
40								
45								
50								
6 - 10								
12								
14								
16								
20								
25								
30								
35								
40								
45								
50								


NSET SCBJ

Phillips Pan Head Screws with Captured Washer SW+JIS Compact W Captured



RoHS10

PSET PSETS

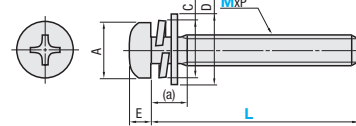

PSET

Screw	Material: JIS-SWCH Equiv.
Washers	Spring Washer JIS B 1251 Flat Washer JIS B 1256
Surface Treatment	Trivalent Chromate

PSETS

Screw	Material: EN 1.4301 Equiv.
Washers	Spring Washer JIS B 1251 Flat Washer JIS B 1256

MxP	A	E	C (Max.)	D	(a)	Phillips No.
3x0.5	5.5	2.0	5.5	6.0	3.0	2
4x0.7	7.0	2.6	7.0	8.0	4.4	2
5x0.8	9.0	3.3	8.5	10.0	5.4	2
6x1.0	10.5	3.9	11.5	11.5	6.9	3

Part Number	Type	M-L	PSET		PSETS					
			Unit Price	Volume Discount Rate	Unit Price	Volume Discount Rate				
			1 ~ 29 pc(s).	30 ~ 99 pcs.	100 ~ 149 pcs.	150 ~ 500 pcs.	1 ~ 29 pc(s).	30 ~ 99 pcs.	100 ~ 149 pcs.	150 ~ 500 pcs.
3 - 6										
8										
10										
12										
4 - 6										
8										
10										
12										
15										
5 - 8										
10										
12										
15										
6 - 10										
12										
15										
20										


PSET PSETS

Phillips Pan Head Screws with Captured Washer SW Captured



RoHS10

WSET WSETS

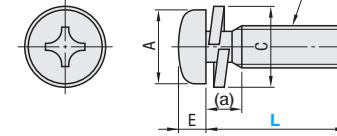

WSET

Screw	Material: JIS-SWCH Equiv.
Washers	Spring Washer JIS B 1251
Surface Treatment	Trivalent Chromate

WSETS

Screw	Material: EN 1.4301 Equiv.
Washers	Spring Washer JIS B 1251


MxP	A	E	C (Max.)	(a)	Phillips No.
3x0.5	5.5	2.0	5.5	2.4	2
4x0.7	7.0	2.6	7.0	3.5	2
5x0.8	9.0	3.3	8.5	4.3	2
6x1.0	10.5	3.9	11.5	5.1	3

Phillips Hex Head Screws with Captured Washer



RoHS10

BSET SBSET (Stainless Steel)

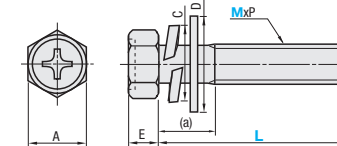

BSET

Screw	Material: Structural Alloy Steel Screw: JIS 0209 (6g)
Washers	Spring Washer JIS B1251 Flat Washer JIS B1256
Surface Treatment	Trivalent Chromate

SBSET

Screw	Material: EN 1.4301 Equiv. *Strength Class A2-50 Equiv. Screw: JIS 0209 (6g)
Washers	Spring Washer JIS B1251 Flat Washer JIS B1256
Surface Treatment	Barrel, Passivated

MxP	A	E	C	D	(a)
4x0.7	7	2.8	7.0	10	4.4
5x0.8	8	3.5	8.5	12	5.2
6x1.0	10	4.0	11.5	13	6.3
8x1.25	13	5.5	14.5	18	8.4

(a) is the max length (reference) between head surface and the complete thread.



Ordering Example

Part Number

BSET5-10
BSET4-8

Part Number	Type	M-L	WSET				WSETS			
			Unit Price	Volume Discount Rate	Unit Price	Volume Discount Rate	Unit Price	Volume Discount Rate	Unit Price	Volume Discount Rate
			1 ~ 29 pc(s).	30 ~ 99 pcs.	100 ~ 199 pcs.	200 ~ 500 pcs.	1 ~ 29 pc(s).	30 ~ 99 pcs.	100 ~ 199 pcs.	200 ~ 500 pcs.
3 - 6										
8										
10										
12										
4 - 8										
10										
12										
15										
5 - 8										
10										
12										
15										
6 - 10										
12										
15										
20										

Part Number	Type	M-L	BSET		SBSET		Part Number	Type	M-L	BSET		SBSET	
			Unit Price	Volume Discount Rate	Unit Price	Volume Discount Rate				Unit Price	Volume Discount Rate	Unit Price	Volume Discount Rate
			1 ~ 99 pc(s).	100 ~ 500 pcs.	1 ~ 99 pc(s).	100 ~ 500 pcs.				1 ~ 99 pc(s).	100 ~ 300 pcs.	1 ~ 99 pc(s).	100 ~ 500 pcs.
BSET 4-8							BSET 6-20						
SBSET 10							25						
12							30						
14							35						
16							40						
20							45						
25							50						
30							55						
35							60						
40							65						
45							70						
50							75						
BSET 5-10							BSET 8-12						
SBSET 12							14						
14							16						
16							20						
20							25						
25							30						
30							35						
35							40						
40							45						
45							50						
50							55						
BSET 6-10							BSET 60						
SBSET 12							65						
14							70						
16							75						



Ordering Example

Part Number

SCBJ6-10
PSET3-6