


# Nuts JIS Class 1 / JIS Class 3

Available in Box



## Nuts - JIS Class 1

Type	Material	Surface Treatment
BOX-LBNR	SAE1008 (JIS-SWRCH Equiv.)	Trivalent Chromate
BOX-SLBNR	EN 1.4301 Equiv.	-

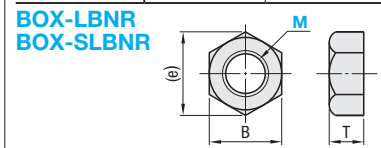

MxP (Coarse)	B	(e)	T
2 x0.4	4	4.6	1.6
2.5x0.45	5	5.8	2
2.6x0.45	5	5.8	2
3 x0.5	5.5	6.4	2.4
4 x0.7	7	8.1	3.2
5 x0.8	8	9.2	4
6 x1.0	10	11.5	5
8 x1.25	13	15	6.5
10 x1.5	17	19.6	8


Can be ordered as a separate item. P.240



RoHS10

## Nuts - JIS Class 3

Type	Material	Surface Treatment
BOX-KNTR	SAE1008 (JIS-SWRCH Equiv.)	Trivalent Chromate
BOX-SKNTR	EN 1.4301 Equiv.	-

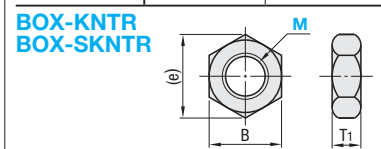

MxP (Coarse)	B	(e)	T <sub>1</sub>
3x0.5	5.5	6.4	1.8
4x0.7	7	8.1	2.4
5x0.8	8	9.2	3.2
6x1.0	10	11.5	3.6
8x1.25	13	15	5
10x1.5	17	19.6	6

Can be ordered as a separate item. P.240

Please specify in box quantity when ordering. One box is shipped for an order of 1.

Ordering Example

Part Number  
BOX-LBNR2.5  
BOX-SKNTR10

Box package is cost-saving for in-house stock or when large quantities are needed.

Part Number	Unit Price 1 to 10 boxes			Pcs./Box
	Type	M	1 Box	
BOX-LBNR	2			1,000 pcs./box
	2.5			
	2.6			
	3			
	4			
	5			
	6			
	8			
	10			
			200 pcs./box	

For orders larger than indicated quantity, please check with WOS.

Part Number	Unit Price 1 to 10 boxes			Pcs./Box
	Type	M	1 Box	
BOX-SLBNR (Stainless Steel)	2			1,000 pcs./box
	2.5			
	2.6			
	3			
	4			
	5			
	6			
	8			
	10			
			200 pcs./box	

For orders larger than indicated quantity, please check with WOS.

Part Number	Unit Price 1 to 10 boxes			Pcs./Box
	Type	M	1 Box	
BOX-KNTR	3			1,000 pcs./box
	4			
	5			
	6			
	8			
	10			
			200 pcs./box	

For orders larger than indicated quantity, please check with WOS.

Part Number	Unit Price 1 to 10 boxes			Pcs./Box
	Type	M	1 Box	
BOX-SKNTR (Stainless Steel)	3			1,000 pcs./box
	4			
	5			
	6			
	8			
			500 pcs./box	
			200 pcs./box	

For orders larger than indicated quantity, please check with WOS.

# Nuts

Single Item Sale

Nuts (LBNR, SLBNR, KNTR, SKNTR) can be ordered by cost saving boxes. P.239

**Nuts**

(JIS Class 1)  
LBNR (Right-Hand Thread)  
SLBNR (Stainless Steel Right-Hand Thread)  
LBNL (Left-Hand Thread)  
SLBNL (Stainless Steel Left-Hand Thread)

(JIS Class 3)  
KNTR (Right-Hand Thread)  
SKNTR (Stainless Steel Right-Hand Thread)  
KNTL (Left-Hand Thread)

ANN (Right-Hand Fine Thread)  
SANN (Stainless Steel Right-Hand Fine Thread)  
TNTR (Thin Right-Hand Fine Thread)  
STNTR (Stainless Steel Thin Right-Hand Fine Thread)

M	(Coarse) Pitch	B	(e)	T	T <sub>1</sub>
2	0.4	4	4.6	1.6	1.2
2.5	0.45	5	5.8	2	1.6
2.6	0.45	5	5.8	2	1.6
3	0.5	5.5	6.4	2.4	1.8
4	0.7	7	8.1	3.2	2.4
5	0.8	8	9.2	4	3.2
6	1.0	10	11.5	5	3.6
8	1.25	13	15	6.5	5
10	1.5	17	19.6	8	6
12	1.75	19	21.9	10	7
16	2.0	24	27.7	13	10
20	2.5	30	34.6	16	12
24	3.0	36	41.6	19	14

Part Number	LBNR		KNTR		SLBNR		SKNTR		LBNL		KNTL		SLBNL	
	Unit Price	Volume Discount Rate	Unit Price	Volume Discount Rate	Unit Price	Volume Discount Rate	Unit Price	Volume Discount Rate	Unit Price	Volume Discount Rate	Unit Price	Volume Discount Rate	Unit Price	Volume Discount Rate
Type	M	1 - 9 pc(s), 10 - 49 pcs, 50 - 200 pcs.	1 - 9 pc(s), 10 - 49 pcs, 50 - 200 pcs.	1 - 9 pc(s), 10 - 49 pcs, 50 - 200 pcs.	1 - 9 pc(s), 10 - 49 pcs, 50 - 200 pcs.	1 - 9 pc(s), 10 - 49 pcs, 50 - 200 pcs.	1 - 9 pc(s), 10 - 49 pcs, 50 - 200 pcs.	1 - 9 pc(s), 10 - 49 pcs, 50 - 200 pcs.	1 - 9 pc(s), 10 - 49 pcs, 50 - 200 pcs.	1 - 9 pc(s), 10 - 49 pcs, 50 - 200 pcs.	1 - 9 pc(s), 10 - 49 pcs, 50 - 200 pcs.	1 - 9 pc(s), 10 - 49 pcs, 50 - 200 pcs.	1 - 9 pc(s), 10 - 49 pcs, 50 - 200 pcs.	1 - 9 pc(s), 10 - 49 pcs, 50 - 200 pcs.
LBNR	2													
LBNL	2.5													
(M3-M16)	2.6													
SLBNR	3													
(M2-M20)	4													
SLBNL	5													
(M3-M16)	6													
KNTR	8													
(M3-M20)	10													
KNTL	12													
(M3-M20)	16													
SKNTR	20													
	24													

No specifications available for sizes with no prices shown.

Part Number	B	(e)	T	ANN		SANN		Part Number	B	(e)	TNTR		STNTR	
				Unit Price	Volume Discount Rate	Unit Price	Volume Discount Rate				Unit Price	Volume Discount Rate	Unit Price	Volume Discount Rate
Type	M (Fine)			1 - 99 pc(s), 100 - 200 pcs.	1 - 99 pc(s), 100 - 200 pcs.	1 - 99 pc(s), 100 - 200 pcs.	1 - 99 pc(s), 100 - 200 pcs.	Type	M-P-T <sub>2</sub>		1 - 99 pc(s), 100 - 200 pcs.	1 - 99 pc(s), 100 - 200 pcs.	1 - 99 pc(s), 100 - 200 pcs.	1 - 99 pc(s), 100 - 200 pcs.
ANN SANN	4-0.5	7	8.1					TNTR STNTR	6-0.75-1.5	8	9.2			
	5-0.5	8	9.2	4					6-0.75-2	9	10.4			
	6-0.75	10	11.5						8-0.75-2	10	11.5			
	8-0.75	13	15	5					10-0.75-2	14	16.2			
	8-1.0			6					10-1.0-2	14	16.2			
	10-1.0			6					10-1.0-3	14	16.2			
	10-1.25	17	19.6	8					10-1.0-4	14	16.2			
	12-1.0			6					12-1.0-2	14	16.2			
	12-1.25			10					12-1.0-3	17	19.6			
	12-1.5	19	21.9						12-1.0-4	17	19.6			
	14-1.5			11					16-1.0-2.5	19	21.9			
	16-1.5	22	25.0											
20-1.5	24	27.7	8											
	30	34.6	10											

Ordering Example

Part Number  
SLBNR10  
ANN10-1.25  
TNTR10-1.0-4