 


Chains / Connecting Parts

■ Chains









Material: EN 1.4301 Equiv.

Part Number	L 50mm Increment	P	A	d	Mass	Allowable Load (Ref.)	Unit Price
SCHSP	100~500	5.5	2.5	1.6	57g/m	9kg	
	550~1000						

The reference applied load is only a guideline.

 ■ Ball Chains

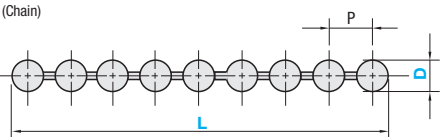

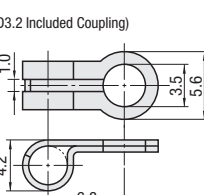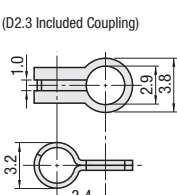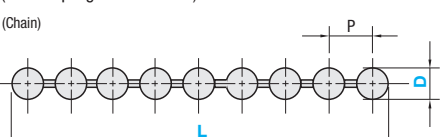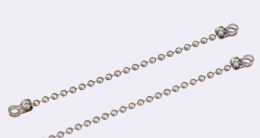

Material: EN 1.4301 Equiv.

Part Number Type	D	L 50mm Increment	P	Allowable Load (Ref.)	Accessory (Connector)		Unit Price		
					d	ℓ	BALLC	BALLC-S	BALLC-W
BALLC (One connector is included.)	2.3	100~500	3.3	4kg	3	8			
		550~1000							
BALLC-S (One coupling is included.)	3.2	100~500	4.4	6kg	4.3	11			
		550~1000							

* Depending on the number of links, the actual L dimension may be slightly longer than the specified dimension.
The reference applied load is only a guideline. Dimensions of chains and connecting parts are for reference only.

Ordering Example


Part Number - L

SCHSP - 600

BALLC2.3 - 150

BALLC-W3.2 - 200

■ Chains
Screw Fixed

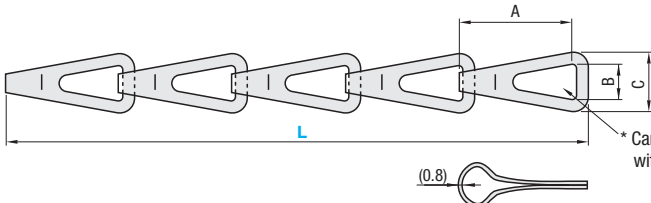

Material: EN 1.4301 Equiv.

Part Number Type	No.	L 50mm Increment	A	B	C	Plate Thickness	Mass	Applied Load	Unit Price
CHSP	4	100~500	15.5	4.2	8	0.8	60g/m	70kg	
		550~1000							


* Depending on the number of links, the actual L dimension may be slightly longer than the specified dimension. (Connecting parts are not included. Please refer to <http://jp.misumi-ec.com/mech/>.)
The reference applied load is only a guideline.

Ordering Example

Part Number - L

CHSP4 - 100

■ Metal Joints

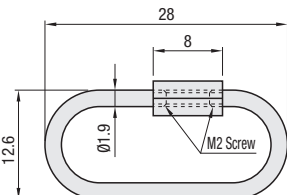

Material: EN 1.4301 Equiv.

Part Number	Mass	Applied Load	Unit Price	Volume Discount Rate		
SKC	3.2g	20kg		1 ~ 19 pc(s).	20 ~ 29 pcs.	30 ~ 49 pcs. 50 ~ 500 pcs.

 
The reference applied load is only a guideline.
For orders larger than indicated quantity, please check with WOS.

Ordering Example


Part Number

SKC

Up to 3.5mm



■ Double Rings

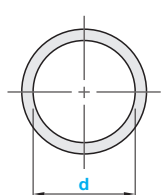

Material: EN 1.4301 Equiv.(d=10,18,22)
EN 1.4401 Equiv.(d=8,12,14)

Part Number Type	Wire Dia.	d	Applied Load (kg)	Unit Price	Volume Discount Rate		
RWS	8	0.8	0.5		1 ~ 3 pc(s).	4 ~ 19 pcs.	20 ~ 49 pcs. 50 ~ 500 pcs.
	10	0.8	0.7				
	12	1	1				
	14	1.2	1				
	18	1	0.7				
	22	1.2	1				

Ordering Example

Part Number

RWS10