


Sliders for Aluminum Extrusions


Curtains / Sliders for Curtain Rail / Curtain Fasteners

Sliders for Aluminum Extrusions - Tapped

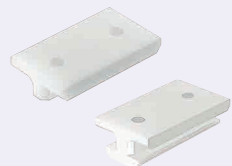


RoHS 10

HFAFSTA (Tapped Type without Slot-T)

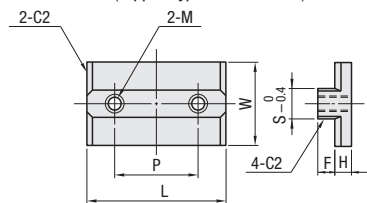


HFAFSTB (Tapped Type with Slot-T)

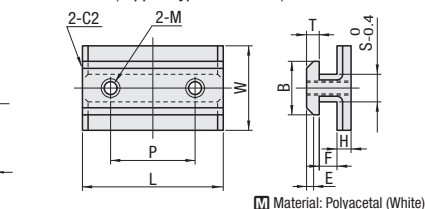


Part Number Type	No.	Extrusion (Series)	H	F	S	T	E	B	L	P	W	M	Applicable Screw	Unit Price 1 ~ 9 pc(s).	Volume Discount Rate 10~100
HFAFSTA	5	HFS5	5	3	5.8				35	20	18	3	M3		
	5L	HFS5		3	5.8				70	55	18	3	M3		
	6	HFS6		4	7.8				40	24	24	4	M4		
	6L	HFS6		4	7.8				80	66	24	4	M4		
	8	HFS8, HFS8-45		6	9.8				50	30	30	5	M5		
HFAFSTB	5	HFS5	5	3	5.8				35	20	18	3	M3		
	5L	HFS5		3	5.8				70	55	18	3	M3		
	6	HFS6		4	7.8				40	24	24	4	M4		
	6L	HFS6		4	7.8				80	66	24	4	M4		
	8	HFS8, HFS8-45		6	9.8				50	30	30	5	M5		
	8L	HFS8, HFS8-45		6	9.8				100	80	30	5	M5		
	2.5	HFS5		5.8	3.5	3	10		35	20	18	3	M3		
	2.5L	HFS5		5.8	3.5	3	10		70	55	18	3	M3		
	2.5	HFS6		7.8	5.3	3.5	14.1		40	24	24	4	M4		
	2.5L	HFS6		7.8	5.3	3.5	14.1		80	66	24	4	M4		

Sliders for Aluminum Extrusions - Counterbored

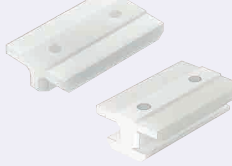


RoHS 10

HFAFSZA (Counterbored Type without Slot-T)

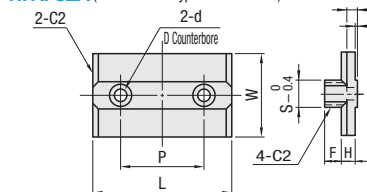

HFAFSZB (Counterbored Type with Slot-T)

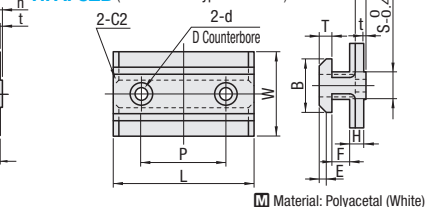


Part Number Type	No.	Extrusion (Series)	H	F	S	T	E	B	L	P	W	D	d	h	t	Screw, Nut	Unit Price 1 ~ 9 pc(s).	Volume Discount Rate 10~100
HFAFSZA	6	HFS6	5	4	7.8				40	24	24	6.5	3.4			CBM3-10 HNTT6-3		
	6L	HFS6		4	7.8				80	66	24	6.5	3.4			CBM3-10 HNTT6-3		
	8	HFS8, HFS8-45		6	9.8				50	30	30	8	4.5	3.8	0.8	CBM4-12 HNTT8-4		
	8L	HFS8, HFS8-45		6	9.8				100	80	30	8	4.5	3.8	0.8	CBM4-12 HNTT8-4		
	8L	HFS8, HFS8-45		6	9.8				100	80	30	8	4.5	3.8	0.8	CBM4-12 HNTT8-4		
HFAFSZB	6	HFS6	5	2.5	7.8	5.3	3.5	14.1	40	24	24	6.5	3.4			CBM3-10 HNTT6-3		
	6L	HFS6		2.5	7.8	5.3	3.5	14.1	80	66	24	6.5	3.4			CBM3-10 HNTT6-3		
	8	HFS8, HFS8-45		6.3	9.8	4.5	2.5	19	50	30	30	8	4.5	3.8	0.8	CBM4-12 HNTT8-4		
	8L	HFS8, HFS8-45		6.3	9.8	4.5	2.5	19	100	80	30	8	4.5	3.8	0.8	CBM4-12 HNTT8-4		
	8L	HFS8, HFS8-45		6.3	9.8	4.5	2.5	19	100	80	30	8	4.5	3.8	0.8	CBM4-12 HNTT8-4		

Sliders for Aluminum Extrusions - Counterbored Mini



RoHS 10


HFBFSZB (Counterbored Type Mini with Slot-T)

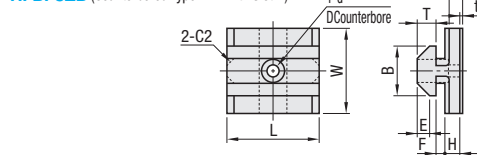

Part Number Type	No.	Extrusion (Series)	H	F	S	T	E	B	L	W	D	d	h	t	Screw, Nut	Unit Price 1 ~ 9 pc(s).	Volume Discount Rate 10~100
HFBFSZB	6	HFS6	5	2.5	7.8	5.3	3.5	14.1	26	24	6.5	3.4	3.8	0.8	CBM3-10 HNTT6-3		
	8	HFS8, HFS8-45		6.3	9.8	4.5	2.5	19	34	30	8	4.5	3.8	0.8	CBM4-12 HNTT8-4		

Ordering Example
HFAFSTA6

Example
Used to slide over aluminum extrusions.

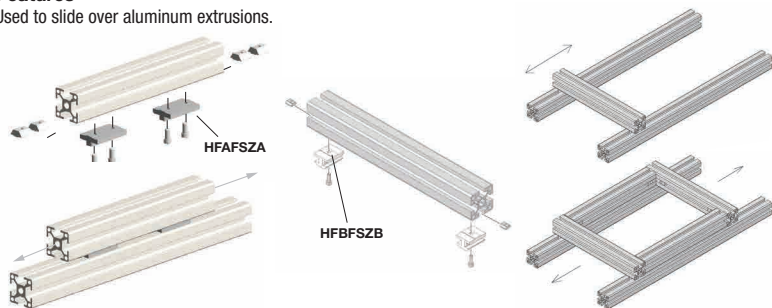

Curtains


Grommet




RoHS 10

HPEFC (Standard Type)

HPEDC (Anti-Static Type)

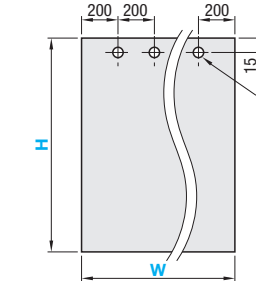

Grommet Details

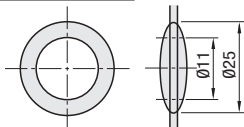


(Curtain)
Material: EN CW452K Equiv.
Surface Treatment: Nickel Plating


Grommets are provided at 200mm pitch. Can be cut by scissors.

Accessory
Curtain Fastener

Opened

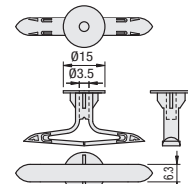

Closed

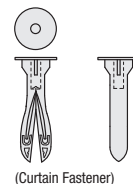

(Curtain Fastener)
Material: Polypropylene Resin

Curtains

Part Number Type	No.	Height (H) 100mm Increment	Width (W) 200mm Increment	Sheet Used P.794
HPEFC	6 8	1200~2400	600~1200	HPEDT0.2
HPEDC				HPEDT0.2

H	No. 6 Unit Price 1 ~ 4 pc(s).							
	HPEFC6				HPEDC6			
1200	600	800	1000	1200	600	800	1000	1200
1300								
1400								
1500								
1600								
1700								
1800								
1900								
2000								
2100								
2200								
2300								
2400								

For orders larger than indicated quantity, please check with WOS.

Alterations

Part Number - H - W - (LHC, RHC)
HPEDC6 - H2000 - W1000 - LHC50-RHC100

Alterations	Grommet on Left End	Grommet on Right End
	LHC	RHC
Code	LHC	RHC
Spec.	Adds a grommet on the left end. LHC = 10mm Increment 20≤LHC≤140 One set of sliding hooks and one piece of curtain fastener are added.	Adds a grommet on the right end. RHC = 10mm Increment 20≤RHC≤140 One set of sliding hooks and one piece of curtain fastener are added.


Sliders for Curtain Rail (50 pcs. per pkg.)



RoHS 10

HCRS5
HCRS6
HCRS8

* HCRS8 is commonly used for 8-45 Series.
Can not be used with Curtain (HFCC).
Use in combination with commercially sold s-hooks, etc.

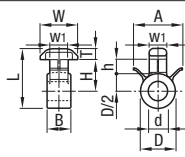

Material: PA6 Polyamide

Part Number Type	No.	W	h	L	w1	d	D	A	T	B	Unit Price 1 ~ 9 pkg(s).	Volume Discount Rate 10~20
HCRS	5	11	3.5	18.5	5	6	12	18	3	7		
	6	15	4	24	7	7	14	19	6	9		
	8	19	7.5	31.5	9	10	18	25	6	12		

For orders larger than indicated quantity, please check with WOS.



Curtain Fasteners



RoHS 10

HPMT

Separate the backing paper, and paste onto the aluminum extrusion.

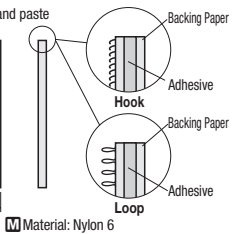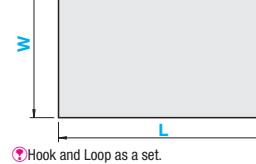

Hook and Loop as a set.

Material: Nylon 6

Ordering Example

Part Number
HPMT50 - L