


# Safety Mesh Fence Units

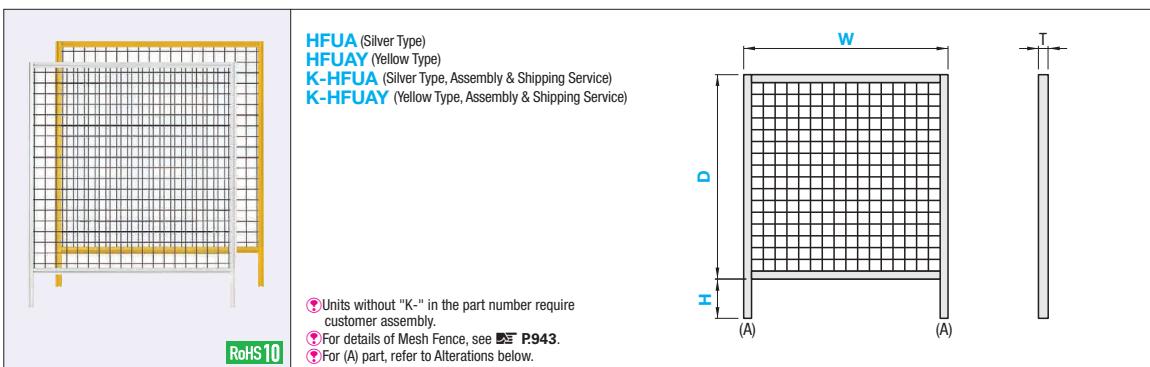


**HFUA** (Silver Type)  
**HFUAY** (Yellow Type)  
**K-HFUA** (Silver Type, Assembly & Shipping Service)  
**K-HFUAY** (Yellow Type, Assembly & Shipping Service)

Units without "K-" in the part number require customer assembly.  
For details of Mesh Fence, see P943.  
For (A) part, refer to Alterations below.

RoHS 10

## Silver Type

Part Number			Mesh Fence (Wire Ø3.2) Panel (t=3) Selection			W (Width) 1mm Increment	D (Height) 1mm Increment	H (Leg Height) Selection	T	Components						
Type	Configuration	No.				Mesh Fence	Extrusion	Fastening Parts		Mesh Fence	Extrusion	Fastening Parts	Quantity			
			Parts	Parts	Parts	Parts	Quantity									
<b>HFUA</b> <b>K-HFUA</b>	6	30B (Pitch 30mm, Black)	<b>PET3</b> (PET 3mm, Clear)	300 500	0 150	30	Black (FENP) Silver (FENM)	HFFS6-3030	SCB8-40	4	30B (Pitch 30mm, Black)	<b>PET3</b> (PET 3mm, Clear)	300 500	0 150	30	HFFS6-3030
		30S (Pitch 30mm, Silver)	<b>AC3</b> (Acrylic 3mm, Clear)	1000	1030	40		HFFS8-4040	SCB12-60	4		<b>PC3</b> (Polycarbonate 3mm, Clear)	1000	2200	40	HFFS8-4040
<b>K-HFUA</b>	8	50B (Pitch 50mm, Black)	<b>PC3</b> (Polycarbonate 3mm, Clear)	1000	1030	40	Black (FENP) Silver (FENM)	HFFS8-4040	SCB12-60	4		<b>ST3</b> (Anti-static PVC 3mm, Clear)	1000	2200	40	HFFH8-4040
		50S (Pitch 50mm, Silver)	<b>ST3</b> (Anti-static PVC 3mm, Clear)												SCB12-60	

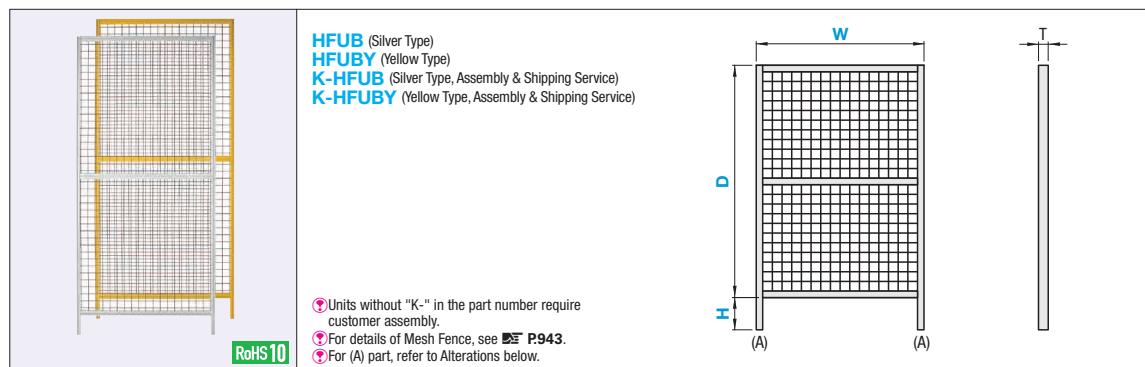

**HFUB** (Silver Type)  
**HFUBY** (Yellow Type)  
**K-HFUB** (Silver Type, Assembly & Shipping Service)  
**K-HFUBY** (Yellow Type, Assembly & Shipping Service)

Units without "K-" in the part number require customer assembly.  
For details of Mesh Fence, see P943.  
For (A) part, refer to Alterations below.

RoHS 10

## Silver Type

Part Number			Mesh Fence (Wire Ø3.2) Panel (t=3) Selection			W (Width) 1mm Increment	D (Height) 1mm Increment	H (Leg Height) Selection	T	Components						
Type	Configuration	No.				Mesh Fence	Extrusion	Fastening Parts		Mesh Fence	Extrusion	Fastening Parts	Quantity			
			Parts	Parts	Parts	Parts	Quantity									
<b>HFUB</b> <b>K-HFUB</b>	6	30B (Pitch 30mm, Black)	<b>PET3</b> (PET 3mm, Clear)	300 500	0 150	30	Black (FENP) Silver (FENM)	HFFS6-3030	SCB8-40	6	30B (Pitch 30mm, Black)	<b>PET3</b> (PET 3mm, Clear)	300 500	0 150	30	HFFS6-3030
		30S (Pitch 30mm, Silver)	<b>AC3</b> (Acrylic 3mm, Clear)	1000	1030	40		HFFS8-4040	SCB12-60	6		<b>PC3</b> (Polycarbonate 3mm, Clear)	1000	2200	40	HFFS8-4040
<b>K-HFUB</b>	8	50B (Pitch 50mm, Black)	<b>PC3</b> (Polycarbonate 3mm, Clear)	1000	1030	40	Black (FENP) Silver (FENM)	HFFS8-4040	SCB12-60	6		<b>ST3</b> (Anti-static PVC 3mm, Clear)	1000	2200	40	HFFH8-4040
		50S (Pitch 50mm, Silver)	<b>ST3</b> (Anti-static PVC 3mm, Clear)												SCB12-60	

## Yellow Type

Part Number			Mesh Fence (Wire Ø3.2) Panel (t=3) Selection			W (Width) 1mm Increment	D (Height) 1mm Increment	H (Leg Height) Selection	T	Components						
Type	Configuration	No.				Mesh Fence	Extrusion	Fastening Parts		Mesh Fence	Extrusion	Fastening Parts	Quantity			
			Parts	Parts	Parts	Parts	Quantity									
<b>HFUAY</b> <b>K-HFUAY</b>	6	30B (Pitch 30mm, Black)	<b>PET3</b> (PET 3mm, Clear)	300 500	0 150	30	Black (FENP) Silver (FENM)	HFFSY6-3030	SCB8-40	4	30B (Pitch 30mm, Black)	<b>PET3</b> (PET 3mm, Clear)	300 500	0 150	30	HFFSY6-3030
		30S (Pitch 30mm, Silver)	<b>AC3</b> (Acrylic 3mm, Clear)	1000	1030	40		HFFSY8-4040	SCB12-60	4		<b>PC3</b> (Polycarbonate 3mm, Clear)	1000	2200	40	HFFSY8-4040
<b>K-HFUAY</b>	8	50B (Pitch 50mm, Black)	<b>PC3</b> (Polycarbonate 3mm, Clear)	1000	1030	40	Black (FENP) Silver (FENM)	HFFSY8-4040	SCB12-60	4		<b>ST3</b> (Anti-static PVC 3mm, Clear)	1000	2200	40	HFFHY8-4040
		50S (Pitch 50mm, Silver)	<b>ST3</b> (Anti-static PVC 3mm, Clear)												SCB12-60	

## Yellow Type

Part Number			Mesh Fence (Wire Ø3.2) Panel (t=3) Selection			W (Width) 1mm Increment	D (Height) 1mm Increment	H (Leg Height) Selection	T	Components						
Type	Configuration	No.				Mesh Fence	Extrusion	Fastening Parts		Mesh Fence	Extrusion	Fastening Parts	Quantity			
			Parts	Parts	Parts	Parts	Quantity									
<b>HFUBY</b> <b>K-HFUBY</b>	6	30B (Pitch 30mm, Black)	<b>PET3</b> (PET 3mm, Clear)	300 500	0 150	30	Black (FENP) Silver (FENM)	HFFSY6-3030	SCB8-40	6	30B (Pitch 30mm, Black)	<b>PET3</b> (PET 3mm, Clear)	300 500	0 150	30	HFFSY6-3030
		30S (Pitch 30mm, Silver)	<b>AC3</b> (Acrylic 3mm, Clear)	1000	1030	40		HFFSY8-4040	SCB12-60	6		<b>PC3</b> (Polycarbonate 3mm, Clear)	1000	2200	40	HFFSY8-4040
<b>K-HFUBY</b>	8	50B (Pitch 50mm, Black)	<b>PC3</b> (Polycarbonate 3mm, Clear)	1000	1030	40	Black (FENP) Silver (FENM)	HFFSY8-4040	SCB12-60	6		<b>ST3</b> (Anti-static PVC 3mm, Clear)	1000	2200	40	HFFHY8-4040
		50S (Pitch 50mm, Silver)	<b>ST3</b> (Anti-static PVC 3mm, Clear)												SCB12-60	

## Example

Ordering Example: Part Number - Mesh Fence - W - D - H

HFUA6 - 30B - W700 - D800 - H150

K-HFUA6 - 30B - W700 - D800 - H150

Ordering Example: Part Number - Mesh Fence - W - D - H - Alteration Code

HFUA6 - 30B - W700 - D800 - H150 - UTP

K-HFUA6 - 30B - W700 - D800 - H150 - UTP

Alteration Code Spec.

Tapping on the Bottom End Face UTP Adds tapped holes on (A) in the drawing. HFUA6, HFUAY6 ⇒ M8 Depth 24 HFUA8, HFUAY8 ⇒ M12 Depth 36

Procedure① Connect frame extrusions with counterbored holes and end tapped holes using hex socket cap screws.  
\* Use hex socket head cap screws (SCB12-60) when connecting HFFS8-4040 extrusions.

Procedure② Insert a mesh fence into a dedicated slot.  
The slots may be slightly tight.

Procedure③ Connect the extrusions in the same manner as Step ① to complete.

## Example

<How to Mount Safety Fence Extrusions>

