

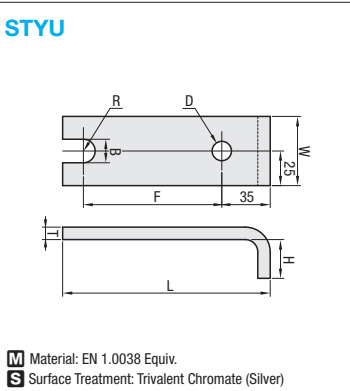


Angle Brackets


Press-Fit / Standard / Ribbed

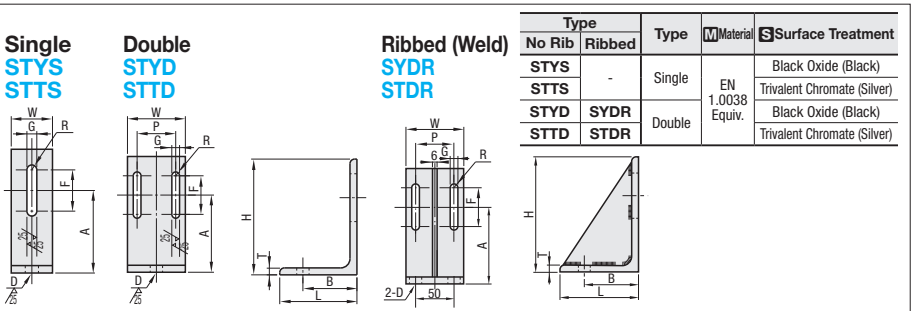

Part Number	Applicable	F	B	H	L	W	T	D	R	Unit Price
Type	No. Leveling Mount							Hole Dia. Applicable Screw		
STYU	12 FJFN12 (P.1110)	70	13	26	130	50	9	14	M12	6.5
	16 FJFN16 (P.1110)		17	28						8.5
	20 FJFN20 (P.1110)		21	31						10.5

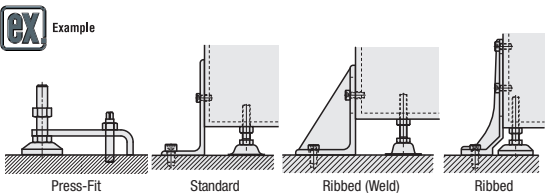

Main Body	Part Number		H	L	T	W	D		B	A	F	G		R	P	Unit Price		
	Type	No.					Hole Dia.	Applicable Screw				Slotted Hole	Applicable Screw			STYS, STYD	STTS, STTD	SYDR, STDR
Single	Black Oxide	10	100	75	7	45	12	M10	60	60	50	12	M10	6	-	-	-	
	STYS	12	150	100	9	50	16	M12	70	100	50				-	-	-	
	Trivalent Chromate	16	200	90		55	18	M16		120	60	14	M12	7		-	-	
Double	Black Oxide	10	100	75	7	70	12	M10	50	60	50	10	M8	5	45	-	-	
	STYD (No Rib)	12	150	100	9	75	16	M12	70	100				50				
	SYDR (Ribbed)	16	200	90		80	18	M16		120	60	12	M10	6	55	-	-	
	Trivalent Chromate																	
	STTD (No Rib)																	
	STDR (Ribbed)																	

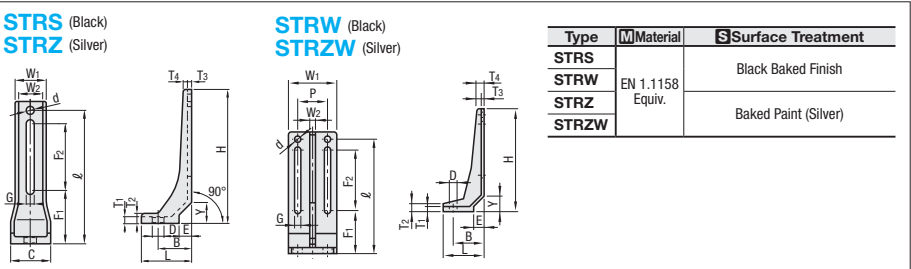

Part Number		H	L	C	T1	T2	T3	T4	W1	W2	D		B	F1	F2	G		d	P	ℓ	Y	E	Unit Price	
Type	No.										Hole Dia.	Applicable Screw				Slotted Hole	Applicable Screw						STRS, STRW	STRZ, STRZW
Single STRS STRZ	8	125	50	40	6	10	4	5	30	23	12	M8	35	50	50	7	M6	7	-	115	20	12		
	10	160	60	45	8	12	5	5	35	27	14	M10	40	60	75	9	M8	9	-	150	25	15		
	12	200	72	55	10	15	6	5	45	35	16	M12	50	70	100	11	M10	11	-	188	30	18		
Double STRW STRZW	10	150	60	-	8	12	5	10	65	8	14	M10	40	50	60	9	M8	9	30	140	25	15		
	12	200	80	-	10	15	6	15	80	10	16	M12	60	70	100	11	M10	11	50	188	30	20		

