


Knurled Knobs with Captured Washer / Stepped Knobs / Knurled Knobs - Large Diameter / Knurled Knobs - Small Diameter

Knurled Knobs with Captured Washer

Type	Knobs	Flat Washer
NKOST	M Material: EN 1.4305 Equiv. S Surface Treatment: Brushed Finish	M Material: EN 1.4305 Equiv.

RoHS 10

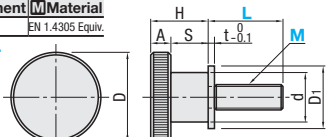


Part Number		L Selection										Unit Price	
Type	M (Coarse)												
NKOST	6	10	16	20	25								
	8		16	20	25	30							
	10			20	25	30	40						

Stepped Knobs - No Knurling

Type	M
NKCR	EN 1.4305 Equiv.

RoHS 10

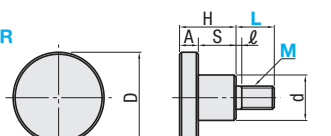


Part Number		L Selection										Unit Price	
Type	M (Coarse)												
NKCR	3	6	10										
	4		10	16									
	5			10	16								
	6				16	20							

Knurled Knobs - Large Diameter

Type	M	Material	Surface Treatment
NORD	EN 1.0736 Equiv.	EN 1.0736 Equiv.	Buff Polished + Chrome Plating
NKRD	EN 1.4305 Equiv.	EN 1.4305 Equiv.	Brushed Finish

RoHS 10

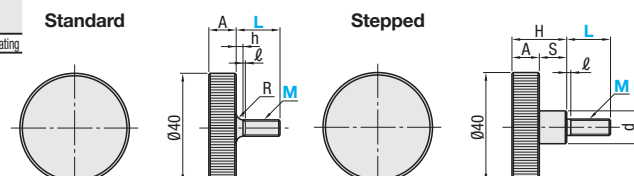


Part Number		L Selection										Unit Price	
Type	M (Coarse)												
Standard NORD	5	16	25										
	6	16		30									
	8	16			30								

Knurled Knobs - Small Diameter

Type	Shape	Material	Surface Treatment
NOBC	Threaded	EN 1.0736 Equiv.	Buff Polished + Chrome Plating
NOSC	Threaded	EN 1.4305 Equiv.	Brushed Finish
NOMC	Tapped	EN 1.0736 Equiv.	Buff Polished + Chrome Plating
NOMSC	Tapped	EN 1.4305 Equiv.	Brushed Finish

RoHS 10

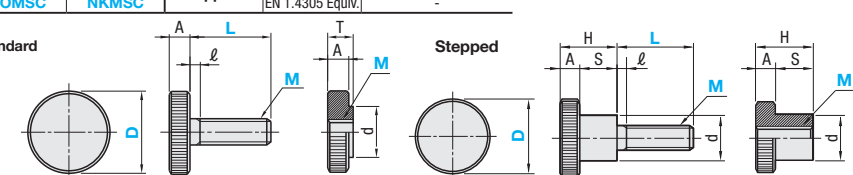

Part Number		L Selection										Unit Price			
Type	M (Coarse)														
Standard NOBC	3	6	10												
	4	6	10	16											
	5		10	16	20										
	6		10	16	20	25	30								
	8			16	20	25	30								
	10				20	25	30	40							

* marked items are applicable to NOBC and NOSC only.

Ordering Example

Part Number - L - D

NKOST6 - 25

NKCR3 - 10

NORD8 - 30


NOBC5 - 10 - 18

Knurled Knobs with Hex Socket / Checker Knurled Knobs / Knurled Knobs - Captured

Knurled Knobs with Hex Socket

Type	Material	Surface Treatment
NOBR	EN 1.0718 Equiv.	Buff Polished + Chrome Plating
NOOSR	EN 1.4305 Equiv.	Brushed Finish

RoHS 10

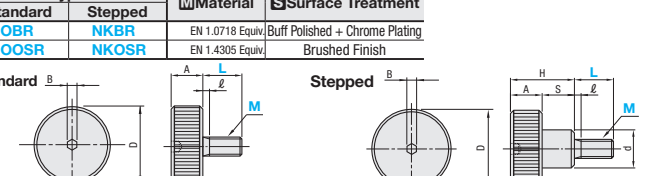

Part Number		L Selection										Unit Price	
Type	M (Coarse)												
Standard NOBR	3	6	10										
	4	6	10	16									
	5		10	16	20								

Ordering Example


Part Number - L

NOBR3 - 6

Checker Knurled Knobs

Type	Shape	Material	Surface Treatment
NOBX	Threaded	EN 1.0718 Equiv.	Buff Polished + Chrome Plating
NOOSX	Threaded	EN 1.4305 Equiv.	Brushed Finish
NOMSX	Tapped	EN 1.4305 Equiv.	Brushed Finish

RoHS 10

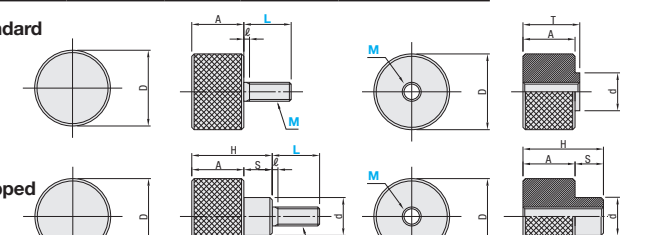


Part Number		L Selection (Threaded Type only)										Unit Price		
Type	M (Coarse)													
Standard NOBX	3	6	10											
	4	6	10	16										
	5		10	16	20									

Knurled Knobs - Captured

Type	Material	Surface Treatment
NOBD	EN 1.0718 Equiv.	Buff Polished + Chrome Plating
NOOSD	EN 1.4305 Equiv.	Brushed Finish

RoHS 10

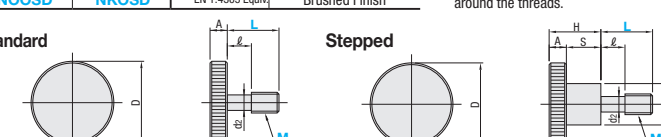

Part Number		L Selection										Unit Price	
Type	M (Coarse)												
Standard NOBD	3	10	12	6	2.5	7.5	5	6	2				
	4	10	16	8	3.5	9.5	6	5	3				
	5	15	20	10	4	11.5	7.5	9	3.8				
	6	20	24	12	5	15	10	12	4.5				
	8	30	30	16	6	18	12	10	6				
	10	30	30	16	6	18	12	10	6				

Ordering Example

Part Number - L

NOBX3 - 6

NOOSD5 - 10

Example

