

PVC Pipes / PVC Fittings

 
TS Fittings / HI Fittings

For dimension of the junction on fittings, see Dimension Table in Overview on **P.1286**. For specifications / application of each material, see Overview in **P.1286**.

■ PVC Pipe



Type	Material	Standards	Color
PVCT	PVC	JIS K 6742	Gray
PVCH	Impact Resistance PVC		Blue Gray



63(✓)

Note that pipe O.D. may have some scratches or small flaws on its surface.

Part Number		L 1mm Increment	O.D.		Thickness		I.D. (Reference Value)	Unit Price					
Type	No.		D	D Tolerance	t	t Tolerance		PVCT					
PVCT PVCH	13	50~1500	18	±0.2	2.5	±0.2	13	L50~200	201~400	401~600	601~800	801~1000	1001~1250
	16		22	±0.2	3	±0.3	16						
	20		26	±0.2	3	±0.3	20						
	25		32	±0.2	3.5	±0.3	25						
	30		38	±0.3	3.5	±0.3	31						


The tolerance of L dimension will be +1 ~ 3 for 50 ~ 1000, +2 ~ 5 for 1001 ~ 1500. * The price of PVCH is the price in the table above plus JPY100.

Ordering Example
Part Number - L
PVCT20 - 1000

■ Sockets



Type	Types	Material
PVCTS	TS Fittings	PVC
PVCHS	HI Fittings	Impact Resistance PVC

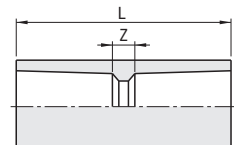


Part Number		Z	L	Standards	Unit Price	
Type	No.				PVCTS	PVCHS
PVCTS PVCHS	13	5	57	JIS K 6743	1 ~ 50 pcs.	20 ~ 50 pcs.
	16	7	67			
	20	7	77			
	25	7	87			
	30	7	95			

For orders larger than indicated quantity, please check with WOS.

■ Sockets for Valve Sockets



Type	Types	Material
PVCTSB	TS Fittings	PVC
PVCHSB	HI Fittings	Impact Resistance PVC

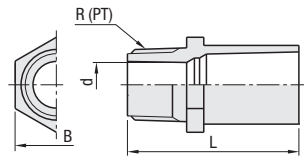


Part Number		R(PT)	d	B	L	Standards	Unit Price	
Type	No.						PVCTSB	PVCHSB
PVCTSB PVCHSB	13	1/2	13	24	50	JIS K 6743	1 ~ 50 pcs.	20 ~ 50 pcs.
	16	1/2	13	29	57			
	20	3/4	18	33	64			
	25	1	23	40	71			
	30	1 1/4	31	46	80			

For orders larger than indicated quantity, please check with WOS.

■ Reducing Sockets



Type	Types	Material
PVCTSD	TS Fittings	PVC
PVCHSD	HI Fittings	Impact Resistance PVC

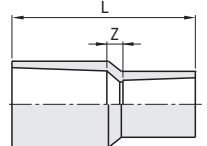


Part Number		Z	L	Standards	Unit Price	
Type	No.				PVCTSD	PVCHSD
PVCTSD PVCHSD	1613	5	61	JIS K 6743	1 ~ 50 pcs.	20 ~ 50 pcs.
	2016	6	71			
	2516	15	85			
	2520	9	84			
	3025	9	93			

For orders larger than indicated quantity, please check with WOS.

■ Tees



Type	Types	Material
PVCTT	TS Fittings	PVC
PVCHT	HI Fittings	Impact Resistance PVC

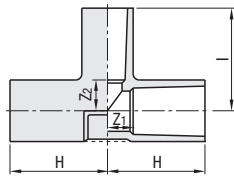


Part Number		Z ₁	Z ₂	H	I	Standards	Unit Price	
Type	No.						PVCTT	PVCHT
PVCTT PVCHT	13	10	10	36	36	JIS K 6743	1 ~ 50 pcs.	20 ~ 50 pcs.
	16	13	13	43	43			
	20	15	15	50	50			
	25	18	18	58	58			
	30	21	21	65	65			

For orders larger than indicated quantity, please check with WOS.

■ Reducing Tees



TS Fittings
PVCTTD

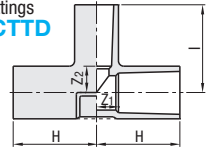

Material: PVC


Part Number		Z ₁	Z ₂	H	I	Standards	Unit Price	
Type	No.						1 ~ 50 pcs.	
PVCTTD	1613	11	12	41	38	JIS K 6743		
	2016	13	15	48	45			
	2516	13	18	53	48			
	2520	15	18	55	53			
	3025	18	21	62	61			

For orders larger than indicated quantity, please check with WOS.

■ 90° Elbows



Type	Types	Material
PVCTE	TS Fittings	PVC
PVCHE	HI Fittings	Impact Resistance PVC

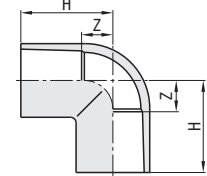


Part Number		Z	H	Standards	Unit Price	
Type	No.				PVCTE	PVCHE
PVCTE PVCHE	13	10	36	JIS K 6743	1 ~ 50 pcs.	20 ~ 50 pcs.
	16	13	43			
	20	15	50			
	25	18	58			
	30	21	65			

For orders larger than indicated quantity, please check with WOS.

■ 45° Elbows



HI Fittings
PVCHHE

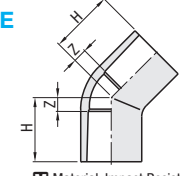

Material: Impact Resistance PVC


Part Number		Z	H	Standards	Unit Price	
Type	No.				1 ~ 50 pcs.	
PVCHHE	13	7	33	JIS K 6743		
	20	9	44			
	25	11	51			

For orders larger than indicated quantity, please check with WOS.

■ Caps



Type	Types	Material
PVCTC	TS Fittings	PVC
PVCHC	HI Fittings	Impact Resistance PVC

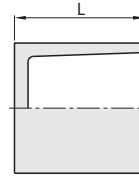


Part Number		L	Standards	Unit Price	
Type	No.			PVCTC	PVCHC
PVCTC PVCHC	13	29	JIS K 6743	1 ~ 50 pcs.	20 ~ 50 pcs.
	16	33.5			
	20	38.5			
	25	44			
	30	48			

For orders larger than indicated quantity, please check with WOS.

■ Elastic Fittings



TS Fittings
PVCTY

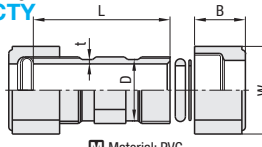

Material: PVC

Part Number		D	t	L	B	W	Standards	Unit Price	
Type	No.							1~10 pcs.	
PVCTY	13	26	3	68	25	38	JIS K 6743		
	16	34	5.5	110	29	42	-		
	20	35	3.5	78	29	50	JIS K 6743		
	25	43	4	89	29	56			
	30	48	4	98	33.5	63			

For PVCTY16, the nut is round-shaped.


Fittings for absorbing expansion / contraction of PVC Pipe due to heat

For orders larger than indicated quantity, please check with WOS.

■ Valves



TS Fittings
PVCTB

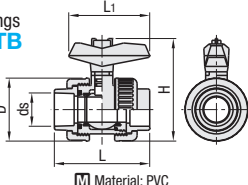

Material: PVC

Part Number		D	ds	H	L	L1	Standards	Unit Price	Volume Discount Rate
Type	No.							1 ~ 9 pc(s).	10 ~ 30 pcs.
PVCTB	16	50	22	78	109	77	JIS K 6743		
	20	59	26	89.5	125	97			
	25	68	32	101	142	97			
	30	80	38	119	158	129			

For orders larger than indicated quantity, please check with WOS.

■ Adhesive

(For PVC)


(For Impact Resistance PVC)


RoHS10

Ordering Example
Part Number
PVCHSB20
PVCHBN100

Part Number		Weight by Volume (g)		Unit Price	
Type	No.	1~20 pcs.		1~20 pcs.	
	100	100			
	500	500			

Part Number		Weight by Volume (g)		Unit Price	
Type	No.	1~20 pcs.		1~20 pcs.	
	100	100			
	500	500			

For orders larger than indicated quantity, please check with WOS.