


Plumbing Parts for Aluminum Duct Hoses

For Aluminum Duct Hoses Socket



RoHS10

 Type	Material	Surface Treatment
HOAM	EN 1.0038 Equiv.	Baked Acrylic Paint
HOAS	EN 1.4301 Equiv.	-




For Aluminum Duct Hoses Panel Mount



RoHS10

Type	Material	Surface Treatment
HOBUM	EN 1.0038 Equiv.	Baked Acrylic Paint
HOBV	EN 1.4301 Equiv.	-

 


For Aluminum Duct Hoses T-Shaped



RoHS10

Type	Material	Surface Treatment
HOATM	EN 1.0038 Equiv.	Baked Acrylic Paint
HOAT	EN 1.4301 Equiv.	-

 


For Aluminum Duct Hoses Y-Shaped



RoHS10

Type	Material	Surface Treatment
HOAYM	EN 1.0038 Equiv.	Baked Acrylic Paint
HOAYF	EN 1.4301 Equiv.	-

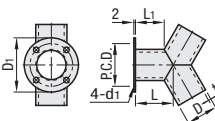


For Aluminum Duct Hoses Variant Y Type



RoHS10

Type	Material	Surface Treatment
HOAYEM	EN 1.0038 Equiv.	Baked Acrylic Paint
HOAYE	EN 1.4301 Equiv.	-

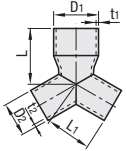


For Aluminum Duct Hoses Variant Y-Shaped



RoHS10

Type	Material	Surface Treatment
HOAHYM	EN 1.0038 Equiv.	Baked Acrylic Paint
HOAHY	EN 1.4301 Equiv.	-

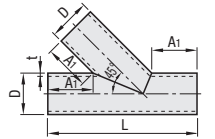

Part Number	Type	No.	L Fixed	L Configurable 1mm Increment	D	t	Unit Price
							HOAM HOAS HOASK
							L50-100 L101-200
		38			38	1.2	
		50			48.6	1.5	
		65			63.5		
		75			75		
		100			98		
		113			112		
		125			124		
		150			149		

Part Number	Type	Normal Dia.	D	L1	L2	D1	P.C.D.	d1	t	Unit Price
										HOBUM HOBV
		38	38	40	100	66	52	6.6	1.2	
		50	48.6	40	100	79	65		1.5	
		65	63.5	40	100	91.5	77.5			
		75	75	40	100	111	94			
		100	98	50	100	136	119			
		113	112	50	100	152	134			
		125	124	50	100	168	148			
		150	149	50	100	193	173			

Part Number	Type	Normal Dia.	D	L	A1	t	Unit Price
							HOATM HOAT
		38	38	100	50	1.2	
		50	48.5	120	60	1.5	
		65	63.5	135	68		
		75	75	145	72		
		100	98	180	90		
		113	112	180	100		
		125	124	200	110		
		150	149	240	120		

Part Number	Type	Normal Dia.	D	L	L1	D1	P.C.D.	d1	t	Unit Price
										HOAYM HOAY HOAYFM HOAYF
		38	38	46(45)	35(34)	66	52	6.6	1.2	
		50	48.6	55(54)	41(40)	79	65		1.5	
		65	63.5	60(59)		91.5	77.5		2	
		75	75	65(64)	43(42)	111	94			
		100	98	75(74)	46(45)	136	119			
		113	112	80(79)	47.7(48.7)	152	134			
		125	124	85(84)	49.2(48.2)	168	148			
		150	149	95(94)	52(51)	193	173			

Dimensions in () are applicable to flanged type.

Part Number	Type	Normal Dia.	D1	D2	L	L1	t1	t2	Unit Price
									HOAYEM HOAYE
		50	48.5	38	80	46	1.5	1.2	
		65	63.5	48.5	85	55		1.5	
		75	75	63.5	88	60			
		100	98	75	100	65			
		113	112	98	105	75			
		125	124	112	110	80			
		150	149	124	120	85			


Part Number	Type	Normal Dia.	D	L	A1	t	Unit Price
							HOAHYM HOAHY
		38	38	114	30	1.2	
		50	48.5	141	36	1.5	
		65	63.5	172	41		
		75	75	194	44		
		100	98	243	52		
		113	112	278	60		
		125	124	305	65		
		150	149	350	70		

For Aluminum Duct Hoses 45° Reducer



RoHS10

Type	Material	Surface Treatment
HOAFEM	EN 1.0038 Equiv.	Baked Acrylic Paint
HOAFE	EN 1.4301 Equiv.	-

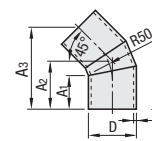


For Aluminum Duct Hoses Flanged



RoHS10

Type	Material	Surface Treatment
HOAJ	EN 1.4301 Equiv.	-

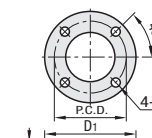

Ordering Example Part Number
HOAFEM 38




Specifications
Operating Temperature Range: 0 ~ 160°C

Duct Plumbing Manifolds



RoHS10

Type	Size	Material
2 Outlets DBXWS DBXWM	150x150x300 200x200x300	EN 1.4301 Equiv.
3 Outlets DBXTS DBXTM		

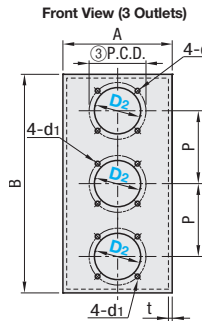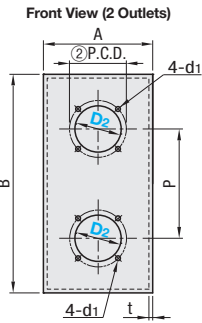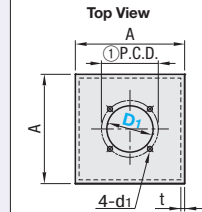


Part Number	Type	D1	D2	A	B	D1 · D2 ①P.C.D.	P 2 Outlets 3 Outlets	d1	t	Unit Price 1 ~ 4 pc(s).
										DBXWS DBXTS DBXWM DBXTM
		38	38			38 52				
		50	50			50 65				
		65	65			65 77.5				
		75	75			75 94				
		100	100			100 119				
		38	38			38 52				
		50	50			50 65				
		65	65			65 77.5				
		75	75			75 94				
		100	100			100 119				
		113	113			113 134				
		125	125			125 148				
		150	150			150 173				

D2=75, 100 is not available for 3-story Type (DBXTS, DBXTM).

Ordering Example Part Number - D1 - D2
DBXWS - 100 - 50
DBXTM - 113 - 38

Example

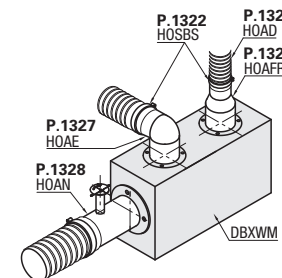

Ordering Example Part Number
HOATM 50

Specifications
Operating Temperature Range: 0 ~ 160°C