

Lids for Open-Top Tanks / Gaskets for Sealing Lids / Stands for Open-Top Tanks


Outlet Config. Selectable

■ **Features:** Upper column mid column: Tank components can be ordered from one unit. Shape of the inlet on Lids for Sealable Tanks are selectable. Lower column: Detachable tank holder.

■ Lids for Open-Top Tanks




Standard Type	Type		Material	Normal Operating Pressure
	Standard	Sealable Outlet Config. Selectable		
TANCV	TANCV	TANCVS	EN 1.4301 Equiv.	Atmospheric Pressure

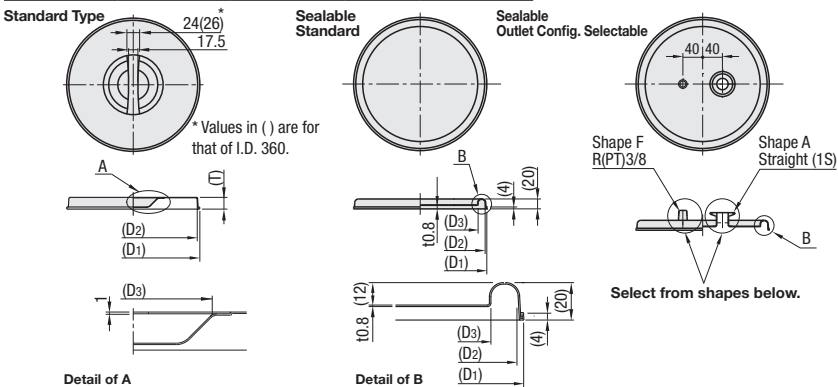


Sanitary Inlet Shapes


A Shape: Straight (1S)

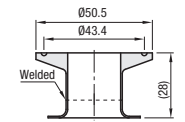


D Shape: R (PT) 1/8

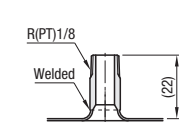

E Shape: R (PT) 1/4

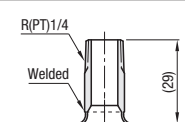

F Shape: R (PT) 3/8

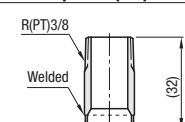

Male Thread Inlet Shapes

■ Lids for Standard Open-Top Tanks

Part Number	Type	Tank I.D. (D)	(D1)	(D2)	(D3)	(T)	Unit Price Qty. 1 ~ 3
180	TANCV	207	197	92	22		
210		236	226				
240		267	257				
270		296	286				
300		330	320				
360		390	380	109	25		

■ Lids for Sealable Open-Top Tanks


Part Number	Type	Tank I.D. (D)	Inlet Shape TANCVS only	(D1)	(D2)	(D3)	Unit Price 1 ~ 3 pc(s).	
							TANCV	TANCVS
180	Standard TANCV	207	A D E F	198	175			
210		234		227	202			
240		269		262	234			
270		297		290	260			
300		330		323	291			
360		390		382	352			

☞ When ordering Outlet Config. Selectable Sealable Open-Top Tanks, choose TANCVS, which is for liquid discharging under airtight condition.


☞ Price of TANCVS = Body Price + Shape Charge x2

Ordering Example: Part Number - For Inlet Shape Selectable Type
TANCV180 - A - A
TANCVS210 - A - A

■ Gasket

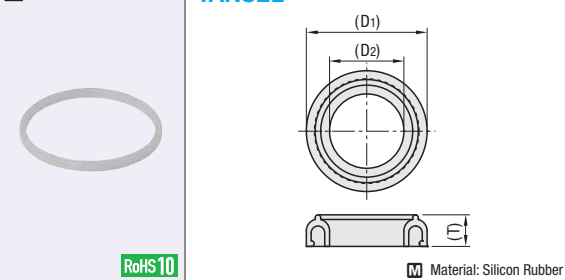

■ Stand

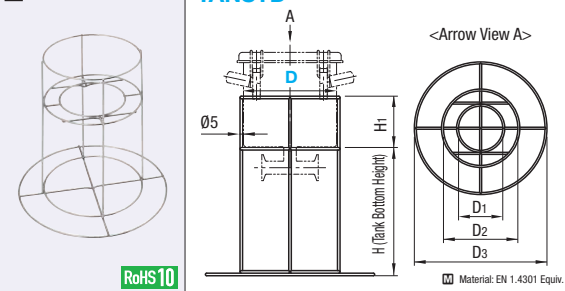

Part Number	Type	Tank I.D. (D)	(D1)	(D2)	(T)	Unit Price Qty. 1 ~ 3
180	Gasket TANSEL	195	177	13		
210		226	205	16		
240		260	235	17		
270		288	266	17		
300		321	296	17		
360		380	358	16		

☞ Feature of Silicon Rubber P.391

☞ Feature of Gaskets for Sealing Lids P.1356

☞ For orders larger than indicated quantity, please check with WOS.

Part Number	Type	Tank I.D. (D)	H	D1	D2	D3	H1	Unit Price Qty. 1 ~ 3
180	Stand TANSTD	250	120	195	330	100		
210			150	225	350	120		
240			180	255	370	140		

☞ D1 fits any of the outlet configuration of Outlet Config. Selectable Type.

☞ Not available when installing level gauge.

☞ For orders larger than indicated quantity, please check with WOS.

Ordering Example: Part Number
TANSEL180
TANSTD210

