


Adjustable Hoses Set

Adjustable Hoses Components / Installation Tools

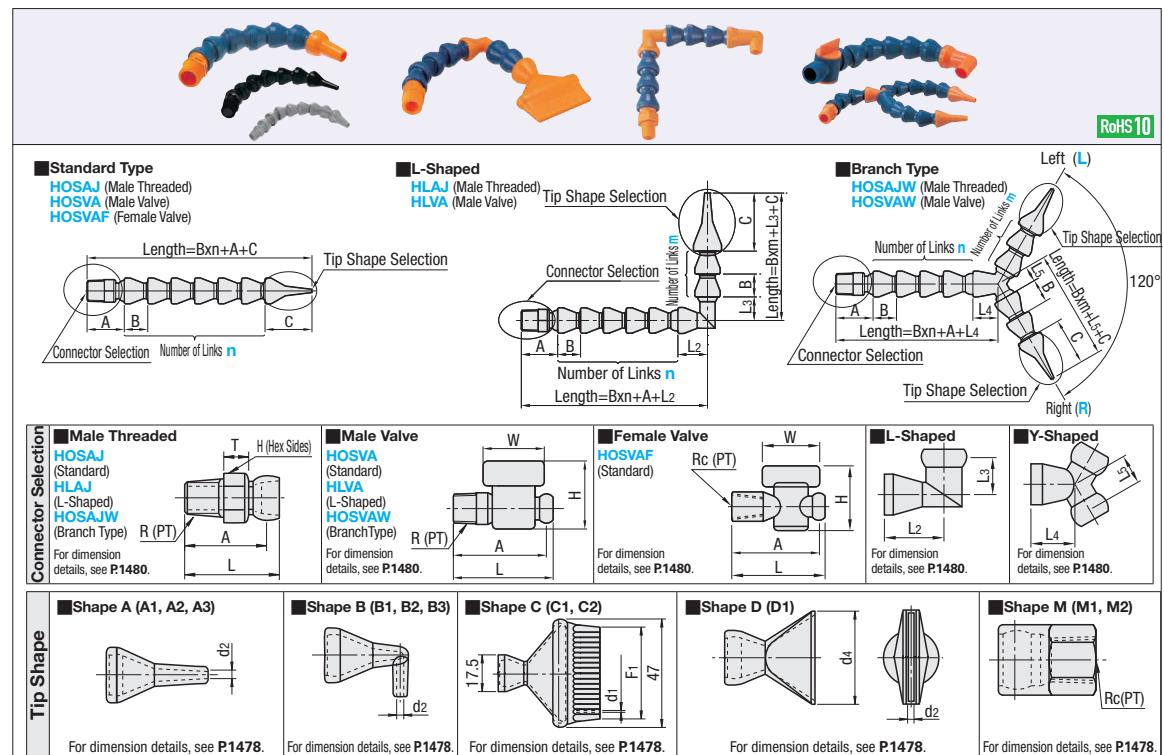

Part Number		Hose Color Selectable		Number of Links n Configurable		Connector Thread Size (PT)		Tip Shape (For dimension details, see P.1478.)	
Type	Hose Nominal	For Male Threaded (Selection)	For Male Valve / Female Valve (Fixed)	For Male Threaded (Selection)	For Male Valve (Fixed)	For Male Threaded (Selection)	For Male Valve / Female Valve (Fixed)	(Hose: Blue) A1, A2, A3, B1, B2, B3, C1, C2, D1, M1, M2	
HOSAJ (Male Threaded) HOSVA (Male Valve) *HOSVAF (Female Valve)	2	Not Specified (Blue) G (Gray) B (Black)	0-30	1 (R1/8) 2 (R1/4)	2 (R/Rc1/4)	3 (R3/8) 4 (R1/2)	3 (R/Rc3/8) 4 (R1/2)	(Hose: Blue) A1, A2, A3, B1, B2, B3, C1, C2, D1, M1, M2 (Hose: Gray) A1, A2, A3, D1 (Hose: Black) A1, A2, A3, C1, C2, D1	(Hose: Blue) A1, A2, A3, D1 (Hose: Gray) A1, A2, A3, D1
	3			3 (R3/8) 4 (R1/2)	3 (R/Rc3/8) 4 (R1/2)				
	4			3 (R3/8) 4 (R1/2)	4 (R/Rc1/2)				

* Hose nominal size 3 is not selectable for Female Valve. The hose color for Female Valve is blue only.

L-Shaped Type Hose Body: Blue, Nozzle: Orange

Part Number		Number of Links n Configurable		Connector Thread Size (PT)		Number of Links m Configurable		Tip Shape (For dimension details, see P.1478.)	
Type	Hose Nominal	For Male Threaded (Selection)	For Male Valve (Fixed)	For Male Threaded (Selection)	For Male Valve (Fixed)	For Male Threaded (Selection)	For Male Valve (Fixed)	A1, A2, A3, B1, B2, B3, C1, C2, D1, M1, M2	
HLAJ (Male Threaded) HLVA (Male Valve)	2	0-30	1 (R1/8) 2 (R1/4)	2 (R/Rc1/4)	0-20	A1, A2, A3, B1, B2, B3, C1, C2, D1, M1, M2			
	4		3 (R3/8) 4 (R1/2)	4 (R/Rc1/2)		A1, A2, A3, B1, B2, B3, D1			


Branch Type Hose Body: Blue, Nozzle: Orange

Part Number		Number of Links n Configurable		Connector Thread Size (PT)		Number of Links m Configurable		Tip Shape (For dimension details, see P.1478.)	
Type	Hose Nominal	For Male Threaded (Selection)	For Male Valve (Fixed)	For Male Threaded (Selection)	For Male Valve (Fixed)	Right (R) Left (L)	Right (R) Left (L)	A1, A2, A3, B1, B2, B3, C1, C2, D1, M1, M2	
HOSAJW (Male Threaded) HOSVAV (Male Valve)	2	0-30	1 (R1/8) 2 (R1/4)	2 (R/Rc1/4)	0-20	0-20	0-20	A1, A2, A3, B1, B2, B3, C1, C2, D1, M1, M2	
	4		3 (R3/8) 4 (R1/2)	4 (R/Rc1/2)				A1, A2, A3, B1, B2, B3, D1	


Standard	Part Number	Hose Color	Number of Links n	Connectors Thread Size	Number of Links m	Number of Links Right (R)	Number of Links Left (L)	Nozzle
(Standard)	HOSVA2 - B - 20 - 2							- D1
(L-Shaped)	HLVA2 - 10 - 2 - 5							- B1

Hose Nominal	Link Unit Price	Connector Unit Price			Nozzle Unit Price			L-Shaped Type / Branch Type Additional Price	
		Shape AJ	Shape VA	Shape VAF	A1 A2	B1 B2	C1 C2	D1	M1 M2
2									
3									
4									

Price Calculation Example
 - For Standard Type HOSAJ2-30-1-A1:
 (Link Unit Price) x (Number of Links) + (Connector Unit Price) + (Nozzle Unit Price)
 - For L-Shaped Type HLVA2-10-2-5-B1:
 (Link Unit Price) x (Number of Links n + Number of Links m) + (Connector Unit Price) + (Nozzle Unit Price) + (L-Shaped Type Additional Price)
 - For Branch Type HOSVAV2-5-2-R10-L7-D1:
 (Link Unit Price) x (Number of Links n + Number of Links on the Right + Number of Links on the Left) + (Connector Unit Price) + (Tip Shape Price for 2 pcs.) + (Branch Type Additional Price)

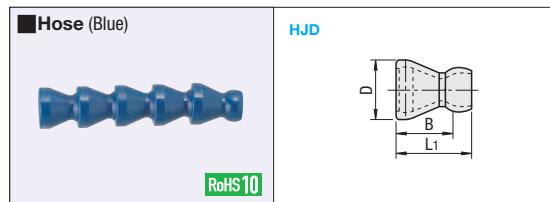


Part Number		Number of Links	Hose I.D.	D	B	L1	Unit Price	
Type	Hose Nominal						1 ~ 20 pc(s).	
HJD	2						6.3	16
	3						8.5	21
	4						12.7	24.5

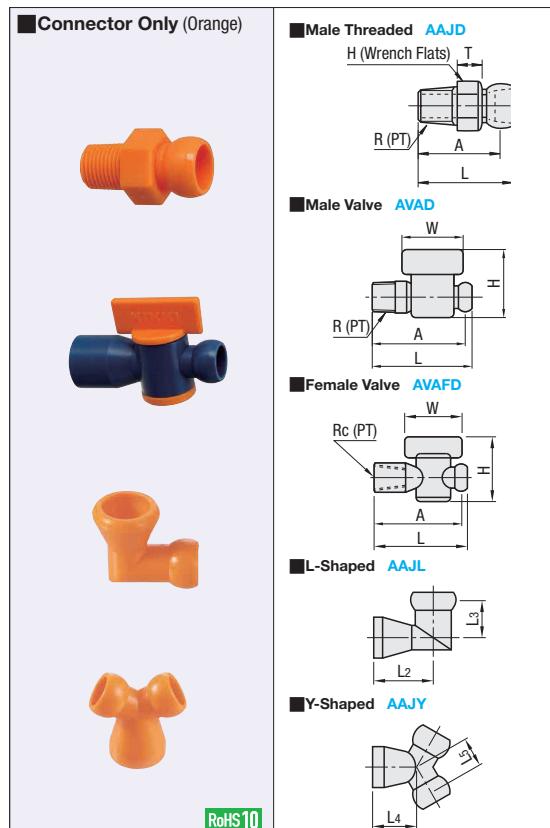

Part Number		Connector Thread Size R (PT)	A	L	H	T	Unit Price	
Type	Hose Nominal						1 ~ 20 pc(s).	
AAJD	1 (R1/8)		23	26.3	14	7		
	2 (R1/4)							
	3 (R3/8)	27.3	32	19	8			
	4 (R1/2)	28	38.3	18.8	7.5			

Part Number		Connector Thread Size R (PT)	A	L	H	W	Unit Price	
Type	Hose Nominal						1 ~ 20 pc(s).	
AVAD	2 (R1/4)		41	41	30	27		
	3 (R3/8)							
	4 (R1/2)	48.5	48.5	43	34			
	3 (R3/8)							

Part Number		AAJL		AAJY		Unit Price 1 ~ 20 pc(s).	
Type	Hose Nominal	L2	L3	L4	L5	AAJY	AAJL
AAJL	2	17	12	15.5	9.5		
AAJY	4	23.5	16.5	23.5	19		

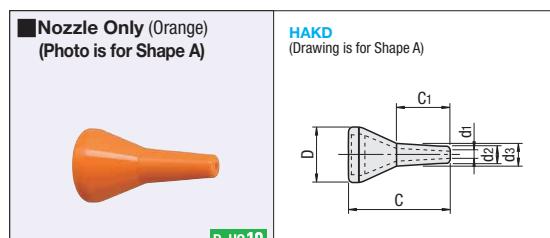

For dimension details, see P.1478.

Part Number		Nozzle		Unit Price 1 ~ 20 pc(s.)				
Type	Hose Nominal	Shape	No.	Shape A	Shape B	Shape C	Shape D	Shape M
HAKD	1	A B C D M	1					
	2		2					
	3		3					
	4		4					
	5		5					



Hose body is fragile; handling requires careful attention.<