



DIN Rails

Price Reduction
Up to 76%

CAD Data

Feature: DIN Rails for mounting amplifiers for fiber sensor or control panels. Offered at a substantially discounted price.


RoHS




M Material	S Surface Treatment	Part Number		
		Installation Surface 27mm		Installation Surface 31mm
		For M4		For M5
EN AW-6063/AlMg0,7Si-T5	Clear Anodize	DNR274	DNR314	DNR315

No Anodizing on the tip and inner surface.
Burs remain inside of the mounting holes.


DNR274

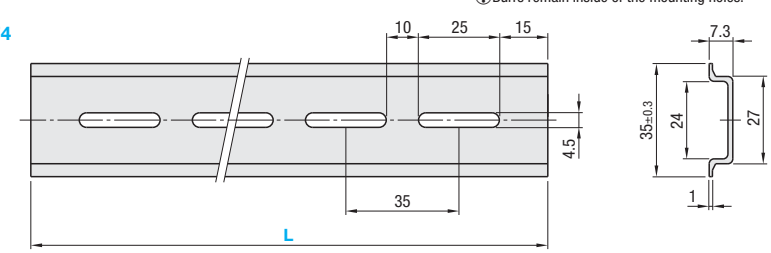

DNR314

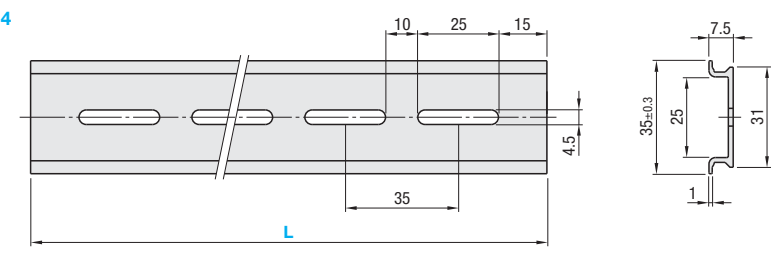

DNR315

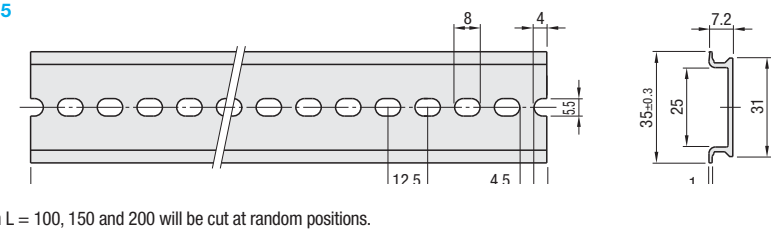

Rails with L = 100, 150 and 200 will be cut at random positions.

Part Number	L Selection	DNR274 · 314			DNR315	
		€ Unit Price Qty. 1~9	Volume Discount		€ Unit Price Qty. 1~9	Volume Discount
DNR274 DNR314 DNR315	100		10~29 pcs.	30~49 pcs.		10~49 pcs.
	150					
	200					
	1000					

Order Example


Part Number - L
DNR274 - 150
DNR315 - 1000

Days to Ship

6 Days

P. 87

Example

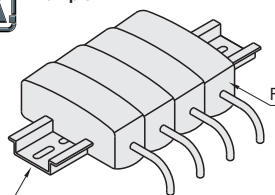

DNR274

Suitable to mount an amplifier for optical fiber sensor.


C-shaped Sensor Rails · Simple Stays
· Grounding Blocks

CAD Data

C-shaped Sensor Rails



SERCC

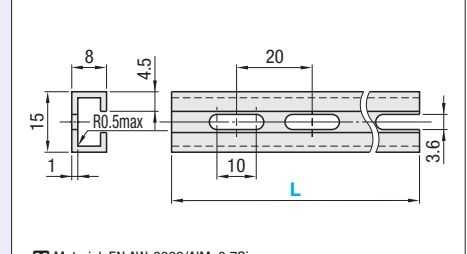

M Material: EN AW-6063/AlMg0,7Si
S Surface Treatment: Clear Anodize (Except Tip Section)

Part Number	L	€ Unit Price Qty. 1~9	Volume Discount 10~
SERCC	200		
	300		
	500		

Order Example


Part Number - L
SERCC - 200

Days to Ship


6 Days

P. 87

Simple Brackets

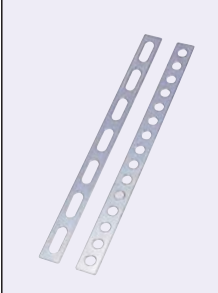


EYST

 

25 / (✓)

 EYSTE



M Material: 1.0330/DC01
S Surface Treatment: Trivalent Chromate Plating

Part Number	No. of Mounting Holes	€ Unit Price
EYST	15	
EYSTE	7	

Order Example

Part Number
EYST

Days to Ship

6 Days

P. 87


Price

Volume Discount (Round down to one Cent.) P.87

Quantity	1~19	20~34	35~49	50~99
Rate	€ Unit Price	5%	10%	18%


For orders larger than indicated quantity, please request a quotation.

 Example




Bendable at desired positions.

Grounding Blocks

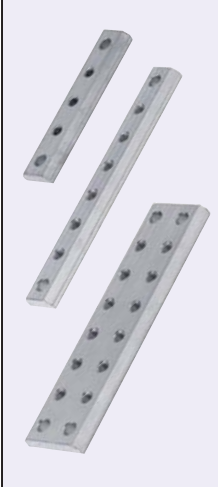


ETB3

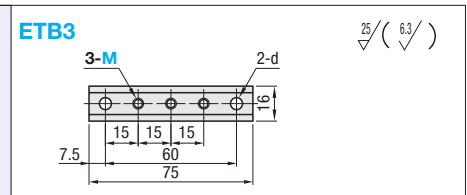


25 / (6.3 / ✓)

ETB6

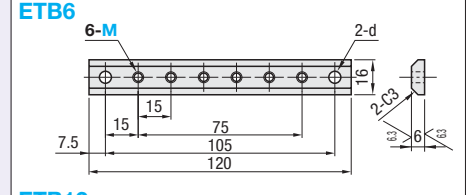

ETB12

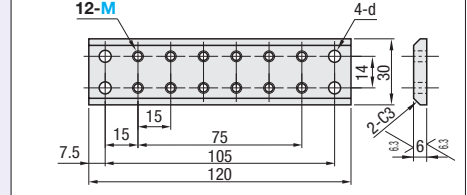

M Material: CW505L/CuZn30
S Surface Treatment: Electroless Nickel Plating

Part Number	M	d	€ Unit Price		
			ETB3	ETB6	ETB12
ETB3	4	4.5			
ETB6	5	5.5			
ETB12	6	6.6			

Order Example

Part Number - M
ETB3 - 4

Days to Ship

6 Days

P. 87

Price

Volume Discount (Round down to one Cent.) P.87

Quantity	1~19	20~34	35~49	50~99
Rate	€ Unit Price	5%	10%	18%

For orders larger than indicated quantity, please request a quotation.

Example

