 


# DATE MARKED PIN SETS

—L ADJUSTABLE TYPE—



Guide P.569

Non JIS material definition is listed on P.1351 - 1352

### ① Inside Arrow

**Inside Arrow (For single items P.573)**

No.	F	T	H	B	ℓ	M×P
6	7.7	1.5	3.0	3.7	2.7	M1.6×0.20
8	9.7	2.0	3.5	5.0	3.2	M2.3×0.25
10	11.7	2.5	4.0	6.3	4.0	M2.5×0.35

M SUS420  
H 50 ~ 53HRC

### ② Outside Ring

**Outside Ring (For single items P.591)**

D	LA	ℓ <sub>1</sub>	ℓ <sub>2</sub>	ℓ <sub>3</sub>	M (Coarse thread)	g	d
6	12	8	4	1.0	M3	1.0	5.5
8	14	10	5	1.0	M4	1.0	7.5
10	16	12	6	1.5	M5	1.5	9.5

M SUS420  
H 50 ~ 53HRC

### ③ Date Mark Adjusting Pins


**Date Mark Adjusting Pins**

No.	d	H	M (Coarse thread)	g2
6	5.5	9	M3	3.5
8	7.5	11	M4	4.5
10	9.5	15	M5	5.5

M SUS440C  
H 56 ~ 60HRC

**\*(Effective tap depth) = LB - X**

LB	X		
	No.6	No.8	No.10
10.00~20.00	4	2	0
20.01~30.00	14	12	10
30.01~40.00	24	22	20
40.01~50.00	34	32	30
50.01~60.00	—	42	40
60.01~70.00	—	—	50

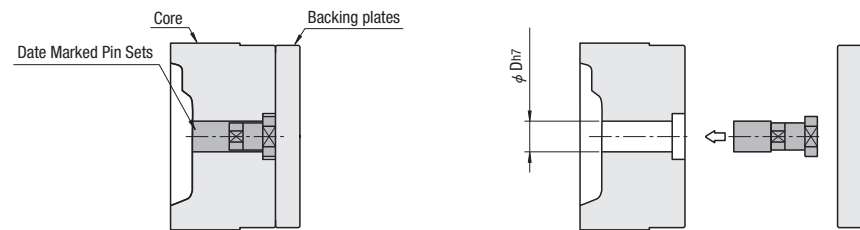

## ① Inside Arrow + ② Outside Ring Set

### Year · Month Type

Indication	Outside rings divisions	Part Number		Year	U/Price 1~9
		Type	D		
Year · Month	12 uniform divisions	DTBXL	6	15	Quotation for 2015 ※Days to ship will be 5-days for the adjustment of production after November 2015. for 2016 (available from Sept., 2015) ※Days to ship will be 5-days for the adjustment of production after November 2016. for 2017 (available from Sept., 2016) ※Days to ship will be 5-days for the adjustment of production after November 2017.
			8	16	
			10	17	

### Character Designation Type

Indication	Outside rings divisions	Part Number		Engraving characters (2 characters · Characters printed in blue in indications)	U/Price 1~9	
		Type	D			
2 characters · Month	12 uniform divisions	DTMBXL	6	ABCDE FGH I J KLMNO PQRST UVWXY Z	Quotation Name Characters for engraving Order code Slash / ¥ Greater > > Less < < Plus + + Minus - # Space □ %	
			8			01234 56789
			10			

Use ¥ for indicating / (slash), # for - (minus), and % for (space).

Order Part Number - Year  
 Year · Month Type DTBXL 8 - 15  
 Month Type DTDXL 8

Days to Ship Quotation

Part Number - Characters for engraving  
 Character Designation Type DTMBXL8 - AB

### Outside Ring Character Designation Type

Indication							
1M (1 place)	2M (2 places)	3M (3 places)	4M (4 places)	5M (5 places)	6M (6 places)	10M (10 places)	12M (12 places)
Engraving position	Engraving position	Engraving position	Engraving position	Engraving position	Engraving position	Engraving position	Engraving position

Up to 3 characters can be designated at each engraving position. Up to 2 characters can be designated at each engraving position. Only 1 character can be designated at each engraving position.

Part Number	Engraving characters (1~3 characters · Characters printed in blue in indications)							U/Price 1~9							
	Type	Indication	D	Engraving position ①~⑫				1M	2M	3M	4M	5M	6M	10M	12M
DTXL	1M	6	8	0	1	2	3	4	Name Characters for engraving Order code Slash / ¥ Greater > > Less < < Plus + + Minus - # Space □ %	Quotation					
	2M														
	3M														
	4M														
	5M														
	6M														
	10M														
12M															

Use ¥ for indicating / (slash), # for - (minus), and % for (space).

Dividing of outside rings 1M · 2M · 3M · 4M · 6M · 12M 12 uniform divisions  
5M · 10M 10 uniform divisions

Order Part Number - Characters for engraving  
 DTXL 3M 6 - POM - PS - SAN  
 DTXL 5M 10 - PA - % - # - 0% - ¥% (No character can be designated by (space).)  
 DTXL 6M 10 - 09 - 10 - 11 - 12 - 13 - 14  
 DTXL 12M 10 - 0 - 1 - 2 - 3 - 4 - 5 - F

Days to Ship Quotation  
Price Quotation

### ③ Date Mark Adjusting Pins

Type	Part Number		Lb	U/Price 1~9		
	Type	No.		0.01mm increments	Lb10.00~30.00	Lb30.01~50.00
	CPWDT-L	6	10.00~50.00			
		8	10.00~60.00	Quotation		
		10	10.00~70.00			

Order Part Number - Lb  
 CPWDT-L 8 - 25.32

Days to Ship Quotation  
Price Quotation

Date Marked Pins Recycle Marked Pins Pins with Gas Vent