

HOSE NIPPLES


— MALE THREAD TYPE / EXTENSION TYPE —

Use in atmospheric pressure 2,500 Kpa (25.49 kgf/cm²) or lower.

Male thread type (Water use)



Type	Valve	max. °C	Thread
D-NPW	—	100	MxP
D-NPWG	—	100	PF(G)

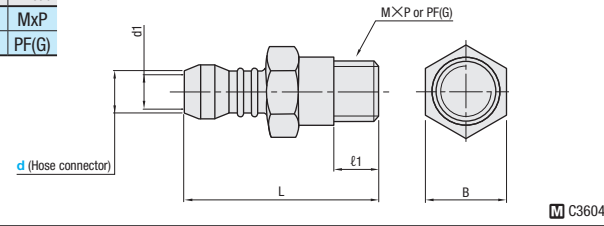

C3604

Metric thread type

B	L	E	d1	M×P	Part No.		M
					Type	d	
11	40.5	7	6	M10×1.0	D-NPW	9	10
15	47	9	8	M12×1.5		13	12
			9	M14×1.5		14	14
27	62	12	13	M24×1.5		19	24

Parallel pipe thread type


B	L	E	d1	PF(G)	Part No.		No.
					Type	d	
11	40.5	7	6	G1/8A	D-NPWG	9	1
15	47	9	9	G1/4A		13	2
27	62	12	13	G1/2A		19	4



Order Part No. — M
D-NPW13 — 14
Part No. — No.
D-NPWG13 — 2

Male thread type (Air use)

D-NPAG

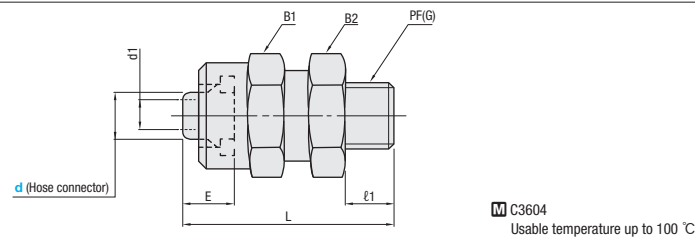

C3604

Usable temperature up to 100 °C


B1	B2	L	E	d1	PF(G)	Part No.		No.
						Type	d	
14	14	25	7	5	G1/8A	D-NPAG	6	1



Order Part No. — No.
D-NPAG6 — 1

Extension type

D-VV

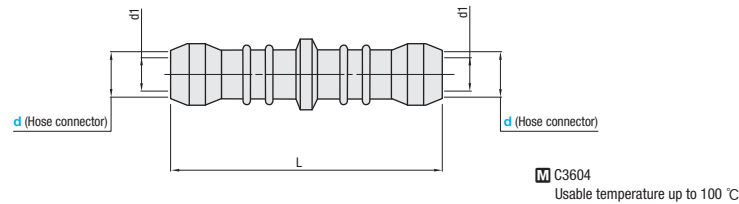

C3604

Usable temperature up to 100 °C

L	d1	Part No.	
		Type	d
48	6	D-VV	9
54	9		13
69	13		19



Order Part No. —
D-VV9

HOSE NIPPLES


— FEMALE THREAD TYPE / HOT WATER HOSES —

Use in atmospheric pressure 2,500 Kpa (25.49 kgf/cm²) or lower.

Female thread type



Type	Valve	max. °C	Thread
D-NPF	—	100	MxP
D-NPFG	—	100	PF(G)

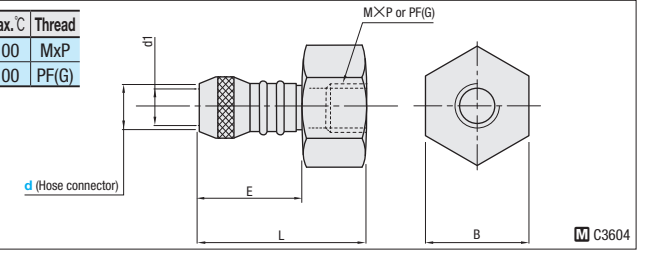

C3604

Metric thread type

B	L	E	d1	M×P	Part No.		M
					Type	d	
17	40	23.5	6	M14×1.5	D-NPF	9	14
22	42	27	9	M16×1.5		13	16
				M24×1.5		19	24

Parallel pipe thread type



B	L	E	d1	PF(G)	Part No.		No.
					Type	d	
17	40	23.5	6	G1/4	D-NPFG	9	2
22	42	27	9	G3/8		13	3
				G3/4		19	6



Order Part No. — M
D-NPF9 — 14
Part No. — No.
D-NPFG13 — 3

Female thread type (Pusher lock type)

D-NPFL

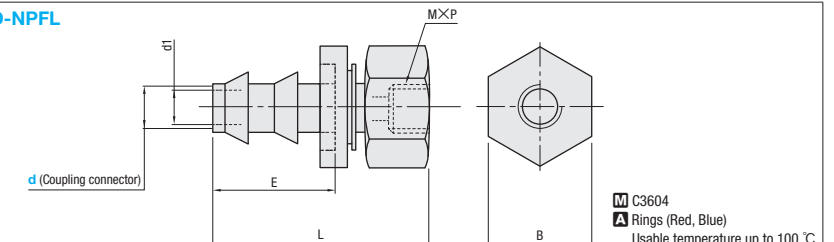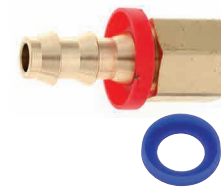

C3604

A Rings (Red, Blue)
Usable temperature up to 100 °C

Metric thread type


B	L	E	d1	M×P	Part No.		M
					Type	d	
17	40	22.5	6	M14×1.5	D-NPFL	9	14
22	42	25	9	M16×1.5		13	16



Order Part No. — M
D-NPFL13 — 16

Hot water hoses

D-MHW

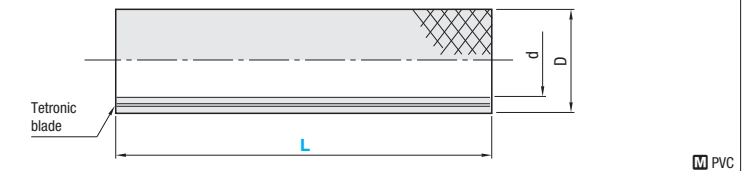

PVC

D	Part No.		L
	Type	d	
15	D-MHW	9	10
17		13	
26		19	

Specifications	Part No.		
	D-MHW9	D-MHW13	D-MHW19
Allowable pressure (MPa)	1.0	0.8	0.6
Allowable temperature range	0°C ~ 60°C		

The color may be different depending on the size.



Order Part No. — L
D-MHW13 — 25